

VK001022
CONNECTION TECHNOLOGY • DISTRIBUTION TERMINALS

distributor, 30x29x113mm, 6x M8 3pin, 10-30V DC, M12 12pin, IP67, PBT, With LED display


MECHANICAL FEATURES

Degree of protection (IP)	IP67
Fix cable version suitable for trailing chain	-
Height	30 mm
Housing material	PBT
Length	28.8 mm
Width	113.4 mm

ELECTRICAL FEATURES

Cable length, configurable	-
Connection for NPN sensors	-
Number of pins	12
Number of pins of sensor/actuator slots	3
Number of sensor/actuator slots	6
Operating voltage	10 V ... 30 V
Type of branches for sensor/actuator cables	M8
Type of plug connector for trunk line	M12
Voltage type	DC
With LED display	+
With potential separation	-

OTHER FEATURES

Degree of soiling	3
Operating temperature	-25 °C ... 70 °C


Other

Packaging dimensions	70mm x 38.0mm x 168.0mm
Shipping weight	0.12kg
Tariff code	85366990


Classification

ipf product group	855
eClass 8.0	27279219
eClass 9.0	27440108
eClass 9.1	27440108
ETIM-5.0	EC002585
ETIM-6.0	EC002585
ETIM-7.0	EC002585

Connection

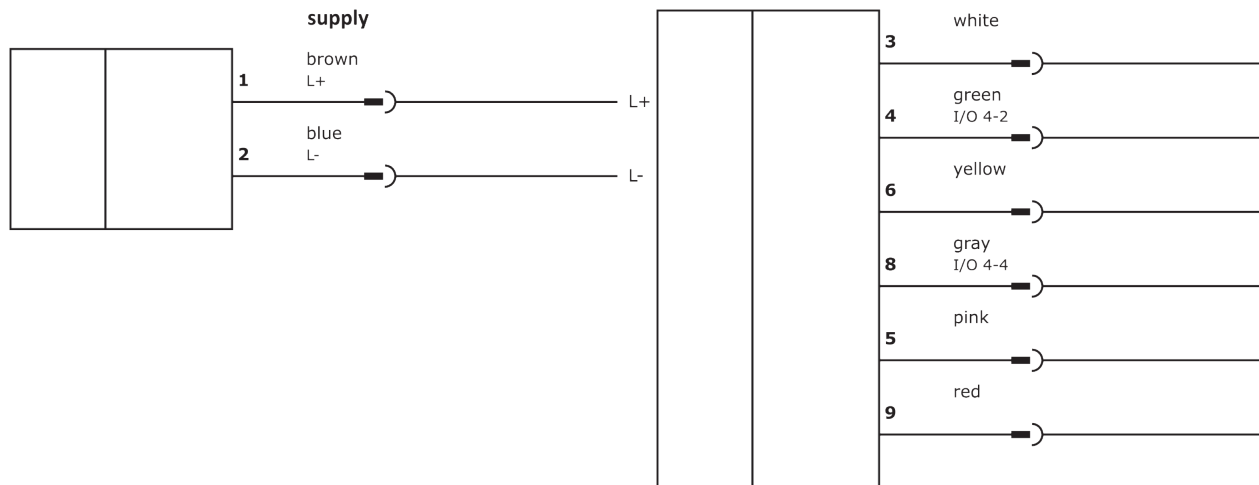

Dimensional drawing

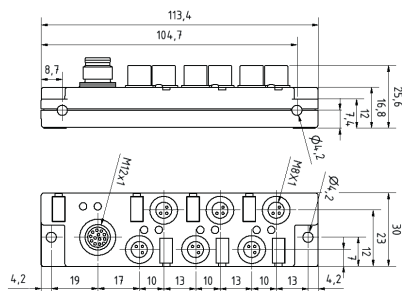

Installation



Mounting / installation may only be carried out by a qualified electrician!

Disposal



Safety warnings

Before initial operation, please make sure to follow all safety instructions that may be provided in the product information. Never use these devices in applications where the safety of a person depends on their functionality. LED lighting systems can generate intensive UV radiation, which can damage your eyes in case of improper use. The manufacturer cannot be held responsible for damages that result from improper use or connection.