


# Flare Nut Wrench & Set

KT No. & D1

## 1931

- 12 points
- 12° ring offset
- Chrome vanadium alloy steel
- Chrome plated
- DIN 3118


| KT NO.   | Size mm | L mm |  |  |
|----------|---------|------|-----------------------------------------------------------------------------------|-----------------------------------------------------------------------------------|
| 19312224 | 22 x 24 | 250  | 309                                                                               | 6 / 72                                                                            |
| 19312427 | 24 x 27 | 270  | 406                                                                               | 6 / 48                                                                            |
| 19313032 | 30 x 32 | 290  | 546                                                                               | 5 / 40                                                                            |

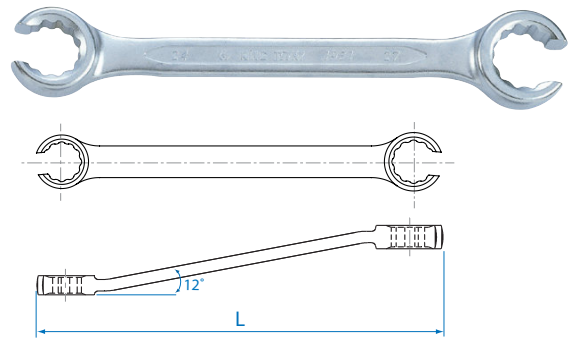

# Flexible Head Wrench & Set

## 1020

- Combination flexible head wrench with 12 points thin wall socket
- 180° swivel head for better accessibility
- Chrome vanadium alloy steel
- Chrome plated



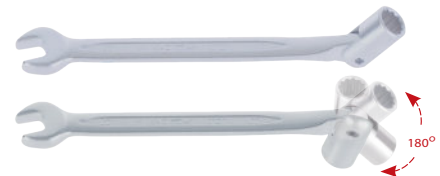


| KT NO.  | Size mm | L mm |  |  |
|---------|---------|------|------------------------------------------------------------------------------------|------------------------------------------------------------------------------------|
| 1020-08 | 8       | 170  | 64                                                                                 | 10 / 180                                                                           |
| 1020-09 | 9       | 170  | 68                                                                                 | 10 / 180                                                                           |
| 1020-10 | 10      | 180  | 81                                                                                 | 10 / 160                                                                           |
| 1020-11 | 11      | 188  | 106                                                                                | 10 / 160                                                                           |
| 1020-12 | 12      | 190  | 107                                                                                | 10 / 120                                                                           |
| 1020-13 | 13      | 206  | 135                                                                                | 10 / 120                                                                           |

| KT NO.  | Size mm | L mm |  |  |
|---------|---------|------|--------------------------------------------------------------------------------------|--------------------------------------------------------------------------------------|
| 1020-14 | 14      | 225  | 167                                                                                  | 10 / 120                                                                             |
| 1020-15 | 15      | 225  | 193                                                                                  | 6 / 72                                                                               |
| 1020-16 | 16      | 234  | 224                                                                                  | 6 / 72                                                                               |
| 1020-17 | 17      | 234  | 237                                                                                  | 4 / 48                                                                               |
| 1020-18 | 18      | 252  | 295                                                                                  | 4 / 48                                                                               |
| 1020-19 | 19      | 250  | 290                                                                                  | 4 / 48                                                                               |

## 1910

 - Double end flexible head wrench with 12 points thin wall socket
- 180° swivel head for better accessibility
- Chrome vanadium alloy steel
- Chrome plated

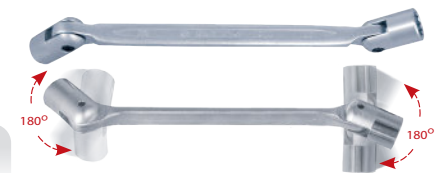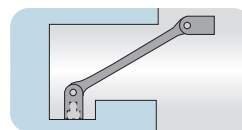

| KT NO.   | Size mm | L mm |  |  |
|----------|---------|------|-------------------------------------------------------------------------------------|-------------------------------------------------------------------------------------|
| 19100607 | 6 x 7   | 182  | 76                                                                                  | 12 / 216                                                                            |
| 19100809 | 8 x 9   | 182  | 81                                                                                  | 12 / 216                                                                            |
| 19100810 | 8 x 10  | 185  | 88                                                                                  | 10 / 160                                                                            |
| 19101011 | 10 x 11 | 200  | 109                                                                                 | 10 / 160                                                                            |
| 19101012 | 10 x 12 | 205  | 122                                                                                 | 10 / 120                                                                            |
| 19101213 | 12 x 13 | 220  | 158                                                                                 | 10 / 120                                                                            |
| 19101214 | 12 x 14 | 225  | 178                                                                                 | 10 / 80                                                                             |
| 19101415 | 14 x 15 | 240  | 232                                                                                 | 10 / 120                                                                            |
| 19101417 | 14 x 17 | 244  | 256                                                                                 | 10 / 120                                                                            |
| 19101617 | 16 x 17 | 259  | 317                                                                                 | 10 / 80                                                                             |

| KT NO.   | Size mm | L mm |  |  |
|----------|---------|------|---------------------------------------------------------------------------------------|---------------------------------------------------------------------------------------|
| 19101719 | 17 x 19 | 260  | 341                                                                                   | 10 / 80                                                                               |
| 19101819 | 18 x 19 | 275  | 393                                                                                   | 6 / 54                                                                                |
| 19101921 | 19 x 21 | 300  | 526                                                                                   | 6 / 36                                                                                |
| 19102022 | 20 x 22 | 305  | 579                                                                                   | 6 / 36                                                                                |
| 19102123 | 21 x 23 | 305  | 631                                                                                   | 6 / 36                                                                                |
| 19102427 | 24 x 27 | 335  | 797                                                                                   | 6 / 24                                                                                |

| KT NO. | PC. | Contents                                                |  |  |
|--------|-----|---------------------------------------------------------|-------------------------------------------------------------------------------------|--------------------------------------------------------------------------------------|
| 1B06MR | 6   | 1020 10, 12, 13, 14, 17, 19                             | 1.06                                                                                | 1 / 24                                                                               |
| 1A06MR | 6   | 1910 8 x 9, 10 x 11, 12 x 13, 14 x 15, 16 x 17, 18 x 19 | 1.49                                                                                | 1 / 16                                                                               |



► Nylon pouch bag