

Angled Socket Wrench & Set




1080



1081



- Angle and through-hole design
- Deep concave at one side and open end socket at the other, easily fit over protruding studs
- Chrome plated
- ISO 2236

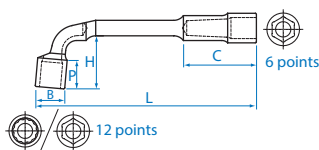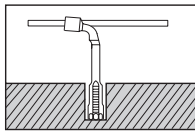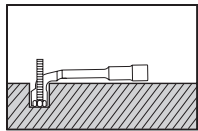

KT NO.	mm	B mm	P mm	H mm	C mm	L mm	g	kg
1080-06	6	11.0	7.0	18.5	29	110	43	12 / 240
1080-07	7	11.5	8.0	21.0	30.5	114	57	12 / 240
1080-08	8	13.0	10.0	21.5	30	120	68	12 / 216
1080-09	9	14.0	10.0	22.0	33	125	85	12 / 216
1080-10	10	15.0	11.0	25.5	35	131	102	6 / 60
1080-11	11	16.5	12.0	26.5	37	137	125	6 / 60
1080-12	12	17.5	12.0	27.0	40	144	143	6 / 60
1080-13	13	19.0	14.0	30.0	47	152.5	173	6 / 60
1080-14	14	20.0	14.0	33.0	48	160	191	6 / 60
1080-15	15	21.5	15.0	35.0	50	174	236	6 / 60
1080-16	16	22.5	17.0	39.5	54	185	281	6 / 60
1080-17	17	24.0	18.0	39.5	56	197	314	6 / 60
1080-18	18	25.0	19.5	42.0	58	211	336	4 / 40
1080-19	19	26.5	20.5	45.0	62	218	374	4 / 40
1080-20	20	27.5	21.5	45.0	63	222	445	2 / 20
1080-21	21	29.0	23.5	49.0	65	231	488	2 / 20
1080-22	22	30.0	23.5	49.0	67	247	537	2 / 16
1080-23	23	31.5	24.5	54.0	74	255	600	2 / 16
1080-24	24	32.5	25.5	56.0	77	266	657	2 / 16
1080-25	25	34.0	25.5	58.0	79	278	692	2 / 16
1080-26	26	35.0	25.5	59.0	80	289	863	2 / 16
1080-27	27	36.5	27.5	59.0	84	299	942	2 / 16
1080-28	28	37.5	27.5	60.0	86	310	1080	2 / 16
1080-29	29	39.0	28.5	62.0	90	319	1167	2 / 16
1080-30	30	40.0	28.5	65.0	93	332	1194	2 / 12
1080-32	32	42.5	28.5	69.0	95	353	1355	2 / 12

KT NO.	mm	B mm	P mm	H mm	C mm	L mm	g	kg
1081-06	6	11.0	7.0	18.5	29	110	44	12 / 240
1081-07	7	11.5	8.0	21.0	30.5	114	54	12 / 240
1081-08	8	13.0	10.0	21.5	30	120	69	12 / 216
1081-09	9	14.0	10.0	22.0	33	125	88	12 / 216
1081-10	10	15.0	11.0	25.5	35	131	105	6 / 60
1081-11	11	16.5	12.0	26.5	37	137	132	6 / 60
1081-12	12	17.5	12.0	27.0	40	144	148	6 / 60
1081-13	13	19.0	14.0	30.0	47	152.5	178	6 / 60
1081-14	14	20.0	14.0	33.0	48	160	185	6 / 60
1081-15	15	21.5	15.0	35.0	50	174	245	6 / 60
1081-16	16	22.5	17.0	39.5	54	185	285	6 / 60
1081-17	17	24.0	18.0	39.5	56	197	315	6 / 60
1081-18	18	25.0	19.5	42.0	58	211	355	4 / 40
1081-19	19	26.5	20.5	45.0	62	218	425	4 / 40
1081-20	20	27.5	21.5	45.0	63	222	441	2 / 20
1081-21	21	29.0	23.5	49.0	65	231	483	2 / 20
1081-22	22	30.0	23.5	49.0	67	247	589	2 / 16
1081-23	23	31.5	24.5	54.0	74	255	661	2 / 16
1081-24	24	32.5	25.5	56.0	77	266	658	2 / 16
1081-25	25	34.0	25.5	58.0	79	278	798	2 / 16
1081-26	26	35.0	25.5	59.0	80	289	825	2 / 16
1081-27	27	36.5	27.5	59.0	84	299	914	2 / 16
1081-28	28	37.5	27.5	60.0	86	310	1005	2 / 16
1081-29	29	39.0	28.5	62.0	90	319	1161	2 / 16
1081-30	30	40.0	28.5	65.0	93	332	1214	2 / 12
1081-32	32	42.5	28.5	69.0	95	353	1362	2 / 12



► MRN / SRN : Teton pouch bag



► MR / SR : Nylon pouch bag



► Color box



KT NO.	PC.	Contents	Package	g	kg
1805MR	5	10, 11, 13, 14, 17	Color box	1.12	1 / 22
1808MR	8	8, 10, 11, 12, 13, 14, 17, 19	Nylon	1.73	1 / 18
1812MR	12	8, 10, 11, 12, 13, 14, 16, 17, 18, 19, 22, 24	Nylon	3.38	1 / 4
1826MR	26	6, 7, 8, 9, 10, 11, 12, 13, 14, 15, 16, 17, 18, 19, 20, 21, 22, 23, 24, 25, 26, 27, 28, 29, 30, 32	Color box	14.0	1 / 2
1912MR	12	8, 10, 11, 12, 13, 14, 16, 17, 18, 19, 22, 24	Nylon	3.38	1 / 4
1912MRN	12	8, 10, 11, 12, 13, 14, 16, 17, 18, 19, 22, 24	Teton	3.38	1 / 4
1926MR	26	6, 7, 8, 9, 10, 11, 12, 13, 14, 15, 16, 17, 18, 19, 20, 21, 22, 23, 24, 25, 26, 27, 28, 29, 30, 32	Color box	15.0	1 / 2



WRENCHES