

Hex Key Set

20208MR01

20208SR01

20210MR

8
PC.

KT NO.	Spec.	Contents	Kg	1.25	1 / 20
20208MR01	Extra long arm	1125MR H3, H4, H5, H6, H8, H10, H12, H14			
20208SR01		1125SR 1/8, 5/32, 3/16, 1/4, 5/16, 3/8, 1/2, 9/16			

10
PC.


Metal case size (mm) :
372 x 153 x 40 (0.08 cuft)

Spec.	Contents	Kg	3.03	1 / 6
Extra long arm	1125MR	H3, H4, H5, H6, H7, H8, H10, H12, H14, H17		

L- wrench Set With Display Stnad

2020H0MR

- 5mm durable acrylic sheets to increase structural strength
- Transparent design for demonstrating product feature
- Great capacity, suitable for multi-size
- Size : 220 x 260 x 270mm

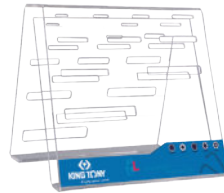

KT NO. 87125

80
PC.

Spec.	Contents	Kg	7.68	1 / 4	Each Q'ty
Extra long arm	1125MR	H2, H2.5, H3, H4, H5, H6, H7, H8, H10, H12			8

Spline L- wrench & Set

1146MR

- Standard arm type
- For spline head screw



KT NO.	Size	mm	mm	Kg	20 / 320
114605MR	M5	29	83	15	20 / 320
114606MR	M6	33	90	24	20 / 320
114608MR	M8	39	98	47	10 / 300
114610MR	M10	44	111	82	10 / 200
114612MR	M12	53	126	127	10 / 180

1126MR

- Extra long arm type



KT NO.	Size	mm	mm	Kg	20 / 300
112605MR	M5	33	165	29	20 / 300
112606MR	M6	38	186	47	20 / 300
112608MR	M8	44	208	91	10 / 100
112610MR	M10	50	234	160	10 / 100
112612MR	M12	53	264	239	10 / 80

20505PR01

20515PR01

5
PC.

KT NO.	Spec.	Contents	Kg	6 / 54
20505PR01	Standard arm type	1146MR M5, M6, M8, M10, M12	0.33	6 / 54
20515PR01	Extra long arm type	1126MR M5, M6, M8, M10, M12	0.63	4 / 32