

Groove Joint Pliers

6511



- 7 positions opening
- DIN ISO 8976



 
KT NO.	inch	L mm	mm	A mm	B mm	kg	Box	Case
6511-10	10	253	50	33	50	435	6 / 48	
6511-10C	10	253	50	33	50	400	6 / 48	
6511-13C	13	325	65	43	50	808	2 / 16	
6511-17C	17	425	100	58	55	1150	2 / 12	



6511-10



6511C




Bolt Cutter

6131

GS / TUV

- Chrome vanadium alloy steel
- Center cut

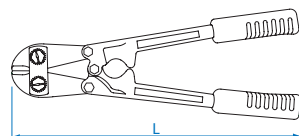

KT NO.	inch	L mm	Cutting capacity 15°(ø mm) HRC	Cutting capacity 35°(ø mm) HRC	kg	Box	Case
6131-12	12	300	ø5	ø4	0.74	1 / 20	
6131-14	14	350	ø7	ø5	1.04	1 / 20	
6131-18	18	450	ø8	ø6	1.45	1 / 12	
6131-24	24	600	ø10	ø8	2.32	1 / 10	
6131-30	30	750	ø13	ø10	3.74	1 / 6	
6131-36	36	900	ø16	ø11	5.50	1 / 5	
6131-42	42	1050	ø18	ø13	8.56	1 / 3	

6131P01

- Spare blade for 6131
- Center cut




KT NO.	Overall length mm	Cutting capacity 15°(ø mm) HRC	Cutting capacity 35°(ø mm) HRC	kg	Box	Case
6131-12P01	95 x 57	ø5	ø4	0.26	1 / 40	
6131-14P01	110 x 65	ø7	ø5	0.40	1 / 40	
6131-18P01	125 x 72	ø8	ø6	0.85	1 / 20	
6131-24P01	150 x 86	ø10	ø8	0.87	1 / 20	
6131-30P01	170 x 97	ø13	ø10	1.25	1 / 10	
6131-36P01	190 x 112	ø16	ø11	1.85	1 / 10	
6131-42P01	205 x 122	ø18	ø13	3.10	1 / 5	

Compact Bolt Cutter

6133

 - Heavy duty type
- DIN ISO 5749
- Center cut



KT NO.	inch	L mm	ø mm	Cutting capacities ø mm	ø mm	ø mm	kg	Box	Case
6133-08	8	200	6.0	5.0	4.0	3.5	399.6	8 / 48	