
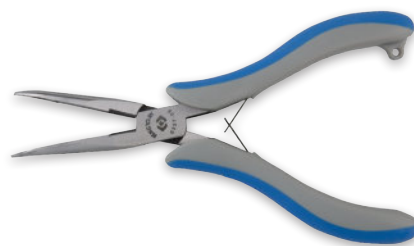
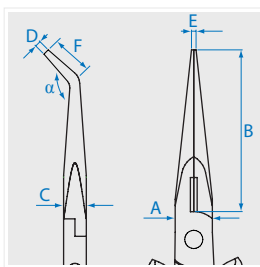


Precision Pliers

6337-06




 Bent nose pliers

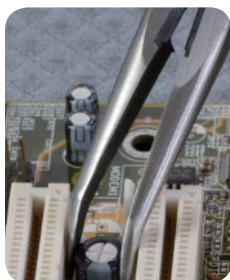

KT NO.	Overall length inch	mm	Cutting capacities ⌀ mm	mm	α	A mm	B mm	C mm	D mm	E mm	F mm		
6337-06	6	154	2.0	1.6	40°	11.3	50	7.5	2	2.5	14	84	6 / 120

6347-05




 Round-nose pliers

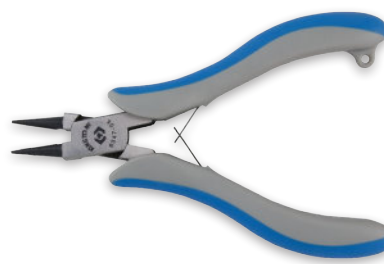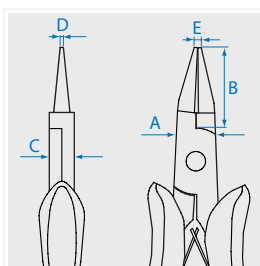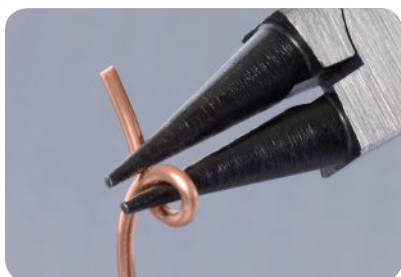

KT NO.	Overall length inch	mm	A mm	B mm	C mm	D mm	E mm		
6347-05	5	128	11.4	24.9	7.5	1	2.14	74	6 / 120

63A7-05




 Round-nose pliers

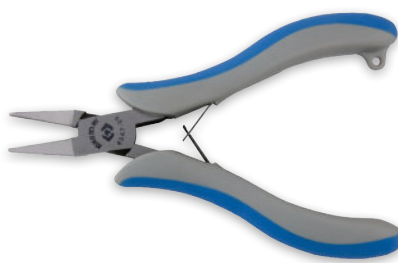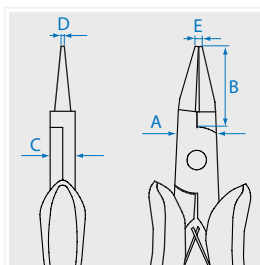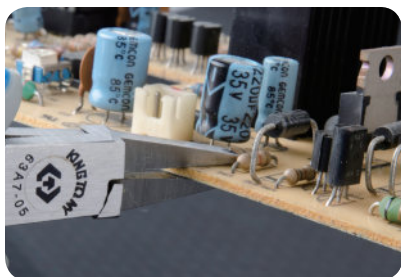

KT NO.	Overall length inch	mm	A mm	B mm	C mm	D mm	E mm		
63A7-05	5	128	11.5	24.7	7.5	3.3	1.8	75	6 / 120

63B7-05

 Round-nose pliers

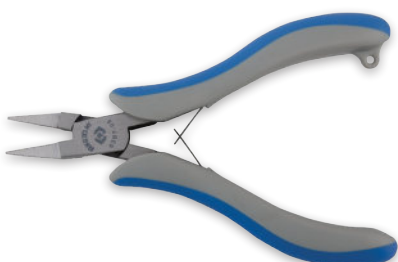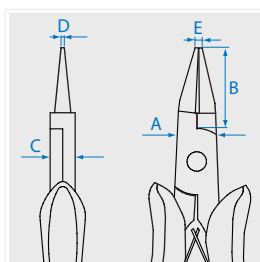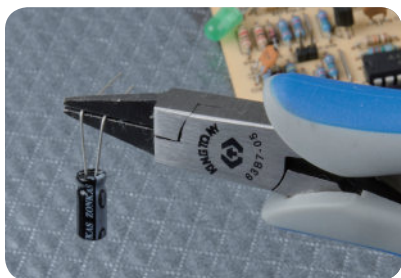

KT NO.	Overall length inch	mm	A mm	B mm	C mm	D mm	E mm		
63B7-05	5	128	11.5	24.7	7.5	1.3	1.8	74	6 / 120

