


Offset Combination Wrench & Set

1063

- Chrome vanadium alloy steel
- Offset ring ideal for deep-seated nuts or bolts
- 15° open end angle
- Chrome plated
- Metric - DIN 3113 from B, ISO 7738, ISO 3318

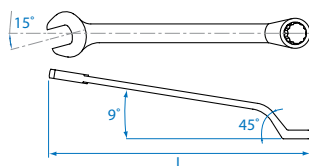


KT NO.	Size mm	L mm		
1063-06	6	110	17	20 / 360
1063-08	8	130	32	20 / 320
1063-11	11	160	50	20 / 320
1063-12	12	170	73	20 / 240
1063-14	14	190	93	15 / 240
1063-15	15	200	105	15 / 180
1063-16	16	210	118	15 / 180
1063-17	17	220	128	15 / 120

5063

KT NO.	Size mm	L mm		
1063-18	18	230	165	12 / 96
1063-21	21	260	226	10 / 80
1063-22	22	270	252	10 / 80
1063-27	27	320	448	6 / 48
1063-30	30	350	535	6 / 48
1063-32	32	370	596	6 / 48
KT NO.	Size inch	L mm		
5063-14	7/16	160	59	20 / 320
5063-16	1/2	180	78	20 / 240
5063-18	9/16	190	103	15 / 240

1067

- Chrome vanadium alloy steel
- Offset ring ideal for deep-seated nuts or bolts
- 15° open end angle
- Chrome plated
- DIN 3113 from B, ISO 7738, ISO 3318

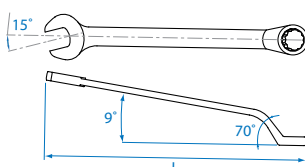

KT NO.	Size mm	L mm		
1067-06	6	105	18	10 / 640
1067-07	7	115	23	10 / 640
1067-08	8	125	32	10 / 640
1067-09	9	135	37	10 / 480
1067-10	10	145	45	6 / 288
1067-11	11	155	56	12 / 240
1067-12	12	165	61	10 / 200
1067-13	13	175	73	8 / 160
1067-14	14	185	96	10 / 160
1067-15	15	195	105	10 / 160
1067-16	16	205	122	10 / 160
1067-17	17	215	138	8 / 128
1067-18	18	225	161	12 / 144

KT NO.	Size mm	L mm		
1067-19	19	235	192	10 / 120
1067-20	20	235	256	10 / 80
1067-21	21	265	248	10 / 80
1067-22	22	265	252	10 / 80
1067-23	23	290	316	8 / 64
1067-24	24	290	307	8 / 64
1067-25	25	300	327	10 / 60
1067-26	26	320	423	10 / 40
1067-27	27	320	402	10 / 40
1067-28	28	330	494	10 / 40
1067-29	29	350	402	6 / 48
1067-30	30	350	522	6 / 48
1067-32	32	370	621	4 / 32



► MRN / SRN : Teton pouch bag



► MR / SR : Nylon pouch bag

KT NO.	PC.	Contents	Package		
1271MR	11	6, 8, 9, 10, 11, 12, 13, 14, 17, 19, 22	Nylon	1.23	1 / 15
1271MRN	11		Teton		
1272MR	12	6, 7, 8, 9, 10, 11, 12, 13, 14, 17, 19, 22	Nylon	1.21	1 / 15
1275MR	15		Nylon		
1275MRN	15	6, 7, 8, 10, 11, 12, 13, 14, 17, 19, 22, 24, 27, 30, 32	Teton	3.3	1 / 8
1266MR	26		Nylon		
		6, 7, 8, 9, 10, 11, 12, 13, 14, 15, 16, 17, 18, 19, 20, 21, 22, 23, 24, 25, 26, 27, 28, 29, 30, 32		6.85	1 / 2