 


Star Box End Wrench & Set

1920

- Chrome vanadium alloy steel
- Chrome plated
- ANSI / ASME B107.6



KT NO.	Size	L mm		
19200608	E6 x E8	114.0	21	12 / 504
19200711	E7 x E11	126.5	31	12 / 504
19201012	E10 x E12	142.5	43	12 / 384
19201418	E14 x E18	183.0	90	12 / 240
19201622	E16 x E22	205.0	114	12 / 192
19202024	E20 x E24	225.0	159	12 / 144

1406PR

Metal case size (mm):
280 x 130 x 41 (0.053 cuft)



6
PC.

Contents


0.46 1 / 15

1920 E6 x E8, E7 x E11, E10 x E12, E14 x E18,
E16 x E22, E20 x E24

Flare Nut Wrench

1930

- 6 points
- 12° ring offset
- Chrome vanadium alloy steel
- Chrome plated
- Metric - DIN 3118
- Inch - ANSI / ASME B107.6

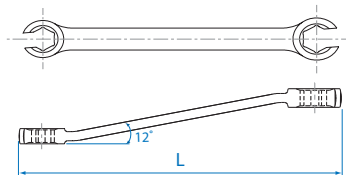

KT NO.	Size mm	L mm		
19300810	8 x 10	130	56	12 / 216
19300911	9 x 11	150	74	12 / 216
19301011	10 x 11	150	76	12 / 192
19301012	10 x 12	150	73	12 / 192
19301113	11 x 13	170	96	12 / 144
19301213	12 x 13	170	102	12 / 144
19301214	12 x 14	170	100	12 / 144
19301315	13 x 15	178	122	12 / 144
19301417	14 x 17	190	138	12 / 144
19301719	17 x 19	210	170	8 / 128
19301922	19 x 22	230	245	9 / 108

5930



KT NO.	Size inch	L mm		
59301012	5/16 x 3/8	130	60	12 / 216
59301214	3/8 x 7/16	150	76	12 / 192
59301618	1/2 x 9/16	180	125	12 / 144
59301820	9/16 x 5/8	190	169	12 / 144
59302224	11/16 x 3/4	210	184	6 / 96
59302428	3/4 x 7/8	230	249	6 / 72



► MRN / SRN : Teton pouch bag



► MR / SR : Nylon pouch bag

KT NO.	PC.	Contents	Package		
1306MR	6	8 x 10, 10 x 12, 11 x 13, 12 x 14, 17 x 19, 19 x 22	Nylon	0.90	1 / 30
1306MRN	6	1930	Teton	0.90	1 / 30
1306SR	6	5/16 x 3/8, 3/8 x 7/16, 1/2 x 9/16, 9/16 x 5/8, 11/16 x 3/4, 3/4 x 7/8	Nylon	0.86	1 / 30
1306CR	6	1930	Nylon	0.74	1 / 12
		5930			