


## FLEXIMARK® Collar Snap-on

FLEXIMARK® collars for marking single cores before or after assembly.

### Info

Mounting after installation possible by snap-on mechanism

Snap-On 2-3,5/15 included in FLEXIMARK® sample bag (article no. M3251010)

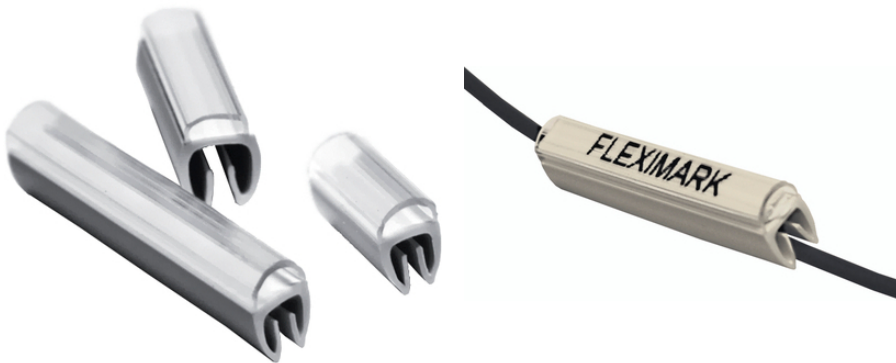

Flame-retardant



Halogen-free

### Benefits

Enhanced scratch-protection

Resistant and flexible protection

Resistant to chemicals, UV-light, moisture and oils (diesel oil, basic cleaning agent, sea water, ethanol,...)

### Product features

Extremely flame-retardant according to  
UL 94 V0

### Note

Suitable marking collar for LMB labels

### Included

Marking collars without labels

### Technical Data

Classification ETIM 5:

ETIM 5.0 Class-ID: EC002248

ETIM 5.0 Class-Description: Mounting for labelling material

Classification ETIM 6:

ETIM 6.0 Class-ID: EC002248

ETIM 6.0 Class-Description: Mounting for labelling material

Colour delivered:

Transparent

Material:

Halogen-free polyethylene

Temperature range:

-40 °C to +80 °C

Last Update (22.01.2021)

©2021 Lapp Group - Technical changes reserved

Product Management [www.lappkabel.de](http://www.lappkabel.de)

You can find the current technical data in the corresponding data sheet.

PN 0456 / 02\_03.16

## **FLEXIMARK® Collar Snap-on**

### **Note**

Photographs and graphics are not to scale and do not represent detailed images of the respective products.

Prices are net prices without VAT and surcharges. Sale to business customers only.

FLEXIMARK® products are sold in packaging units. As example if you like to order 640 labels of LCK 32 you just need to order 1 PU instead of 640 single labels.

**FLEXIMARK® Collar Snap-on**

| Article number            | Article designation                     | Length (mm) | For cable Ø (mm) | Markers / PU | PU |
|---------------------------|-----------------------------------------|-------------|------------------|--------------|----|
| FLEXIMARK® Collar Snap-on |                                         |             |                  |              |    |
| 83252650                  | FLEXIMARK® collar SnapOn<br>2-3.5/10 TR | 10          | 2 - 3.5          | 1000         | 1  |
| 83252651                  | FLEXIMARK® collar SnapOn<br>2-3.5/15 TR | 15          | 2 - 3.5          | 1000         | 1  |
| 83252695                  | FLEXIMARK® collar SnapOn<br>2-3.5/23 TR | 23          | 2 - 3.5          | 500          | 1  |
| 83252653                  | FLEXIMARK® collar SnapOn<br>2.8-5/10 TR | 10          | 2.8 - 5          | 1000         | 1  |
| 83252654                  | FLEXIMARK® collar SnapOn<br>2.8-5/15 TR | 15          | 2.5 - 5          | 1000         | 1  |
| 83252656                  | FLEXIMARK® collar SnapOn<br>5-8/10 TR   | 10          | 5 - 8            | 500          | 1  |
| 83252657                  | FLEXIMARK® collar SnapOn<br>5-8/15 TR   | 15          | 5 - 8            | 500          | 1  |
| 83252660                  | FLEXIMARK® collar SnapOn<br>8-10/15 TR  | 15          | 8 - 10           | 500          | 1  |

Last Update (22.01.2021)

©2021 Lapp Group - Technical changes reserved

Product Management [www.lappkabel.de](http://www.lappkabel.de)

You can find the current technical data in the corresponding data sheet.

PN 0456 / 02\_03.16