



Flat Cat.8 Patch Cable

Flat Cat.8 *Patch Cable*



40Gbps
2000MHz

Flat cable design
convenient wiring

Oxygen-free
copper core twisted
anti-interference

Match steel+
copper-plated
shield shell

Surf the Net at Maximum Speeds

Type	Transmission rate	Frequency bandwidth	Distance	Standard
Cat.8	40Gbps	2000MHz	30m	SSTP
Cat.7	10Gbps	600MHz	100m	SSTP
Cat.6A	10Gbps	500MHz	100m	STP/UTP
Cat.6	1000Mbps	250MHz	100m	STP/UTP
Cat.5e	100Mbps	155MHz	100m	STP/UTP
Cat.5	100Mbps	100MHz	100m	STP/UTP

Note: The above are theoretical data. The actual usage data may be limited by the equipment environment such as routers, switches, and network vendors.

40Gbps Transmission Rate 2000MHz Frequency Bandwidth

Easily control large online game,
without delaying watching videos
and downloading at higher speeds

40
Gbps

2000
MHz



Smooth



Delay

Convenient Wiring

Flat cable design, suitable for tiled ground, tabletop, corner,
More reasonable and comfortable integration with the home environment




Flat cable
design

Oxygen Free Copper Core


4 twisted pairs resist external electromagnetic interference

30
AWG

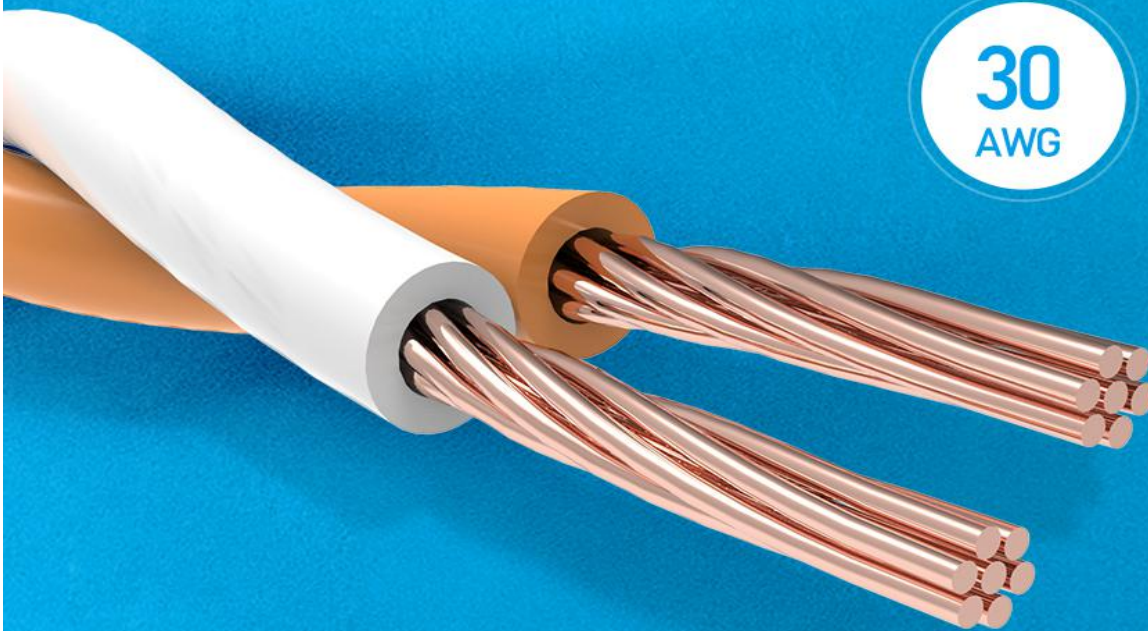


Aluminum Foil Shield

Ensure stable network

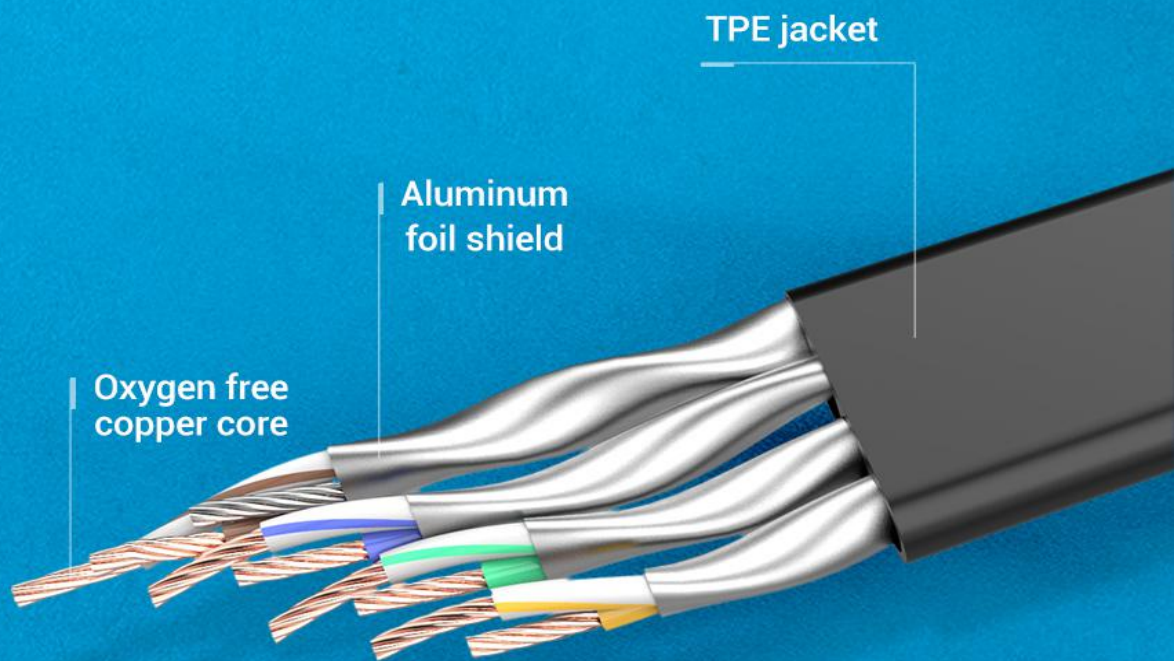

Private Appearance


—
Beauty of mechanics

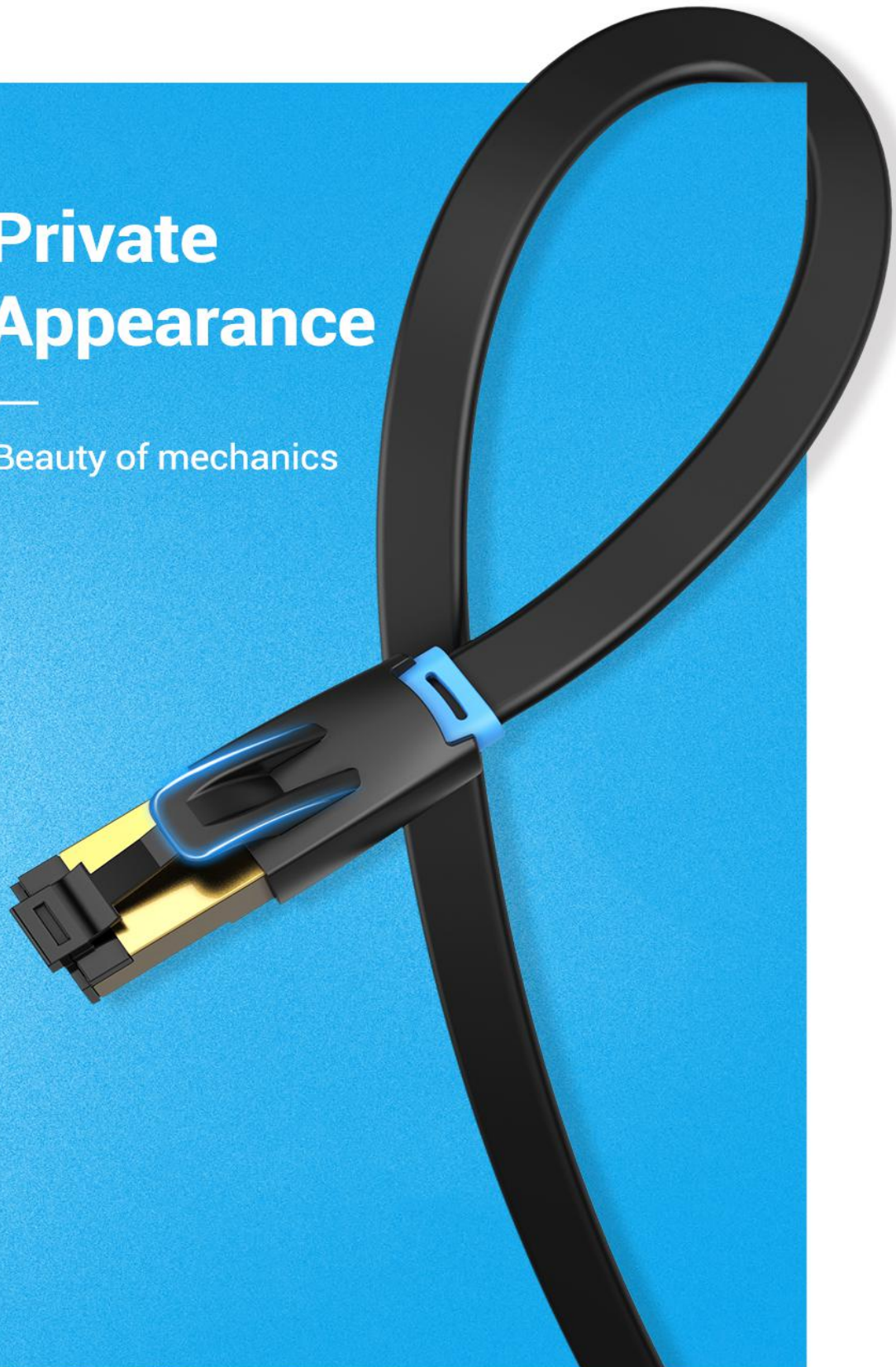

Net Tail Anti-fracture



Environmentally Friendly TPE Jacket


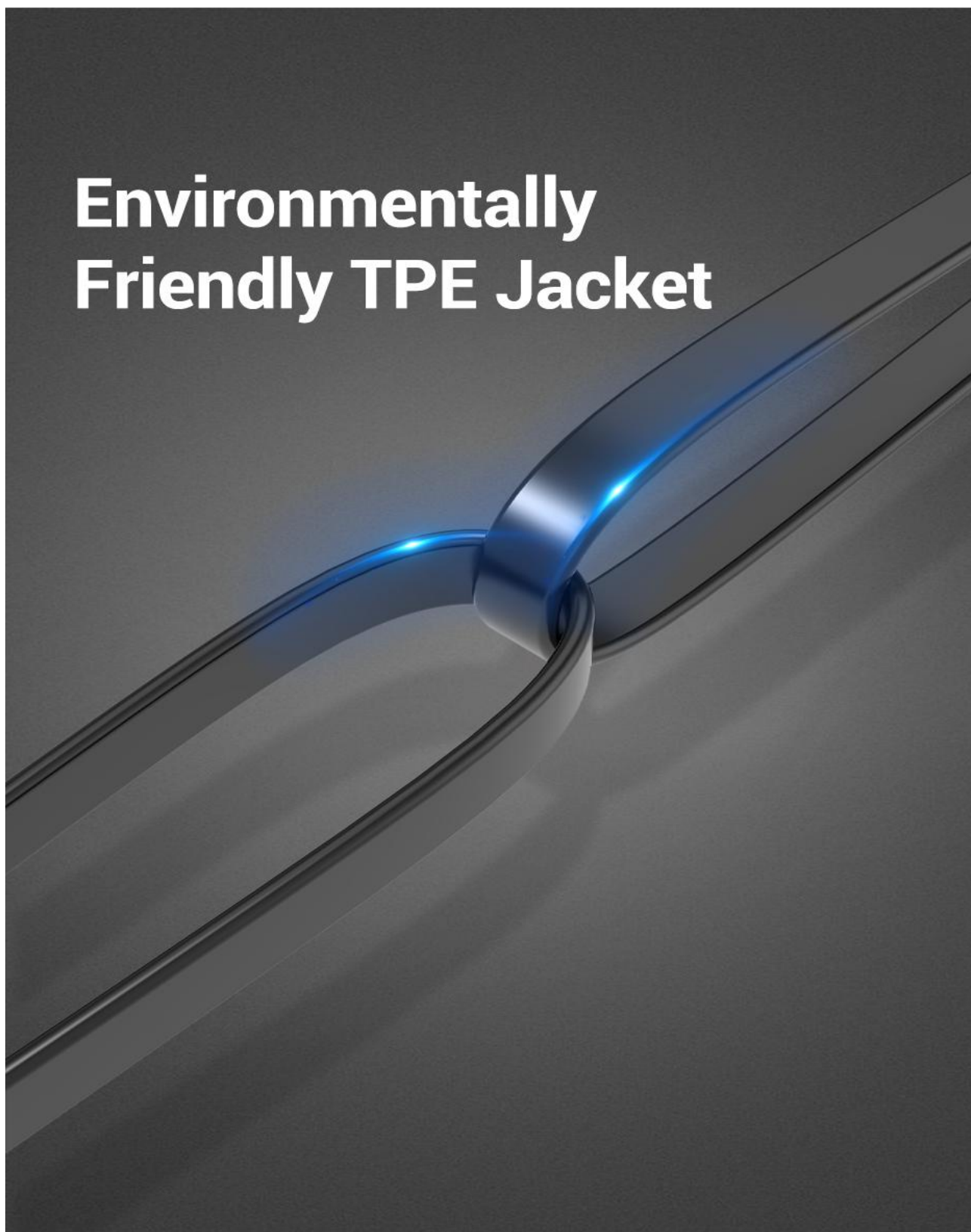


Match Steel+Copper -plated Shield Shell


—
Match Steel+Copper-plated



Gold-plated Contacts Trigeminal Chip

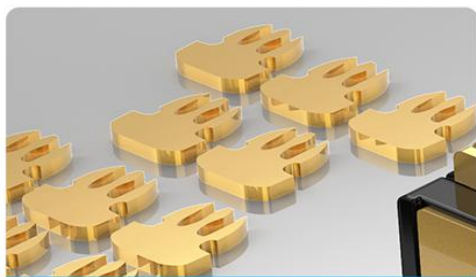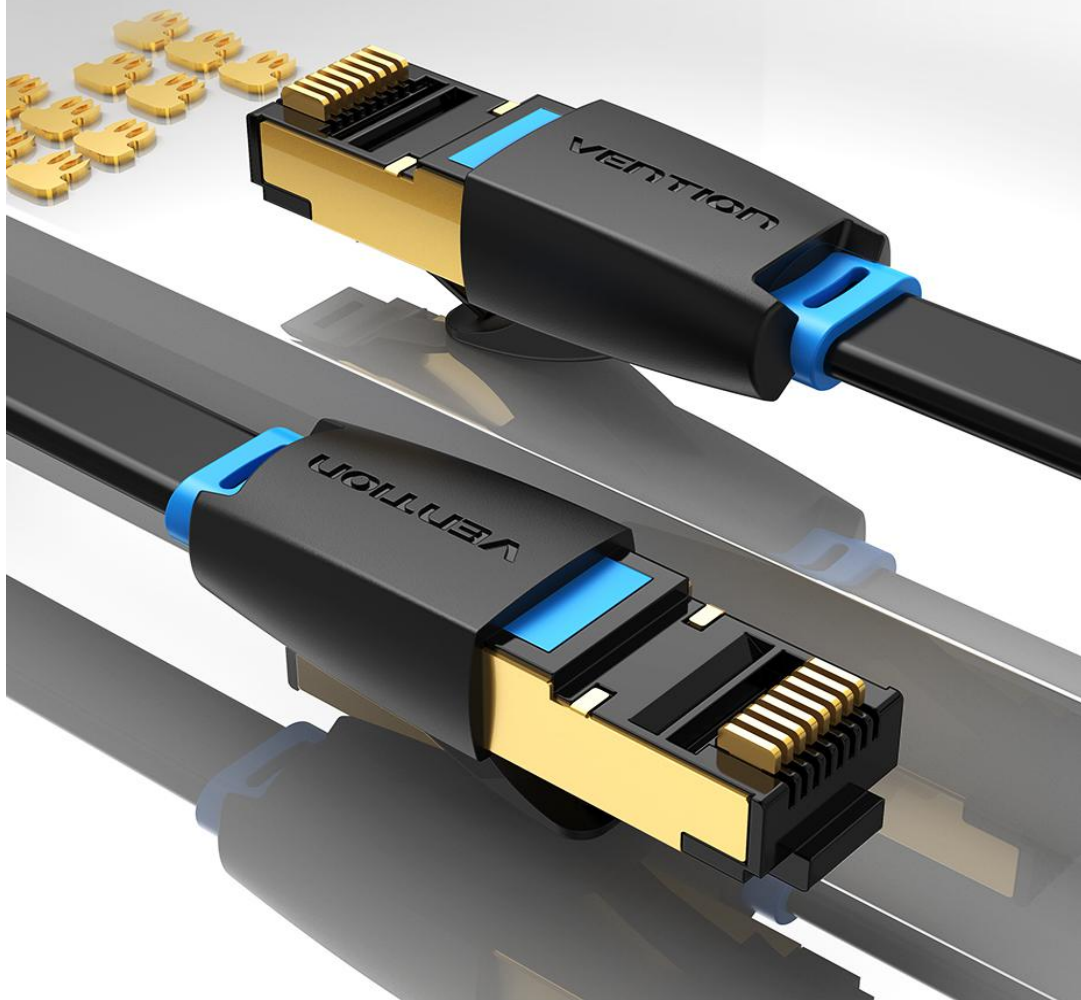

Three-pronged chip

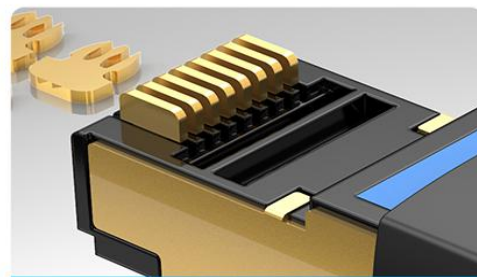

Gold-plated contacts

Multiple Devices and Scenes



Home / Office



Internet Cafe / Community



Supermarket /
Department Store



KTV / Club




Hotel



School / Building


FLUKE Network Test

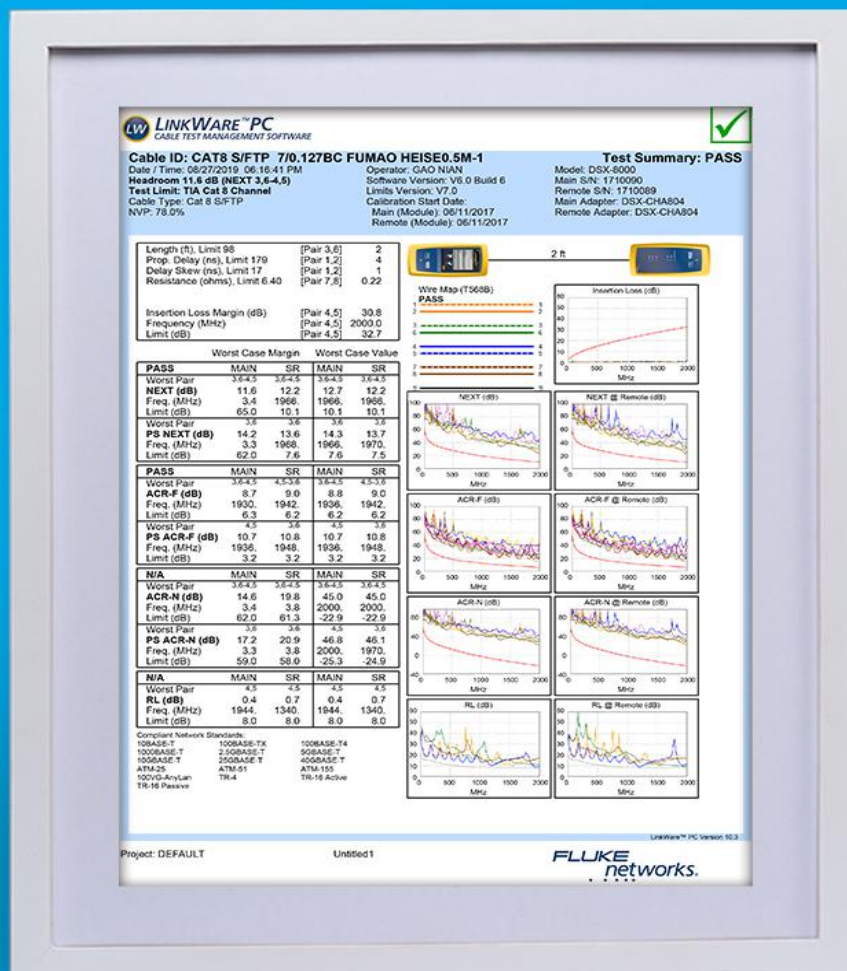

Product Parameters


Brand: Vention	Conductor: Oxygen-free Copper
Name: Flat Cat.8 Patch Cable	Shield Shell: Match Steel+Copper-plated
Model: IKC	Shielding: Aluminum Foil
Color: Black	Jacket: TPE
Inrerface: Cat.8/RJ45/8P8C	AWG: 30AWG
Body Technics: PVC	OD: 2.7*8.5mm
Transmission Rate: 40Gbps	Length: 0.5/1/1.5/2/3/5/8m
Transmission Bandwidth: 2000MHz	Warranty: 1 Year
Connector Chips Technics: Three-pronged Gold-plated Chip	

Packing: PE Bag

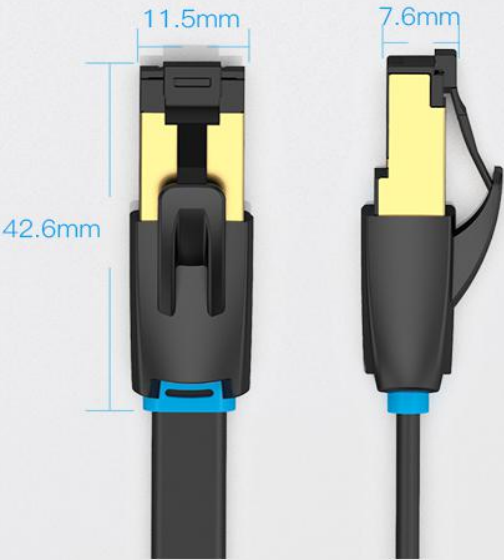

Note:All data are from Vention lab.
Sizes above are hand measurement, there might be slight tolerance.

Length	Art.No.	EAN Code
0.5	IKCBD	6922794743755
1m	IKCBF	6922794743762
1.5m	IKCBG	6922794743779
2m	IKCBH	6922794743786
3m	IKCBI	6922794743793
5m	IKCBJ	6922794743809
8m	IKCBK	6922794743816

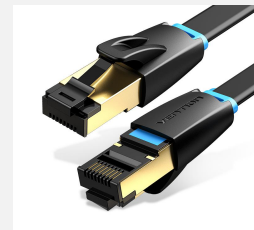

Package Contents

Patch Cable x 1

Packaging Information

Packing Dimension	mm
Packing Weight	kg
Carton Dimension	48*29*30mm
Carton Qty	200pcs(0.5m) 200pcs (1m) 150pcs(1.5m) 150pcs(2m) 150pcs(3m) 90pcs(5m) 60pcs(8m)
Carton Weight	4kg (0.5m)
Package	PE bag

www.ventioncable.com