

Cat.7 SSTP Patch Cable



Super Speed of Cat.7 Network Cable

	Transmission Rate	Bandwidth
Cat.7	10Gbps	600MHz
Cat.6	1Gbps	250MHz
Cat.5E	100Mbps	155MHz

Note:All data are from Vention Lab.



More stable
in game



Faster
downloading



Smoother in
watching films






Enjoy Game and Film

Fast respond to network enviroment such as playing large games and watching HDTV


Metal Weaving+Aluminum Foil

- ① Aluminum foil on each two cores to form four pairs of aluminum foil package precision anti-interference with shielding protection
- ② Woven mesh is densely wrapped in mesh, with shielding protection

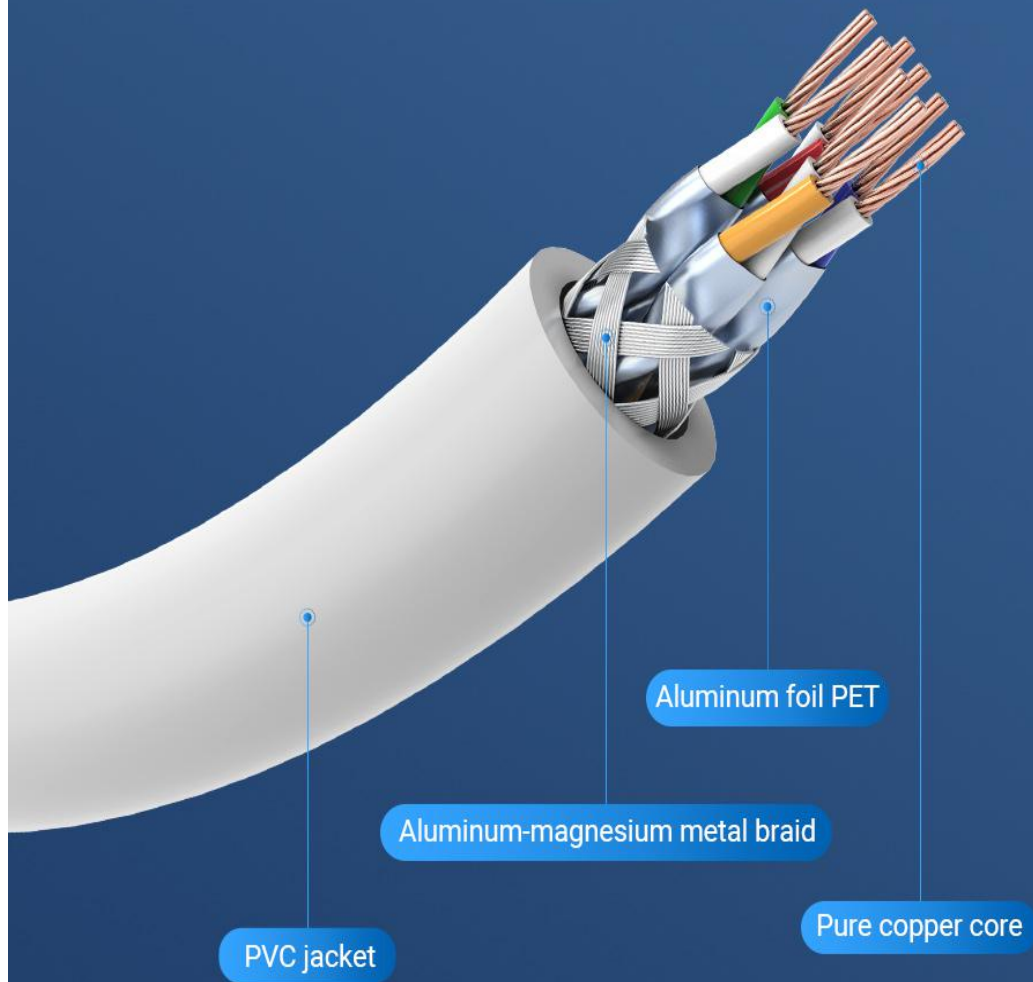


Pure Copper Core Twisted Structure

Twisted copper core protects cable from external electro-magnetic interference to enhance signal stability

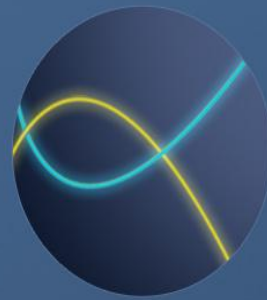


Twisted structure

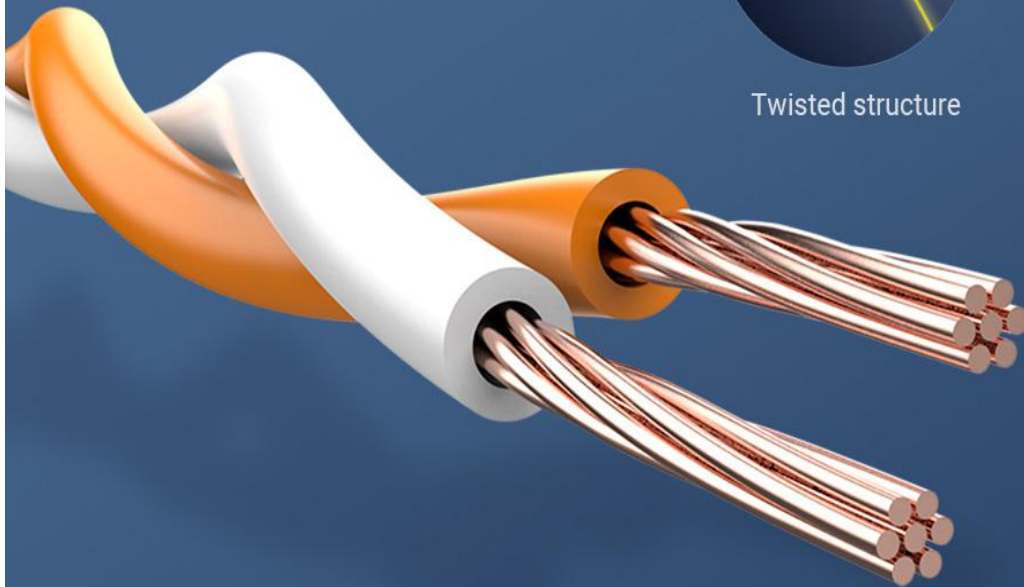


Metal Shielded Crystal Head


Trigeminal chip gold-plated contacts

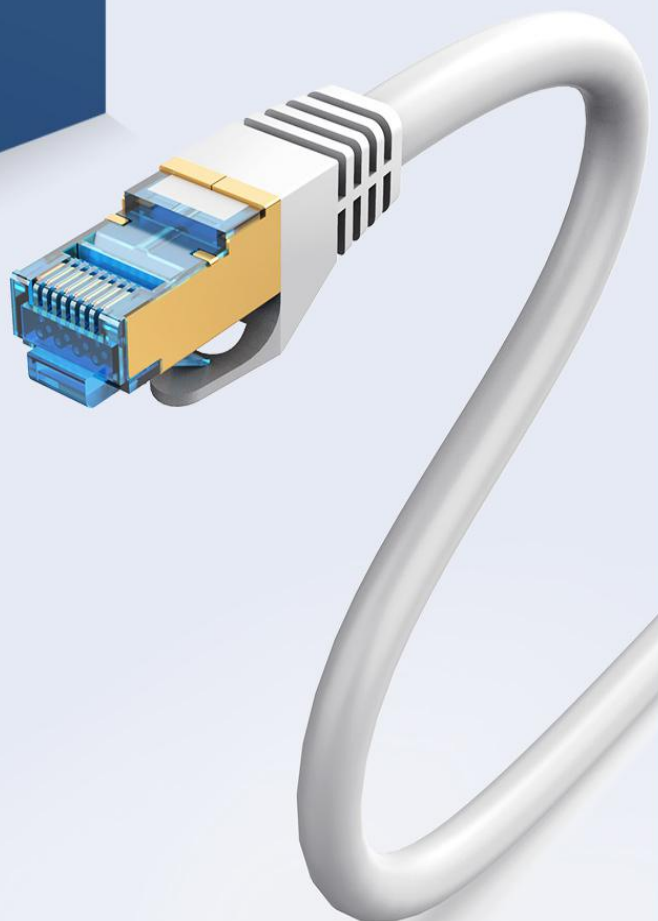

Metal shell wrapping
anti-interference
and pluggable

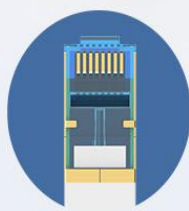

Pure copper
plated contacts
stable signal

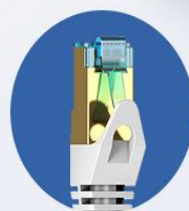

Widened
compression piece
easy to use

Durable Anti-folding Tail Design

Ted injection molding process, high-tough mesh tail
non-slip, wear-resistant




Soft PVC Fireproof and Moistureproof

Soft PVC material , durable to use



Wide Applicability

Compatible with RJ45 network port

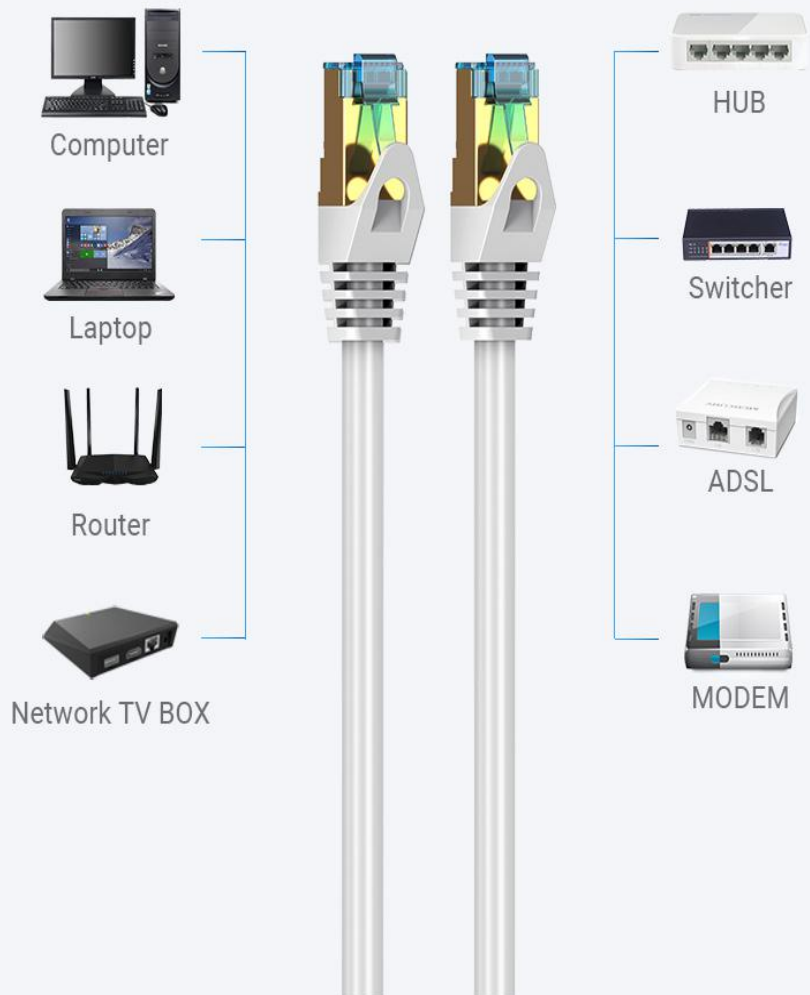

Applicable Scene




Office



Home



Net Bar

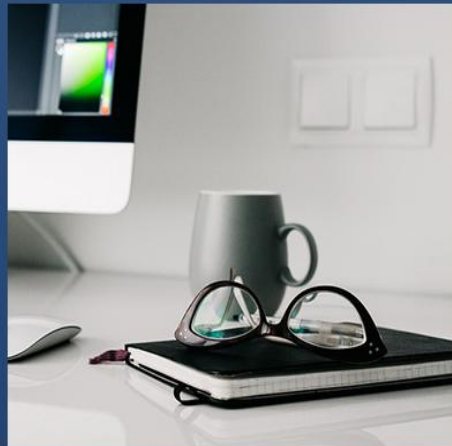

Hotel


Product Parameters

Brand: Vention	Shield Shell: Gold-plated Iron Shell
Name: Cat.7 SFTP Patch Cable	Shielding: Aluminum Foil + Braid
Model: ICE	Jacket: PVC
Color: Gray	AWG: 26AWG
Interface: RJ45	OD: 6.0mm
Version: Cat.7	Length: 0.75-20m
Body Technics: PC	Warranty: 1 Year
Conductor: Pure Copper	Packing: PE Bag/Kraft Box
Connector Chips Technics: Three-pronged Gold-plated 3U Chip	



Note: All data are from Vention Lab.
Sizes above are manually measured. There might be slight tolerance.

Length	Art.No.	EAN Code
0.75m	ICEHE	6922794743823
1m	ICEHF	6922794743830
1.5m	ICEHG	6922794743847
2m	ICEHH	6922794743854
3m	ICEHI	6922794743861
5m	ICEHJ	6922794743878
10m	ICEHL	6922794743885
15m	ICEHN	6922794743892
20m	ICEHQ	6922794743908

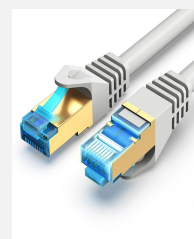

Package Contents

Patch Cable x 1

Packaging Information

Packing Dimension	mm
Packing Weight	kg
Carton Dimension	48*29*30mm
Carton Qty	100pcs(0.75m) 100pcs (1m) 100pcs(1.5m) 80pcs(2m) 60pcs(3m) 50pcs(5m) 30pcs(10m) 25pcs(15m) 28pcs(20m)
Carton Weight	4kg (0.75m)
Package	PE bag

www.ventioncable.com