



DVI(24+5) to VGA Cable

DVI 24+5 Standard Male



DVI 24+5 female




DVI 24+1 female



DVI 18+1 female

1080P HD Picture Quality

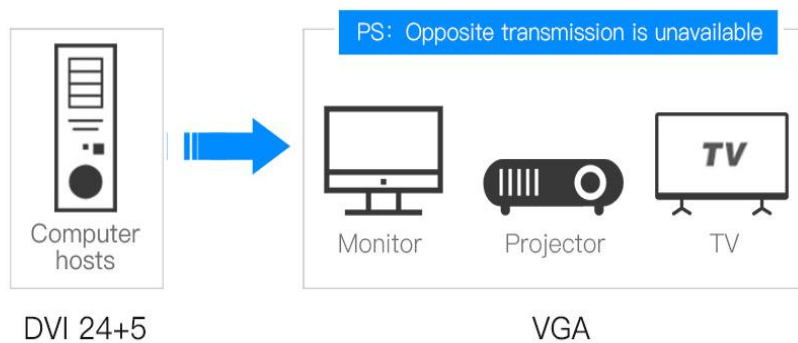


Dual Magnetic Ring Anti-interference

Anhydrous
ripple

PVC section	Length	Wire gauge	Wire diameter	Strengthen the configuration
	1-10m	30AWG	7.3mm	Double magnetic ring

Reinforced SR, No Break

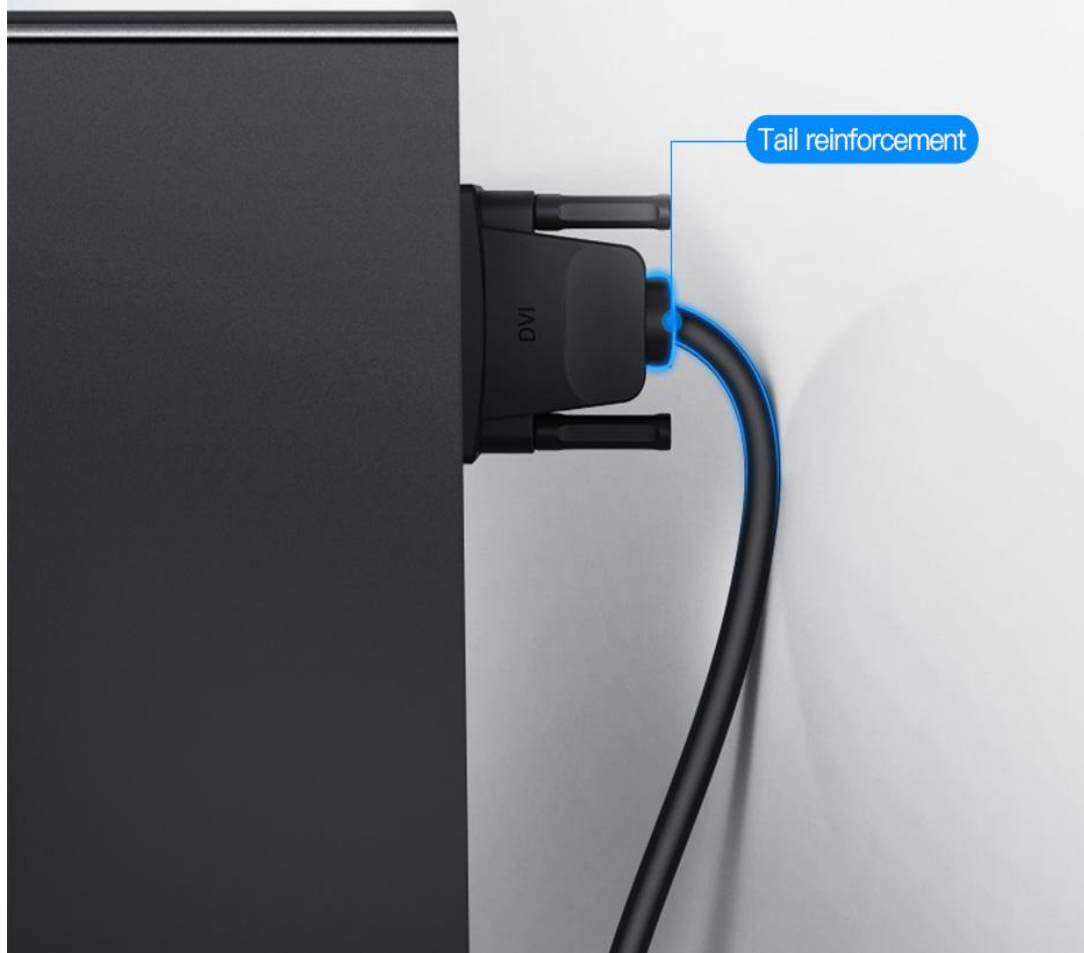

Anti-stretch Material Durable




Interface/Pin, No Rust



Anti-rust gold
plating process

Two Modes

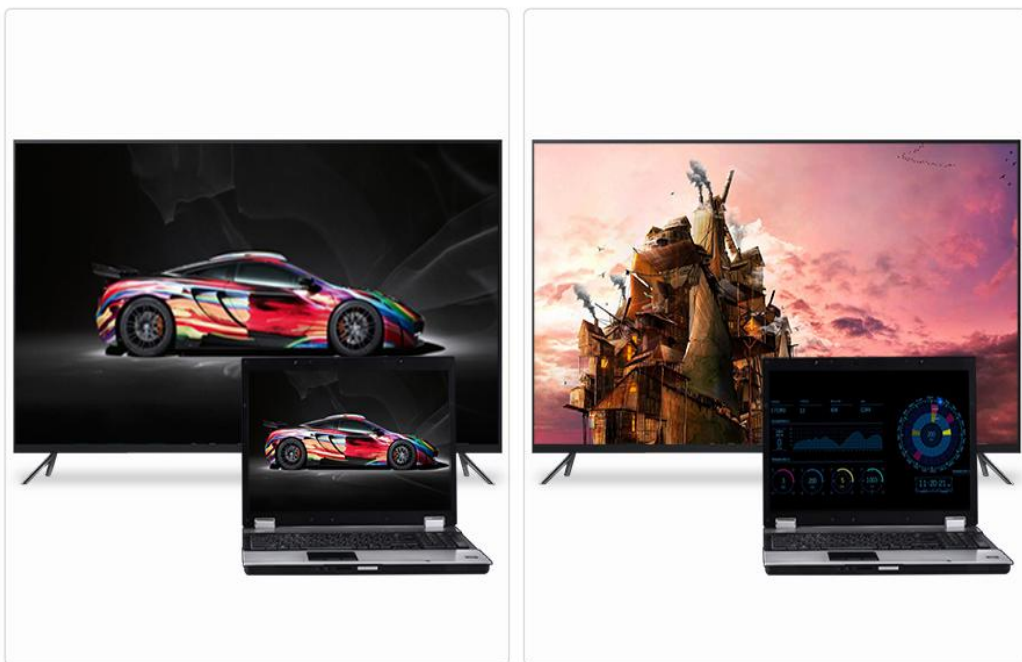

① Mirror Mode

Enjoy large screen for video and image


② Extended Mode

Work and entertainment at the same time


Ergonomic Design


Plugging
effortless

Ergonomic design

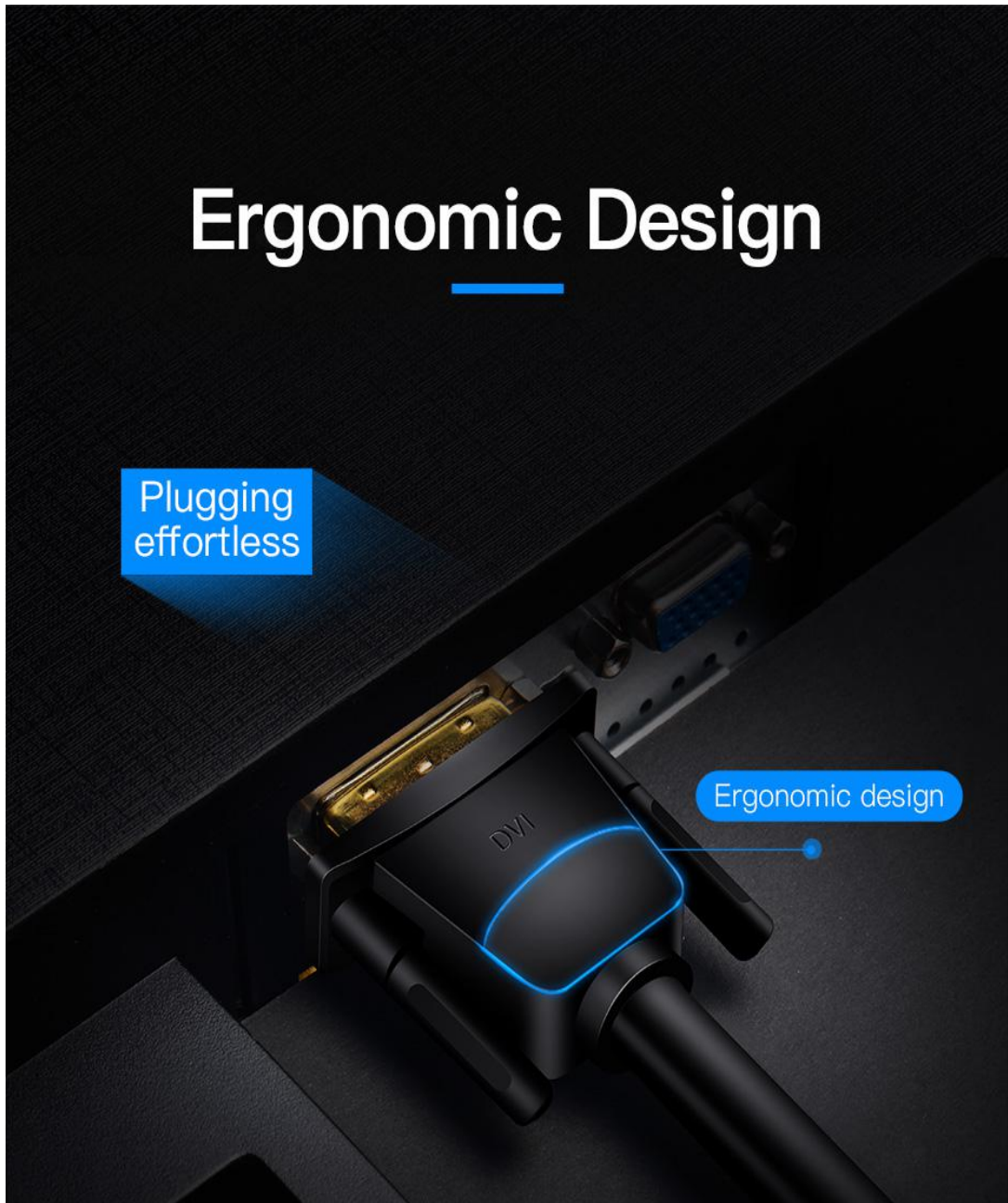

No ghosting, No splash

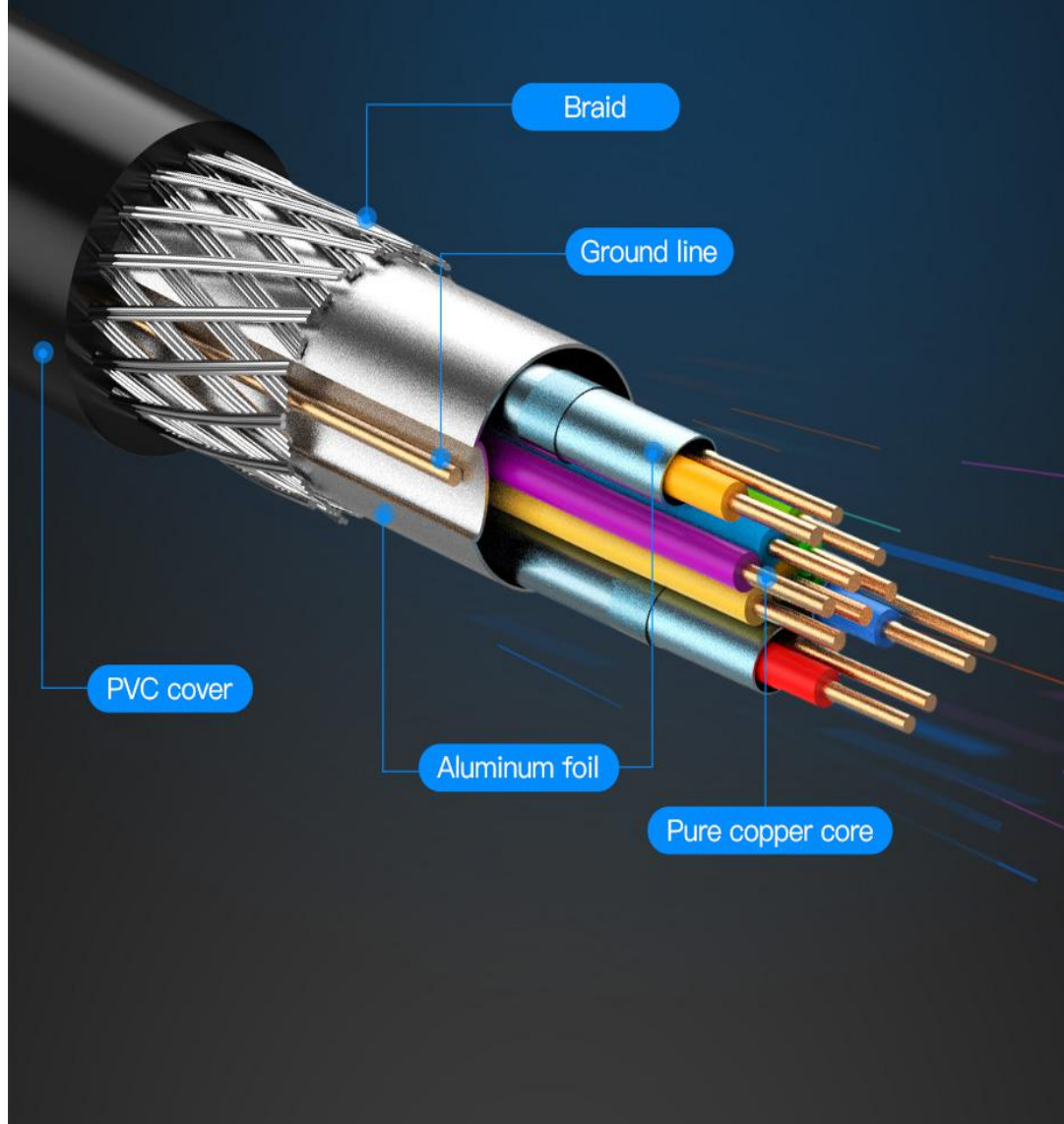

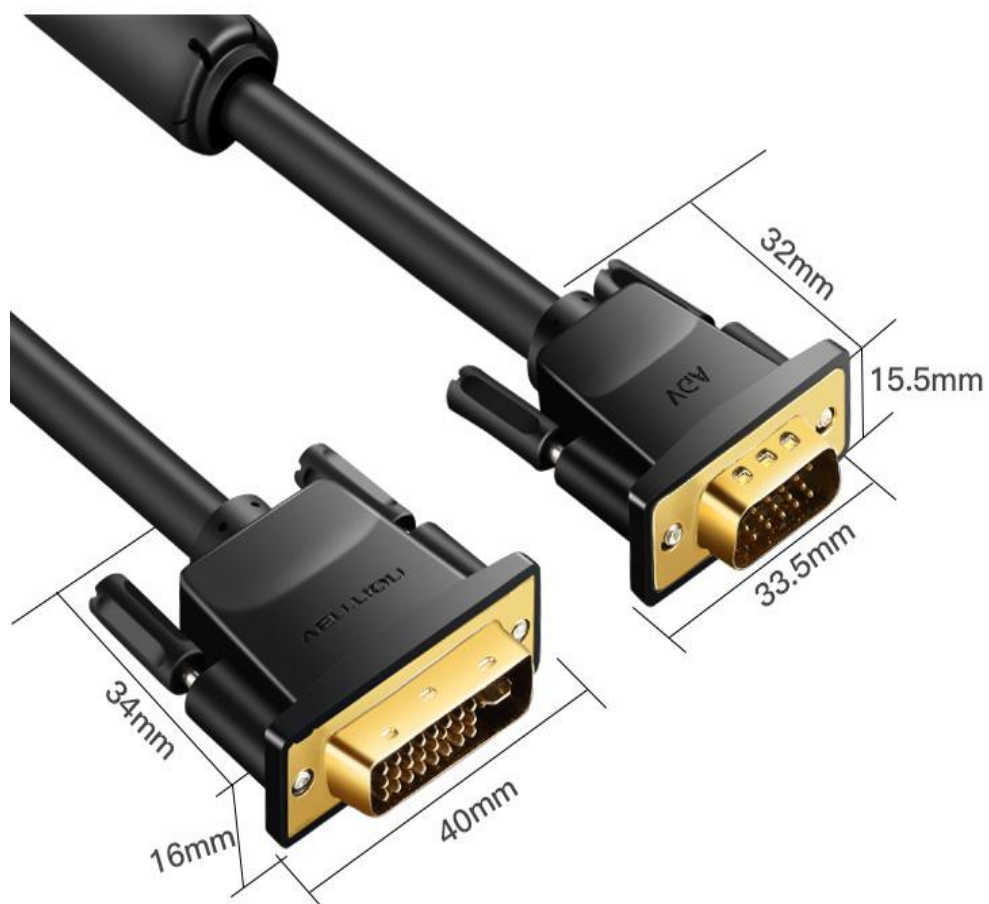


* Sizes above are hand measurement, there might be slight tolerance

Product Parameters

Brand	Vention
Name	DVI 24+5 to VGA Converter
Model	EAC
Appearance Color	Black
Interface Process	Gold plated
Core	High purity copper
Interface Type	DVI 24+5 male, VGA male
Resolution	1920x1080@60Hz
Shielding	Double aluminum foil + Metal braided Double magnetic ring
Specifications	17.5mmx9.5mmx28mm
OD	7.3mm
Length	1m-10m
Jacket	PVC
AWG	30AWG
Warranty	One year
Packing	Color box

* All data are from Vention laboratory

Length	Art.No.	EAN Code
1m	EACBF	6922794732957
1.5m	EACBG	6922794732964
2m	EACBH	6922794732971
3m	EACBI	6922794732988
5m	EACBJ	6922794732995
8m	EACBK	6922794733008
10m	EACBL	6922794733015

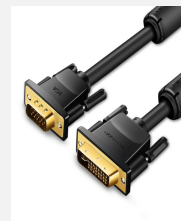

Package Contents

DVI to VGA Cable x 1

Packaging Information

Packing Dimension	mm
Packing Weight	kg
Carton Dimension	48*29*30mm
Carton Qty	80pcs(1m) 70pcs (1.5m) 55pcs(2m) 50pcs(3m) 40pcs(5m) 28pcs(8m) 28pcs(10m)
Carton Weight	10.76kg (1m)
Package	Color Box

www.ventioncable.com