




RIF.	Q.TY	DRAWING	DESCRIPTION
1	1	2_040_00006	BASE CBOX EURO INT D60
2	1	2_040_00008	COVER CBOX EURO INT H25 5 POLES

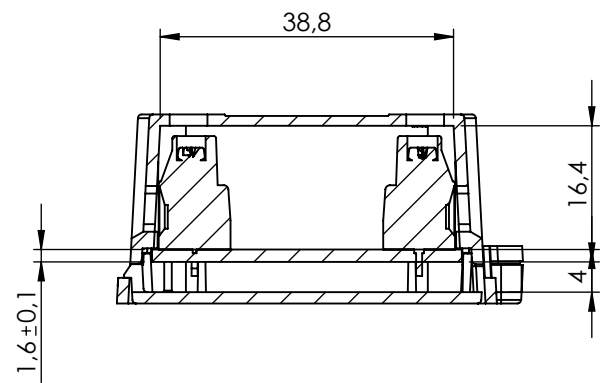

SECTION Q-Q
SCALE 1 : 1

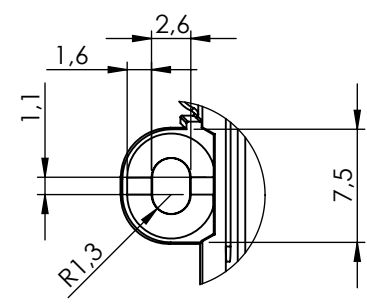


DETAIL V

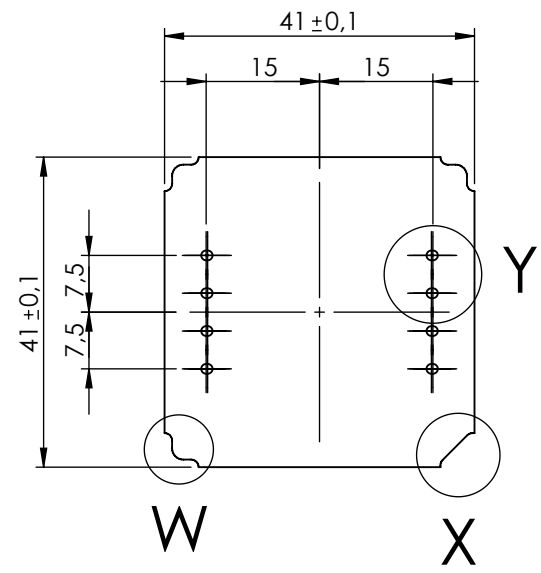


W



X

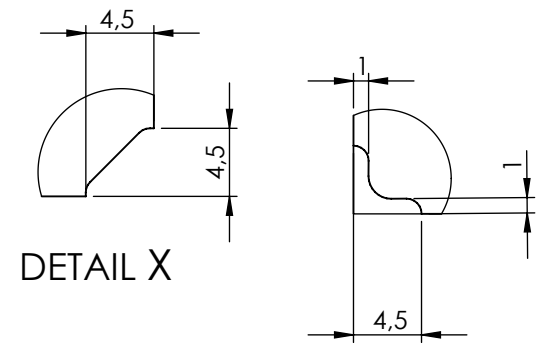



DETAIL X

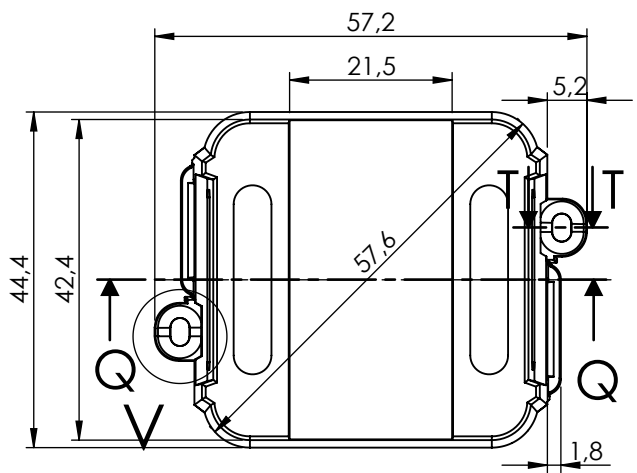

SECTION T-T
SCALE 1 : 1

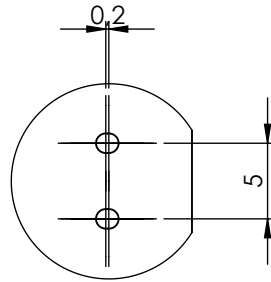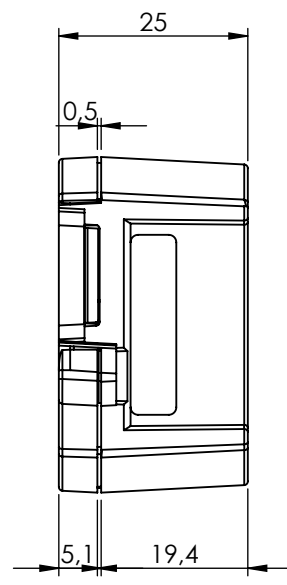


DETAIL Y

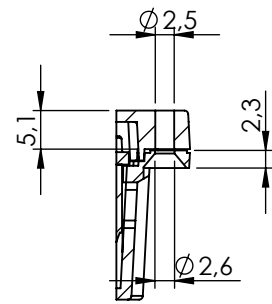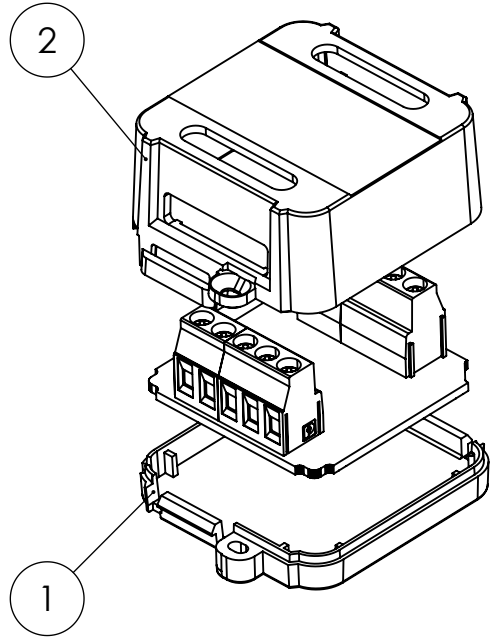


Self-tapping screws
countersunk head
d2.9x6.5


Screws for pressed
wood or chipboard
d2.5 mm for dowel
fixing to wall

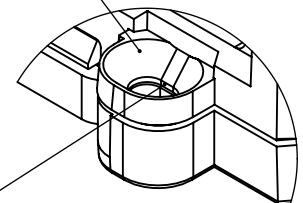

DETAIL Z

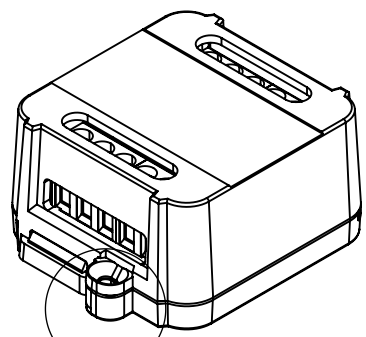

Z

 General Tolerance UNI EN 22768/1 Media (m)									
from 0.5 to 3	from 3 to 6	from 6 to 30	from 30 to 120	from 120 to 400					
± 0.1	± 0.1	± 0.2	± 0.3	± 0.5					
Scale:	Sheet nr.:	Drawn:	Checked:	Date:					
2:1	1/1	R.N.	R.N.	29/01/2021	Rev. description				
		Material:		Weight:	Cod. Mold:				
Dimension in mm				gr	--				
 enclosures for electronics italtronic.com		Description:							
		CONTENTITORE CBOX EURO D60 H25 5 POLI ENCLOSURE CBOX INT EURO D60 H25 5 POLES							
		Drawing nr.							Rev.
		3_040_00005							

RESERVED PROPERTY: The present drawing cannot be reproduced or communicated to 3d parties, even partially, without the authorization of ITALTRONIC Srl. Italtronic reserves to protect its own rights according to the law.