



USB 3.0 Male to Male Cable

USB 3.0 Male to Male Cable



Wide Application



Laptop



Desktop



All-in-one PC



Smart TV



Radiator



TV box



Hard drive



HDD/SDD case



Pen tablet



Webcam



Car MP3



Camera

Note: Do not support two computers connect to each other




Fast Transmission

5Gbps transfer rate
transfer 1GB file in 5 seconds

5Gbps

Note: All data are from Vention Lab

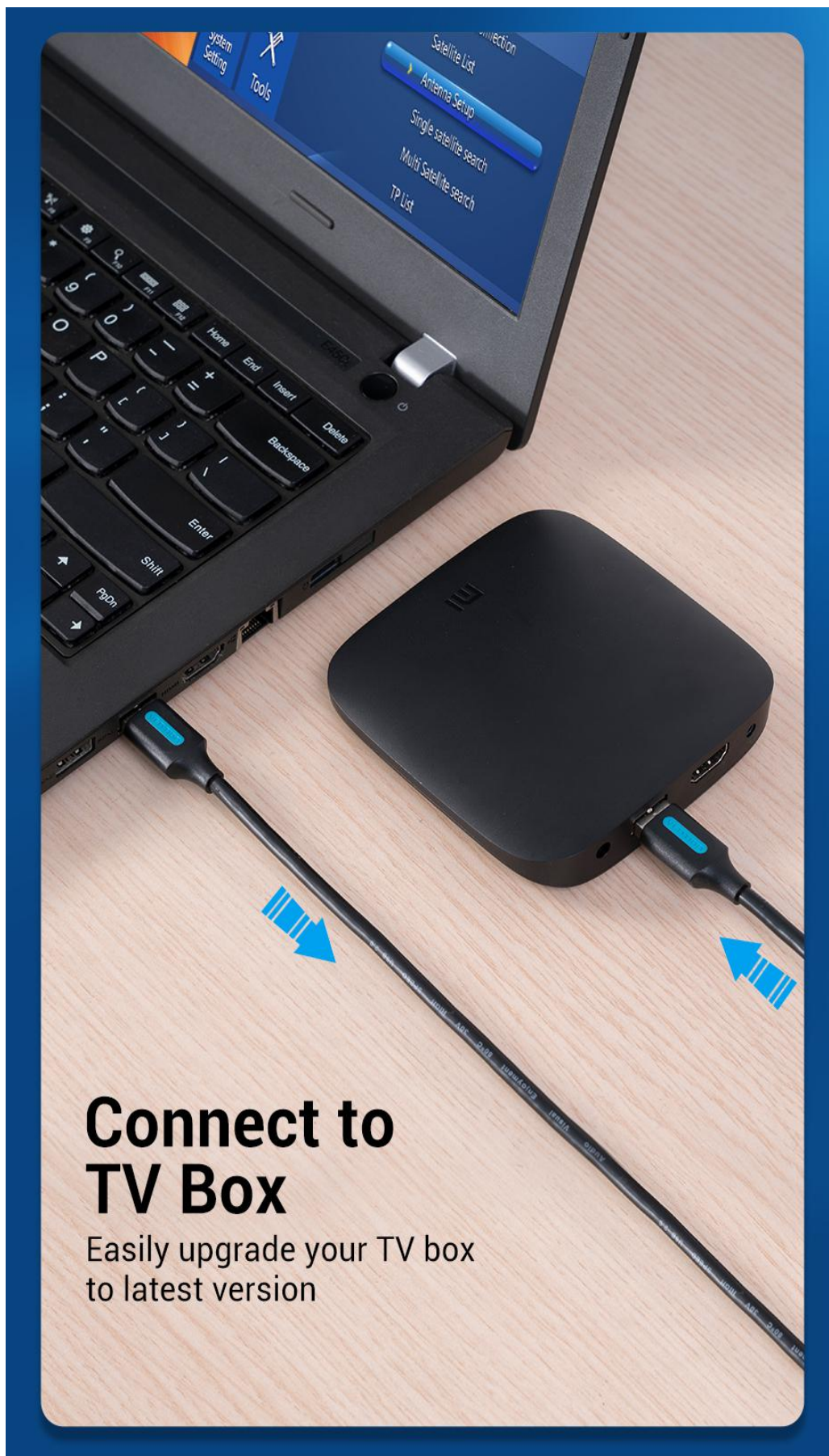


Connect to TV Box

Easily upgrade your TV box
to latest version

Connect to Hard Drive

Safe and lossless
file transmission

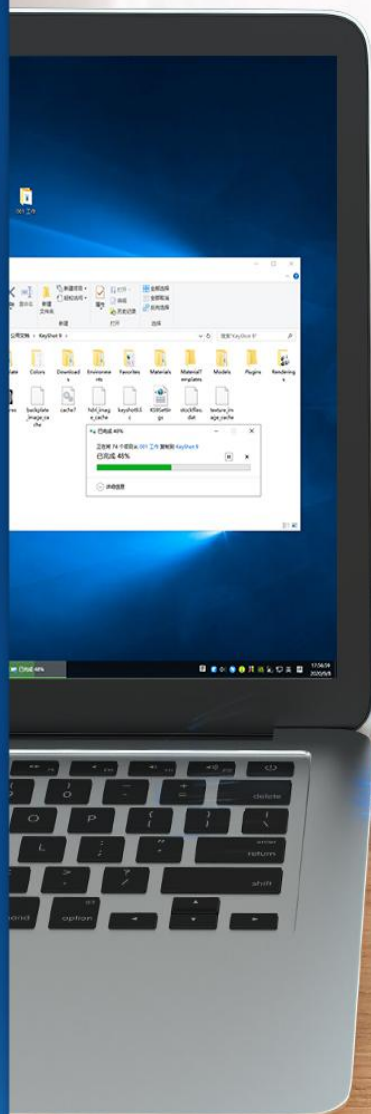

Long Tail Design

Refuse to change cables frequently




Nickel-plated Interface

Wear-resistant, oxidation-resistant
durable in swapping



High Quality Cable


Ensure faster and more stable transmission

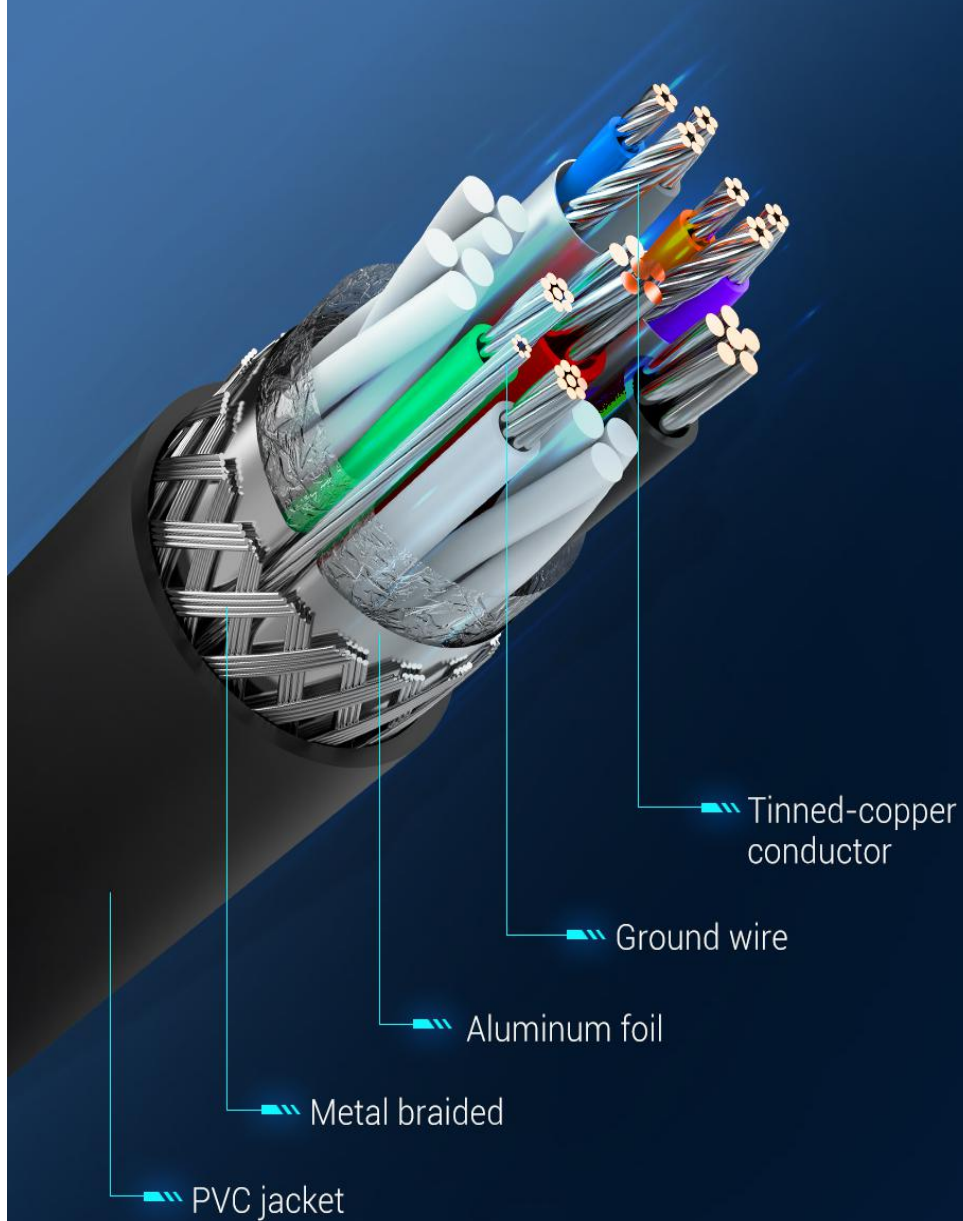

Note: The internal structure is a rendering, please refer to the actual product

PVC Jacket

Flexible and high tenacity, longer service life

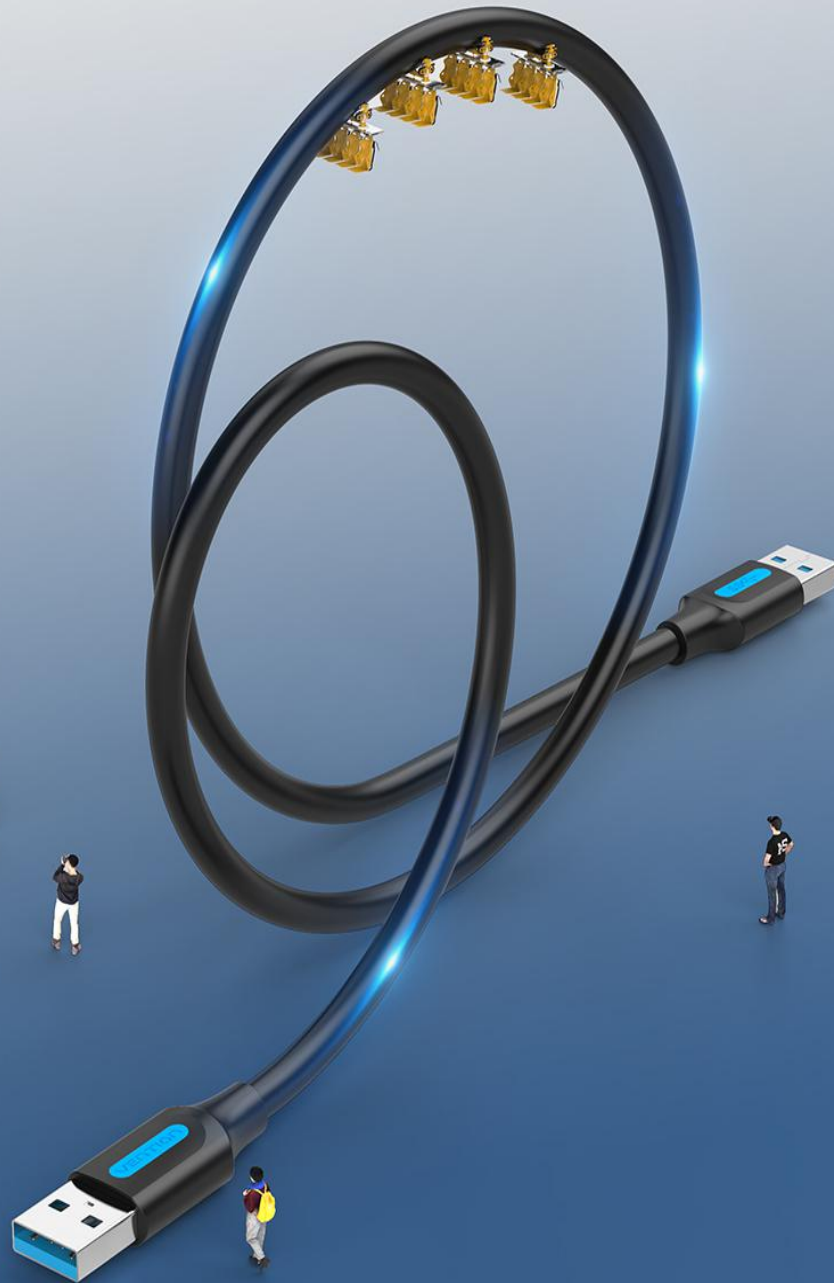

Product Parameters

Brand: Vention	Shielding: Aluminum Foil + Metal Braided + GND
Name: USB 3.0 A Male to A Male Cable	
Model: CONB	Jacket: PVC
Color: Black	AWG: 24+28AWG
Interface: USB 3.0 A Male	OD: 5.4mm
Interface Technics: Nickel-plated	Length: 0.5/1/1.5/2/3m
Transmission Speed: 5Gbps	Power Supply: 2A
Conductor: Tinned-copper	Warranty: 1 Year
Shell: PVC	Packing: PE Bag



Note: All data are from Vention Lab.
Sizes above are manually measured. There might be slight tolerance

Length	Art.No.	EAN Code
0.5m	CONBD	6922794748804
1m	CONBF	6922794748811
1.5m	CONBG	6922794748828
2m	CONBH	6922794748835
3m	CONBI	6922794748842



Package Contents

USB Cable x 1

Packaging Information

Packing Dimension	mm
Packing Weight	kg
Carton Dimension	48*29*30mm
Carton Qty	200pcs (0.5m) 150pcs(1m) 120pcs(1.5m) 100pcs(2m) 80pcs(3m)
Carton Weight	8kg (0.5m)
Package	PE bag

www.ventioncable.com