



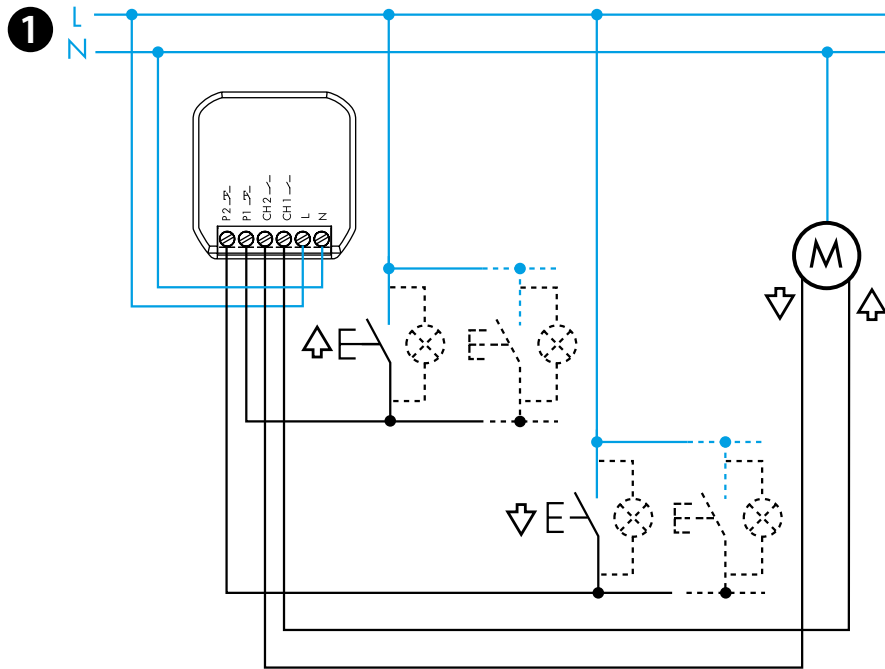

13.S2

EN 60669-1 / EN 60669-2-1			
	13.S2.8.230.B000 U_N 110...230 V AC (50/60 Hz) U_{min} 96 V AC U_{max} 253 V AC P 2 VA (50 Hz) / 0.5 W		
Ch1  Ch2 	2 NO (DPST-NO) 6A 230 V AC		
	AC1 AC15 	110 V 650 VA 150 VA 100 W	230 V 1380 VA 300 VA 200 W
	(-10...+50)°C		
	5 (≤ 1 mA)		
IP20			

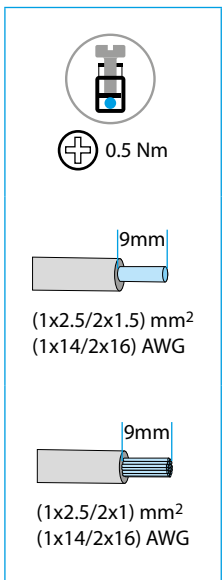

ENGLISH

13.S2.8.230.B000
CURTAINS ACTUATOR

1 WIRING DIAGRAM

Channel 1: Ch1 - push button 1 (P1)
Channel 2: Ch2 - push button 2 (P2)

2 FINDER TOOLBOX APPLICATION

With the Finder Toolbox App you can:
- Set the timings on channels Ch1 - Ch2
- Associate the wireless button
- Set scenarios (Where a scenario calls for the simultaneous operation of several shutters the "R" setting staggers their operation to avoid excessive disturbance on the supply system)

NOTE

- Transmission range: approximately 10 m in free space and without obstacles
- The transmission range may vary depending on the building structure
- Example:
 - Reinforced concrete walls and/or metal walls
 - Partition walls filled with insulating wool on a metallic backing
 - Ceilings with metal or carbon fiber panels
 - Lead glass or glass with metal cladding, steel furniture

3 FUNCTIONS

Download on the App Store

GET IT ON Google Play

TOOLBOX PLUS

