


Crocodile clips

AGF 20

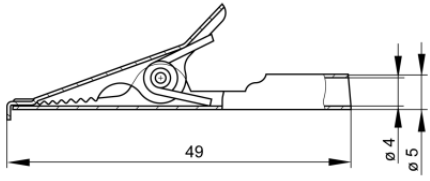

Product	AGF 20
description	Nickel-plated steel alligator clip. The special shape allows clamping of both extremely fine and thick wires. 4 mm diameter socket connection and solder connection possible. max. bolt diameter 12 mm
operating instruction	BA420
Articlenummer	930120000 Ni
drawing	
	
technical data	
connection	unsprung socket 4 mm, solder connection
rated voltage ⁽¹⁾	30 VAC / 60 VDC
measurement cat. acc. to IEC 61010	O ⁽³⁾
rated current ⁽¹⁾ (consider derating curve)	4 A
material socket	steel, nickel plated
temperature range acc. To IEC61010 ⁽²⁾	-25 °C to +100 °C
clamping range	10 mm
standard	IEC 61010

⁽¹⁾ for normal environmental conditions -5°C to +40°C

⁽²⁾ contact the manufacturer for applications at deviating temperature ranges

⁽³⁾ without rated measurement category, for other circuits that are not directly connected to mains

stand: 19.06.2019