


Plugs

LAS S G

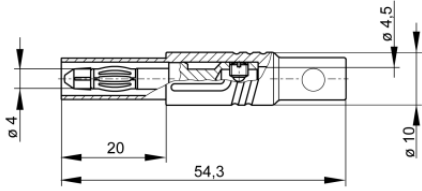

Product	LAS S G
description	Safety straight connector with screw connection for leads from 0.5mm ² to 1.5mm ² , outer diameter of lead max. 4.2mm. Plug 4mm with caged spring, 1000 V-system, IEC 61010. Simple assembly by Click-System.
operating instruction	BA459
article-no. / *colour	9340971xx  00 black  01 red  02 blue  03 yellow  04 green  05 brown  06 gray  07 white  09 violet Ni
drawing	
	
technical data	
connection	screw terminal
rated voltage ⁽¹⁾	AC/DC 1000 V
measurement cat. acc. to IEC 61010	CAT III
rated current ⁽¹⁾ (consider derating curve)	24 A
material plug	brass, nickel plated
housing material	PA
temperature range acc. To IEC61010 ⁽²⁾	-15 °C to +70 °C
flammability class acc. to UL 94 (only valid for basic material of housing)	V-2
standard	IEC 61010

⁽¹⁾ for normal environmental conditions -5°C to +40°C

⁽²⁾ contact the manufacturer for applications at deviating temperature ranges

stand: 28.01.2019