


Sockets

MPB 1

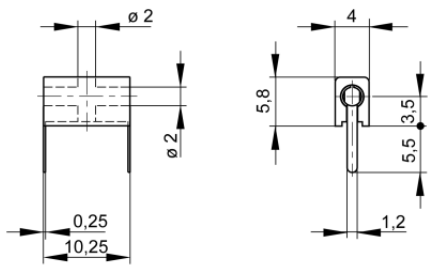

Product	MPB 1
description	2 mm diameter miniature test socket, dimensions complying with DIN 41649. Suitable for measuring and testing printed circuits during operation. Tin-plated sprung bronze contact spring. Test socket with horizontal and vertical connections.
operating instruction	BA204
article-no. / *colour	● 00 black ● 01 red Sn
drawing	
technical data	
connection	solder connection
rated voltage ⁽¹⁾	30 VAC / 60 VDC
measurement cat. acc. to IEC 61010	O ⁽³⁾
rated current ⁽¹⁾ (consider derating curve)	6 A
material socket	contact spring: bronze
housing material	PC
temperature range acc. To IEC61010 ⁽²⁾	-20 °C to +60 °C
standard	IEC 61010

⁽¹⁾ for normal environmental conditions -5°C to +40°C

⁽²⁾ contact the manufacturer for applications at deviating temperature ranges

⁽³⁾ without rated measurement category, for other circuits that are not directly connected to mains
stand: 12.07.2019