
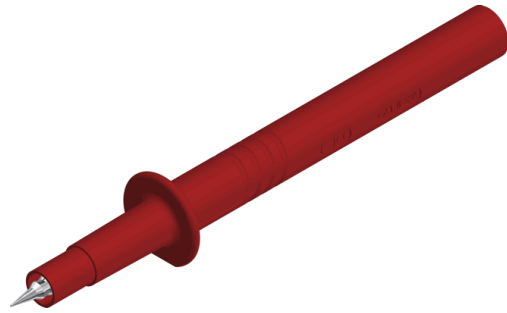


Test probes

PRUEF 2700

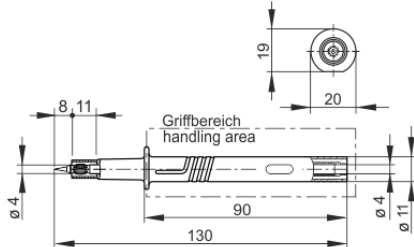

Product	PRUEF 2700
description	Safety test probe with dual function. Tip for penetrating oxide layers and 4 mm diameter pin for insertion in sockets. 4 mm diameter brass socket connection. Connects with safety measuring leads.
operating instruction	BA463
article-no. / *colour	9723191xx  00 black  01 red Ni
drawing	
	
technical data	
connection	unsprung socket 4 mm
rated voltage ⁽¹⁾	AC/DC 1000 V
measurement cat. acc. to IEC 61010	CAT II
rated current ⁽¹⁾ (consider derating curve)	32 A
material socket	brass, nickel plated
housing material	PP
temperature range acc. To IEC61010 ⁽²⁾	-25 °C to +70 °C
flammability class acc. to UL 94 (only valid for basic material of housing)	HB
standard	IEC 61010

⁽¹⁾ for normal environmental conditions -5°C to +40°C

⁽²⁾ contact the manufacturer for applications at deviating temperature ranges
stand: 19.06.2019