


Sockets

SEB 2610 F4,8

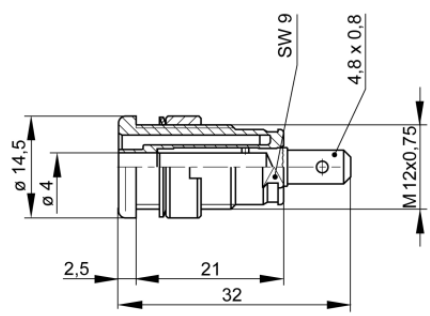

Product	SEB 2610 F4,8
description	Safety built-in socket, 4 mm diameter, contact-protected, with 4.8 x 0.8 tab connector complying with DIN 46 244, gold-plated brass. For installation into switchpanels and equipment chassis with wall thicknesses up to 6 mm. Installation hole: 12.2 mm diameter, Tightening torque: 50 Ncm, Accessory: assembly tool MW SEB
operating instruction	BA451
article-no. / *colour	9723551xx  00 black  01 red  02 blue  03 yellow  04 green  05 brown  06 gray  07 white  09 violet  88 yellow green Au
drawing	
	
technical data	
connection	flat connector 4.8 x 0.8 mm
rated voltage ⁽¹⁾	AC/DC 1000 V
measurement cat. acc. to IEC 61010	CAT III
rated current ⁽¹⁾ (consider derating curve)	25 A
material socket	brass, gold plated
housing material	PA
temperature range acc. To IEC61010 ⁽²⁾	-40 °C to +80 °C

4 mm safety system

inflammability class acc. to UL 94 (only valid for basic material of housing)	V-2
standard	IEC 61010

⁽¹⁾ for normal environmental conditions -5°C to +40°C

⁽²⁾ contact the manufacturer for applications at deviating temperature ranges

stand: 13.05.2016