


Sockets

PKI 110

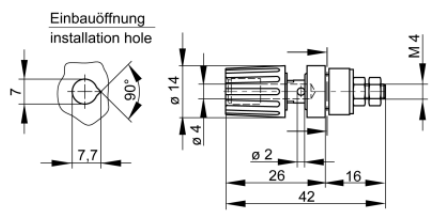

Product	PKI 110
description	Pole terminal with claw edge, captive insulated head and insulated ring. 4 mm diameter nickel-plated brass threaded bolt with 2 mm diameter transverse hole. For insulated, non-rotating installation in equipment chassis and switch panels up to 3.5 mm wall thickness.
operating instruction	BA402
article-no. / *colour	9317141xx  00 black  01 red  02 blue  03 yellow  04 green  88 yellow green Ni
drawing	
technical data	
connection	M4 thread
rated voltage ⁽¹⁾	30 VAC / 60 VDC
measurement cat. acc. to IEC 61010	O ⁽³⁾
rated current ⁽¹⁾ (consider derating curve)	35 A
material socket	brass, nickel plated
housing material	PA
temperature range acc. To IEC61010 ⁽²⁾	-25 °C to +100 °C
flammability class acc. to UL 94 (only valid for basic material of housing)	V-2
standard	IEC 61010

4 mm system

⁽¹⁾ for normal environmental conditions -5°C to +40°C

⁽²⁾ contact the manufacturer for applications at deviating temperature ranges

⁽³⁾ without rated measurement category, for other circuits that are not directly connected to mains

stand: 03.09.2018