


## SPAX®

BN 14073 - Hexalobular (6 Lobe) socket flat countersunk head chipboard screws T-STAR plus, fully threaded with 4CUT point



Manufacturer

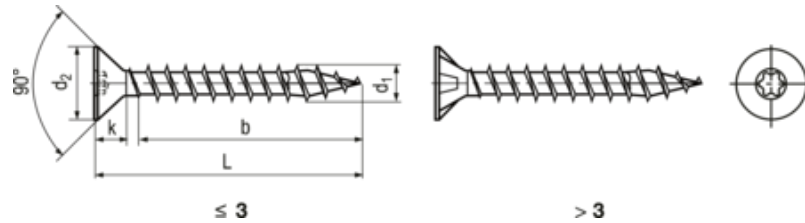

Product description

Other documentation: [www.spax.com](http://www.spax.com)

Additional information

The YELLOX® coating is an alternative chromium free (VI) surface coating with considerably higher corrosion protection compared to yellow electrogalvanizing.

Headform

Countersunk

Drive

Hexalobular socket

Thread

fully threaded

Brand

SPAX®

Material

Steel

Material execution

case-hardened

Surface

YELLOX®, waxed

Version

with 4CUT point

Certificates



Warnings

ISO 4042

Quenched and tempered fasteners  $\geq 360$  HV and tempered case-hardened fasteners with electroplated coatings: Susceptible to hydrogen embrittlement!

Further notice to residual risks can be found in the introduction section.

| Article no | d1 | L  | d2 | k max | Hexalobular socket | b~ |
|------------|----|----|----|-------|--------------------|----|
| 2107260    | 3  | 12 | 6  | 1.8   | T10                | 10 |
| 2101823    | 3  | 16 | 6  | 1.8   | T10                | 14 |

| Article no | d1  | L  | d2  | k max | Hexalobular socket | b~ |
|------------|-----|----|-----|-------|--------------------|----|
| 2101831    | 3   | 20 | 6   | 1.8   | T10                | 17 |
| 3373540    | 3   | 25 | 6   | 1.8   | T10                | 21 |
| 2101858    | 3.5 | 16 | 7   | 2.1   | T15/T20            | 14 |
| 2101866    | 3.5 | 20 | 7   | 2.1   | T15/T20            | 16 |
| 3373544    | 3.5 | 25 | 7   | 2.1   | T15/T20            | 21 |
| 2101874    | 4   | 15 | 8   | 2.4   | T20                | 11 |
| 2101882    | 4   | 20 | 8   | 2.4   | T20                | 16 |
| 3368263    | 4   | 25 | 8   | 2.4   | T20                | 21 |
| 2107287    | 4.5 | 20 | 8.8 | 2.7   | T20                | 15 |