


SPAX®

BN 15002 - Hexalobular (6 Lobe) socket flat countersunk head chipboard screws T-STAR plus, partially threaded with 4CUT point



Manufacturer

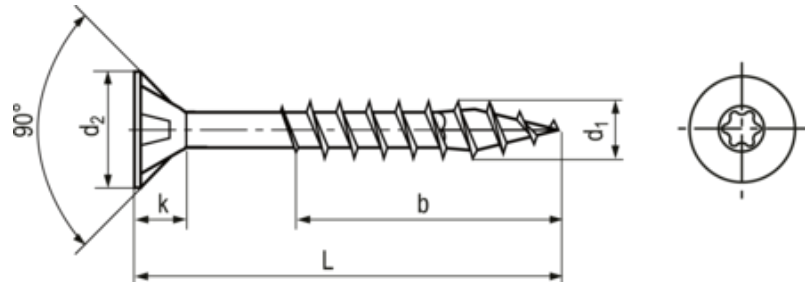

Product description

- Waxed

Other documentation: www.spax.com

Headform

Countersunk

Drive

Hexalobular socket

Thread

partially threaded

Brand

SPAX®

Material

Stainless steel

Material type

A2

Version

with 4CUT point

Certificates



Article no	d1	L	d2	k max	Hexalobular socket	b
3062713	3.5	30	7	2.1	T15	18
3062714	3.5	35	7	2.1	T15	23
3062716	3.5	40	7	2.1	T15	23
3062717	4	30	8	2.4	T20	18
3062718	4	35	8	2.4	T20	23
3062720	4	40	8	2.4	T20	23
3062721	4	45	8	2.4	T20	30
3062722	4	50	8	2.4	T20	32
3062724	4.5	40	8.8	2.7	T20	25

Article no	d1	L	d2	k max	Hexalobular socket	b
3062725	4.5	45	8.8	2.7	T20	30
3062727	4.5	50	8.8	2.7	T20	32
3062728	4.5	60	8.8	2.7	T20	37
3062729	4.5	70	8.8	2.7	T20	42
3062730	5	40	9.7	2.9	T20	27
3062731	5	45	9.7	2.9	T20	30
3062732	5	50	9.7	2.9	T20	32
3062733	5	60	9.7	2.9	T20	37
3062734	5	70	9.7	2.9	T20	41
3062735	5	80	9.7	2.9	T20	46
3062736	5	90	9.7	2.9	T20	61
3062737	5	100	9.7	2.9	T20	61
3062738	5	120	9.7	2.9	T20	68
3062742	6	60	11.6	3.4	T30	37
3062743	6	70	11.6	3.4	T30	41
3062744	6	80	11.6	3.4	T30	46
3062745	6	90	11.6	3.4	T30	61
3062746	6	100	11.6	3.4	T30	61
3062748	6	120	11.6	3.4	T30	68
3062749	6	140	11.6	3.4	T30	68
3062752	6	160	11.6	3.4	T30	68