


Hexalobular (6 Lobe) socket flat countersunk head double neck chipboard screws, fully threaded

BN 20149

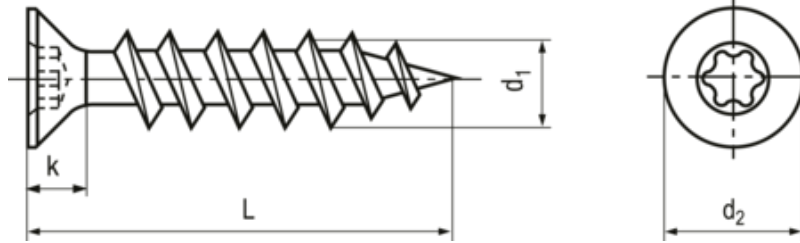

Product description

- Waxed

Headform

Countersunk

Drive

Hexalobular socket

Thread

fully threaded

Material

Stainless steel

Material type

A2

Article no	d1	L	d2 max	k max	Hexalobular socket
3242440	3	13	6	1.9	X10
3242441	3	16	6	1.9	X10
3242442	3	20	6	1.9	X10
3242443	3	25	6	1.9	X10
3242444	3.5	16	7	2.1	X15
3242445	3.5	20	7	2.1	X15
3242446	3.5	25	7	2.1	X15
3242447	3.5	30	7	2.1	X15
3242448	3.5	35	7	2.1	X15
3242449	4	16	8	2.5	X20
3242451	4	20	8	2.5	X20
3242452	4	25	8	2.5	X20
3242453	4	30	8	2.5	X20
3242454	4	35	8	2.5	X20
3242455	4	40	8	2.5	X20
3242456	4	45	8	2.5	X20
3242457	4	50	8	2.5	X20
3242458	4.5	20	9	2.7	X20

Article no	d1	L	d2 max	k max	Hexalobular socket
3242459	4.5	25	9	2.7	X20
3242460	4.5	30	9	2.7	X20
3242462	4.5	35	9	2.7	X20
3242463	4.5	40	9	2.7	X20
3242464	4.5	45	9	2.7	X20
3242465	4.5	50	9	2.7	X20
3242466	4.5	60	9	2.7	X20
3242467	4.5	70	9	2.7	X20
3242468	4.5	80	9	2.7	X20
3242469	5	25	10	3	X25
3242470	5	30	10	3	X25
3242471	5	35	10	3	X25
3242472	5	40	10	3	X25
3242474	5	45	10	3	X25
3242475	5	50	10	3	X25
3242477	5	60	10	3	X25
3242478	5	70	10	3	X25
3242479	5	80	10	3	X25
3242480	5	90	10	3	X25
3242482	5	100	10	3	X25
3242483	6	60	12	3.6	X25
3242484	6	70	12	3.6	X25
3242485	6	80	12	3.6	X25
3242486	6	90	12	3.6	X25
3242487	6	100	12	3.6	X25
3242488	6	120	12	3.6	X25