


Hexalobular (6 Lobe) socket pan head chipboard screws fully threaded

BN 20150

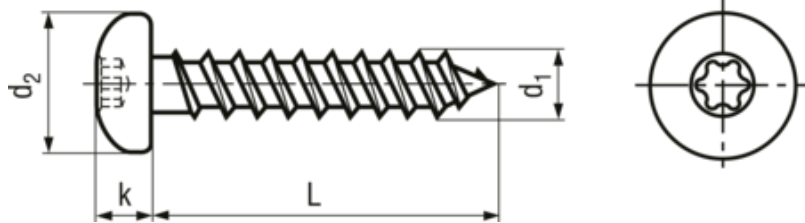

Product description

- Waxed

Headform

Round

Drive

Hexalobular socket

Thread

fully threaded

Material

Stainless steel

Material type

A2

Article no	d1	L	d2	k max	Hexalobular socket
3242491	3	13	6	2.4	X10
3242492	3	16	6	2.4	X10
3242493	3	20	6	2.4	X10
3242494	3	25	6	2.4	X10
3242496	3.5	16	7	2.5	X10
3242498	3.5	20	7	2.5	X10
3242500	3.5	25	7	2.5	X10
3242501	3.5	30	7	2.5	X10
3242502	4	16	8	2.9	X20
3242503	4	20	8	2.9	X20
3242504	4	25	8	2.9	X20
3242506	4	30	8	2.9	X20
3242507	4	35	8	2.9	X20
3242508	4	40	8	2.9	X20
3242511	4	45	8	2.9	X20
3242512	4	50	8	2.9	X20
3242516	4.5	16	8.9	3.2	X20
3242517	4.5	20	8.9	3.2	X20

Article no	d1	L	d2	k max	Hexalobular socket
3242525	4.5	25	8.9	3.2	X20
3242526	4.5	30	8.9	3.2	X20
3242527	4.5	35	8.9	3.2	X20
3242528	4.5	40	8.9	3.2	X20
3242529	4.5	45	8.9	3.2	X20
3242530	4.5	50	8.9	3.2	X20
3242531	4.5	60	8.9	3.2	X20
3242532	5	20	9.9	3.4	X25
3242533	5	25	9.9	3.4	X25
3242534	5	30	9.9	3.4	X25
3242535	5	35	9.9	3.4	X25
3242536	5	40	9.9	3.4	X25
3242537	5	45	9.9	3.4	X25
3242539	5	50	9.9	3.4	X25
3242541	5	60	9.9	3.4	X25
3242543	5	70	9.9	3.4	X25
3242544	5	80	9.9	3.4	X25
3339025	6	30	12	4.2	X25
3339028	6	40	12	4.2	X25
3339029	6	50	12	4.2	X25
3339030	6	60	12	4.2	X25
3339032	6	80	12	4.2	X25