


Hanger bolts with hexalobular (6 Lobe) socket

BN 20215

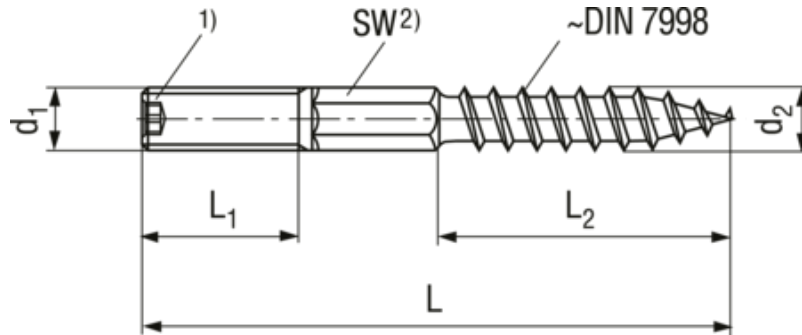

Drive Hexalobular socket

Thread partially threaded

Material Steel

Surface zinc plated blue

1) ≤ M5 without hexalobular socket 2) ≤ M6 without spanner flat SW

Article no	d1	L	d2	Hexalobular socket	SW	L1	L2
9010366	M4	30	4	-	-	10	13
9010367	M4	40	4	-	-	15	18
9010369	M5	40	5	-	-	15	18
9010370	M5	50	5	-	-	20	20
3360700	M6	40	6	X15	-	14	18
3360702	M6	50	6	X15	-	17	23
3360704	M6	60	6	X15	-	17	25
3360705	M6	80	6	X15	-	27	25
3360706	M8	50	7.2	X25	6	12	25
3360707	M8	60	7.2	X25	6	17	25
3360709	M8	70	7.2	X25	6	22	25
3360710	M8	80	7.2	X25	6	27	35
3360711	M8	100	7.2	X25	6	37	35
3360712	M8	120	7.2	X25	6	47	45
3360713	M8	130	7.2	X25	6	47	45
3360714	M8	140	7.2	X25	6	47	45
3360715	M8	150	7.2	X25	6	47	45
3360716	M8	160	7.2	X25	6	47	45
3360717	M8	180	7.2	X25	6	47	45
3360718	M8	200	7.2	X25	6	47	45

Article no	d1	L	d2	Hexalobular socket	SW	L1	L2
3360719	M10	60	8.75	X25	8	17	25
3360720	M10	80	8.75	X25	8	18	35
3360721	M10	100	8.75	X25	8	27	55
3360722	M10	120	8.75	X25	8	38	55
3360723	M10	130	8.75	X25	8	38	55
3360724	M10	140	8.75	X25	8	38	55
3360725	M10	150	8.75	X25	8	38	55
3360726	M10	160	8.75	X25	8	38	55
3360727	M10	180	8.75	X25	8	38	55
3360728	M10	200	8.75	X25	8	38	55