


SPAX®

BN 20537 - Hexalobular (6 Lobe) T-STAR plus flange head screws for timber construction with 4CUT point



Manufacturer

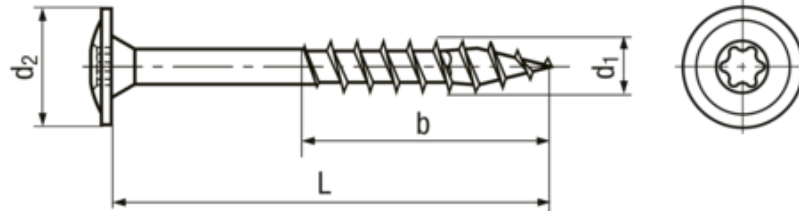

Product description

Other documentation: www.spax.com

Additional information

The WIROX® coating is an alternative chromium free (VI) surface coating with considerably higher corrosion protection compared to yellow electrogalvanizing.

Headform

Button with collar

Drive

Hexalobular socket

Thread

partially threaded

Brand

SPAX®

Material

Steel

Material execution

case-hardened

Surface

WIROX® added lubricant

Version

with 4CUT point

Certificates



Warnings

ISO 4042

Quenched and tempered fasteners ≥ 360 HV and tempered case-hardened fasteners with electroplated coatings: Susceptible to hydrogen embrittlement!

Further notice to residual risks can be found in the introduction section.

$L \geq 160$ with 4CUT cutter

Article no

d1

L

d2

k max

Hexalobular socket

b

Article no	d1	L	d2	k max	Hexalobular socket	b
9017655	6	40	13.6	2.4	T30	37
3547803	6	60	13.6	2.4	T30	56
3547783	6	80	13.6	2.4	T30	61
3547805	6	100	13.6	2.4	T30	61
3547807	6	120	13.6	2.4	T30	68
3547808	6	140	13.6	2.4	T30	68
3547810	6	160	13.6	2.4	T30	65
3547811	6	180	13.6	2.4	T30	65
9017656	6	200	13.6	2.4	T30	65
9017657	6	220	13.6	2.4	T30	65
9017658	6	250	13.6	2.4	T30	65
9017659	6	280	13.6	2.4	T30	65
9017660	6	300	13.6	2.4	T30	65
9006730	8	50	20	4	T40	46
3576813	8	80	20	4	T40	70
3576814	8	100	20	4	T40	80
3576815	8	120	20	4	T40	80
3576816	8	140	20	4	T40	80
3576817	8	160	20	4	T40	80
3576818	8	180	20	4	T40	80
3576819	8	200	20	4	T40	80
3576820	8	220	20	4	T40	80
3576821	8	240	20	4	T40	80
3576822	8	260	20	4	T40	80
3576823	8	280	20	4	T40	80
3576824	8	300	20	4	T40	80
3576825	8	320	20	4	T40	80
3576826	8	340	20	4	T40	80
3576827	8	360	20	4	T40	80
3576828	8	380	20	4	T40	80
3576829	8	400	20	4	T40	80
3576830	8	450	20	4	T40	80
9017661	8	500	20	4	T40	80
9017662	8	550	20	4	T40	80
3792655	10	80	25	4.7	T50	70
3792656	10	100	25	4.7	T50	80
3792657	10	120	25	4.7	T50	80
3792658	10	140	25	4.7	T50	80
3792660	10	160	25	4.7	T50	80
3792661	10	180	25	4.7	T50	80
3792662	10	200	25	4.7	T50	80
3792663	10	220	25	4.7	T50	80
3792665	10	240	25	4.7	T50	80
3792666	10	260	25	4.7	T50	80
3792667	10	280	25	4.7	T50	80
3792668	10	300	25	4.7	T50	80
3792670	10	320	25	4.7	T50	80
3792671	10	340	25	4.7	T50	80
3792672	10	360	25	4.7	T50	80
3792673	10	380	25	4.7	T50	80

Article no	d1	L	d2	k max	Hexalobular socket	b
3792674	10	400	25	4.7	T50	80
3792675	10	450	25	4.7	T50	80