


Universal hexalobular (6 Lobe) socket flat countersunk head wood screws partially threaded, cutting ribs under the head, friction thread, end mill cutter

BN 20594

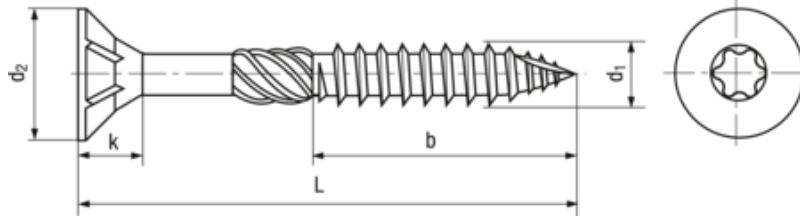

Headform	Countersunk
Drive	Hexalobular socket
Thread	partially threaded
Material	Steel
Material execution	case-hardened
Surface	zinc plated blue, added lubricant
Warnings	ISO 4042 Quenched and tempered fasteners ≥ 360 HV and tempered case-hardened fasteners with electroplated coatings: Susceptible to hydrogen embrittlement! Further notice to residual risks can be found in the introduction section.

Article no	d1	L	d2 max	k max	Hexalobular socket	b
3668358	10	140	18.4	9.1	X40	60
3668359	10	160	18.4	9.1	X40	80
3668372	10	400	18.4	9.1	X40	80
3676240	4.5	40	9	4.25	X20	-
3676241	4.5	50	9	4.25	X20	-
3676242	4.5	60	9	4.25	X20	-
3676243	4.5	70	9	4.25	X20	40
3676244	4.5	80	9	4.25	X20	52
3676245	5	50	10	4.65	X25	-
3676246	5	60	10	4.65	X25	-
3676247	5	70	10	4.65	X25	40
3676248	5	80	10	4.65	X25	52
3676249	5	90	10	4.65	X25	52
3676251	5	100	10	4.65	X25	60

Article no	d1	L	d2 max	k max	Hexalobular socket	b
3676252	5	120	10	4.65	X25	60
3588522	6	50	12.2	6.3	X30	-
3588523	6	60	12.2	6.3	X30	-
3588524	6	70	12.2	6.3	X30	40
3588525	6	80	12.2	6.3	X30	52
3588526	6	90	12.2	6.3	X30	52
3588527	6	100	12.2	6.3	X30	60
3588528	6	110	12.2	6.3	X30	60
3588529	6	120	12.2	6.3	X30	60
3588530	6	130	12.2	6.3	X30	60
3588531	6	140	12.2	6.3	X30	70
3588532	6	150	12.2	6.3	X30	70
3588533	6	160	12.2	6.3	X30	70
3588534	6	180	12.2	6.3	X30	70
3588535	6	200	12.2	6.3	X30	70
3588536	6	220	12.2	6.3	X30	70
3588537	6	240	12.2	6.3	X30	70
3588538	6	260	12.2	6.3	X30	70
3588539	6	280	12.2	6.3	X30	70
3588540	6	300	12.2	6.3	X30	70
3588541	8	80	15	7.4	X40	52
3588542	8	100	15	7.4	X40	60
3588543	8	120	15	7.4	X40	60
3588545	8	140	15	7.4	X40	60
3588546	8	160	15	7.4	X40	80
3588547	8	180	15	7.4	X40	80
3588548	8	200	15	7.4	X40	80
3588549	8	220	15	7.4	X40	80
3588550	8	240	15	7.4	X40	80
3588552	8	260	15	7.4	X40	80
3588553	8	280	15	7.4	X40	80
3588554	8	300	15	7.4	X40	80
3588555	8	320	15	7.4	X40	80
3588556	8	340	15	7.4	X40	80
3588557	8	360	15	7.4	X40	80
3588558	8	380	15	7.4	X40	80
3588559	8	400	15	7.4	X40	80
3668355	10	80	18.4	9.1	X40	52
3668356	10	100	18.4	9.1	X40	60
3668357	10	120	18.4	9.1	X40	60
3668361	10	180	18.4	9.1	X40	80
3668362	10	200	18.4	9.1	X40	80
3668363	10	220	18.4	9.1	X40	80
3668364	10	240	18.4	9.1	X40	80
3668365	10	260	18.4	9.1	X40	80
3668366	10	280	18.4	9.1	X40	80
3668367	10	300	18.4	9.1	X40	80
3668368	10	320	18.4	9.1	X40	80
3668369	10	340	18.4	9.1	X40	80
3668370	10	360	18.4	9.1	X40	80

Article no	d1	L	d2 max	k max	Hexalobular socket	b
3668371	10	380	18.4	9.1	X40	80