


SPAX®

BN 21601 - Hexalobular (6 Lobe) socket flat countersunk head screws T-STAR plus, fully threaded with CUT point



Manufacturer

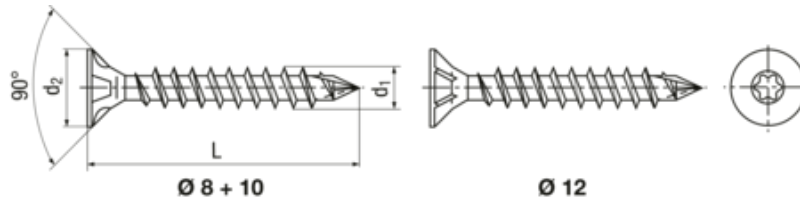

Product description

- Diameter 8 and 10: with MULTI head
- Diameter 12: cutting ribs under the head

Other documentation: www.spax.com

Additional information

For lateral pressure reinforcement, flexibly connected bending beams and lateral tension reinforcements

Headform

Countersunk

Drive

Hexalobular socket

Thread

fully threaded

Brand

SPAX®

Material

Steel

Material execution

case-hardened

Surface

WIROX® added lubricant

Version

with CUT point

Certificates



Warnings

ISO 4042

Quenched and tempered fasteners ≥ 360 HV and tempered case-hardened fasteners with electroplated coatings: Susceptible to hydrogen embrittlement!

Further notice to residual risks can be found in the introduction section.

Article no	d1	L	d2	Hexalobular socket
9017691	10	160	18.6	T50
9017678	8	120	15.1	T40
9017679	8	140	15.1	T40
3792700	8	160	15.1	T40
3792701	8	180	15.1	T40
3792702	8	200	15.1	T40
3792703	8	220	15.1	T40
3792704	8	240	15.1	T40
3792705	8	260	15.1	T40
3792706	8	280	15.1	T40
3792707	8	300	15.1	T40
3792708	8	350	15.1	T40
3792709	8	400	15.1	T40
3792710	8	450	15.1	T40
3792711	8	500	15.1	T40
3792712	8	550	15.1	T40
3792713	8	600	15.1	T40
9017690	10	120	18.6	T50
3792714	10	200	18.6	T50
3792715	10	220	18.6	T50
3792716	10	240	18.6	T50
3792718	10	260	18.6	T50
3792719	10	280	18.6	T50
3792720	10	300	18.6	T50
3792729	10	350	18.6	T50
3792730	10	400	18.6	T50
3792731	10	450	18.6	T50
3792732	10	500	18.6	T50
3792733	10	550	18.6	T50
3792734	10	600	18.6	T50
9017692	10	700	18.6	T50
3792735	10	800	18.6	T50
3792736	12	200	18.6	T50
3792737	12	240	18.6	T50
3792738	12	280	18.6	T50
3792739	12	300	18.6	T50
3792741	12	350	18.6	T50
3792742	12	400	18.6	T50
3792743	12	450	18.6	T50
3792744	12	500	18.6	T50
3792745	12	550	18.6	T50
3792746	12	600	18.6	T50