


Slotted round head wood screws

BN 951

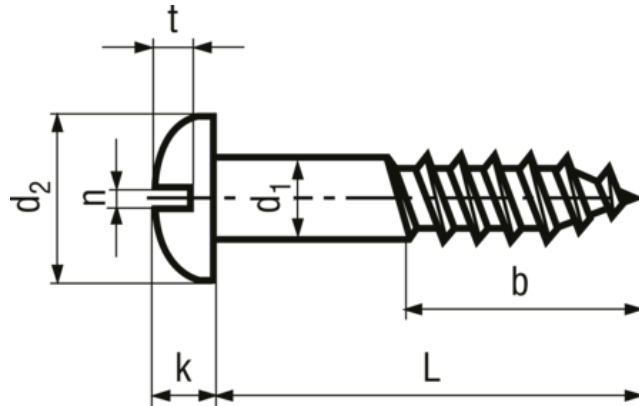

Additional information	Thread end at manufacturer's option, machined or rolled
Headform	Round
Drive	Slot
Thread	partially threaded
Material	Steel
Surface	zinc plated blue
Standard	DIN 96, ~UNI 701, ~ČSN 021812

Article no	d1	L	d2	k	n	t min	b
1069268	3	10	6	2.1	0.8	1.05	
1069306	3	20	6	2.1	0.8	1.05	
1069780	4	25	8	2.8	1	1.4	
1069802	4	35	8	2.8	1	1.4	
1070185	5	30	10	3.5	1.2	1.75	
1070207	5	40	10	3.5	1.2	1.75	
1070223	5	50	10	3.5	1.2	1.75	
1070347	6	35	12	4.2	1.6	2.1	
1070398	6	60	12	4.2	1.6	2.1	
3460197	2	8	4	1.4	0.5	0.7	
3460198	2	10	4	1.4	0.5	0.7	
3274288	2	12	4	1.4	0.5	0.7	
3460199	2	16	4	1.4	0.5	0.7	
3460201	2	20	4	1.4	0.5	0.7	
3460204	2.5	12	5	1.7	0.6	0.85	
1422642	2.5	16	5	1.7	0.6	0.85	

Article no	d1	L	d2	k	n	t min	b
3460205	2.5	20	5	1.7	0.6	0.85	
1422707	3	12	6	2.1	0.8	1.05	
1422723	3	16	6	2.1	0.8	1.05	
1069322	3	25	6	2.1	0.8	1.05	
1422774	3.5	16	7	2.4	0.8	1.2	
1069470	3.5	20	7	2.4	0.8	1.2	
1069497	3.5	25	7	2.4	0.8	1.2	
1069500	3.5	30	7	2.4	0.8	1.2	
1069519	3.5	35	7	2.4	0.8	1.2	
1069527	3.5	40	7	2.4	0.8	1.2	
1422812	4	16	8	2.8	1	1.4	
1069764	4	20	8	2.8	1	1.4	
1069799	4	30	8	2.8	1	1.4	
1069810	4	40	8	2.8	1	1.4	
1069837	4	50	8	2.8	1	1.4	
1069993	4.5	30	9	3.1	1	1.55	
1070010	4.5	40	9	3.1	1	1.55	
1070037	4.5	50	9	3.1	1	1.55	
1070142	5	20	10	3.5	1.2	1.75	
1070169	5	25	10	3.5	1.2	1.75	
1070231	5	60	10	3.5	1.2	1.75	
1070312	6	25	12	4.2	1.6	2.1	
1070339	6	30	12	4.2	1.6	2.1	
1070355	6	40	12	4.2	1.6	2.1	
1070371	6	50	12	4.2	1.6	2.1	