


Hexalobular (6 Lobe) socket pan head chipboard screws

BN 50046

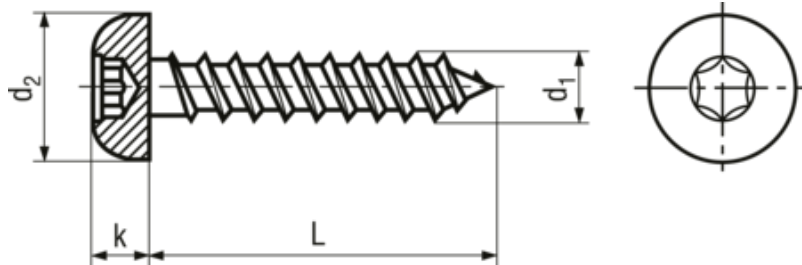

Headform	Round
Drive	Hexalobular socket
Thread	fully threaded
Material	Steel
Material execution	case-hardened
Surface	zinc plated blue, added lubricant
Warnings	ISO 4042 Quenched and tempered fasteners ≥ 360 HV and tempered case-hardened fasteners with electroplated coatings: Susceptible to hydrogen embrittlement! Further notice to residual risks can be found in the introduction section.

Article no	d1	L	Hexalobular socket	d2	k max
3059103	3	12	X10	6	2.65
3059104	3	16	X10	6	2.65
3059105	3	20	X10	6	2.65
3059106	3	25	X10	6	2.65
3059107	3	30	X10	6	2.65
3059110	3.5	20	X15	7	2.9
3059111	3.5	25	X15	7	2.9
3059112	3.5	30	X15	7	2.9
3059113	3.5	35	X15	7	2.9
3059114	3.5	40	X15	7	2.9
3059201	4.5	16	X25	9	3.5
3059202	4.5	20	X25	9	3.5
3059203	4.5	25	X25	9	3.5
3059204	4.5	30	X25	9	3.5

Article no	d1	L	Hexalobular socket	d2	k max
3059205	4.5	35	X25	9	3.5
3059207	4.5	40	X25	9	3.5
3059208	4.5	45	X25	9	3.5
3059209	4.5	50	X25	9	3.5
3059212	5	25	X25	10	3.8
3059216	5	45	X25	10	3.8
3059219	6	25	X30	12	4.4
3059221	6	35	X30	12	4.4
3059224	6	45	X30	12	4.4
3059108	3.5	12	X15	7	2.9
3059109	3.5	16	X15	7	2.9
3059115	4	16	X20	8	3.15
3059116	4	20	X20	8	3.15
3059195	4	25	X20	8	3.15
3059196	4	30	X20	8	3.15
3059197	4	35	X20	8	3.15
3059198	4	40	X20	8	3.15
3059199	4	45	X20	8	3.15
3059200	4	50	X20	8	3.15
3059210	5	16	X25	10	3.8
3059211	5	20	X25	10	3.8
3059213	5	30	X25	10	3.8
3059214	5	35	X25	10	3.8
3059215	5	40	X25	10	3.8
3059217	5	50	X25	10	3.8
3059218	5	60	X25	10	3.8
3059220	6	30	X30	12	4.4
3059222	6	40	X30	12	4.4
3059225	6	50	X30	12	4.4
3059226	6	60	X30	12	4.4
3270966	6	80	X30	12	4.4