


Hexalobular (6 Lobe) socket flat head countersunk screws double neck chipboard screws, partially threaded

BN 33022

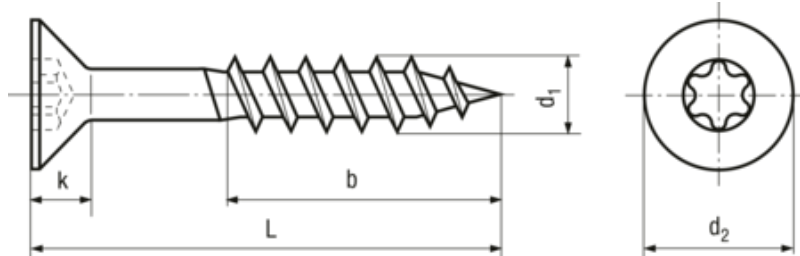

Product description

- Waxed

Headform

Countersunk

Drive

Hexalobular socket

Thread

partially threaded

Material

Stainless steel

Material type

A2

Article no	d1	L	d2 max	k max	Hexalobular socket	b
5813400	3	25	6	1.9	X10	16
5813410	3	30	6	1.9	X10	18
5813420	3	35	6	1.9	X10	22
5813430	3	40	6	1.9	X10	24
5813460	3.5	25	7	2.1	X15	16
5813470	3.5	30	7	2.1	X15	18
5813480	3.5	35	7	2.1	X15	22
5813490	3.5	40	7	2.1	X15	24
5813520	4	25	8	2.5	X20	16
5813530	4	30	8	2.5	X20	18
5813540	4	35	8	2.5	X20	22
5813550	4	40	8	2.5	X20	24
5813560	4	45	8	2.5	X20	28
5813570	4	50	8	2.5	X20	30
5813580	4	60	8	2.5	X20	36
5813590	4	70	8	2.5	X20	42
5813600	4.5	25	9	2.7	X20	16
5813610	4.5	30	9	2.7	X20	18

Article no	d1	L	d2 max	k max	Hexalobular socket	b
5813620	4.5	35	9	2.7	X20	22
5813630	4.5	40	9	2.7	X20	24
5813640	4.5	45	9	2.7	X20	28
5813650	4.5	50	9	2.7	X20	30
5813660	4.5	60	9	2.7	X20	36
5813670	4.5	70	9	2.7	X20	42
5813680	5	25	10	3	X25	16
5813690	5	30	10	3	X25	18
5813700	5	35	10	3	X25	22
5813710	5	40	10	3	X25	24
5813720	5	45	10	3	X25	28
5813730	5	50	10	3	X25	30
5813740	5	60	10	3	X25	36
5813750	5	70	10	3	X25	42
5813760	5	80	10	3	X25	50
3587193	5	90	10	3	X25	56
3587194	5	100	10	3	X25	60
3587195	5	120	10	3	X25	70
5813770	6	40	12	3.6	X25	24
3587196	6	45	12	3.6	X25	28
5813780	6	50	12	3.6	X25	30
5813790	6	60	12	3.6	X25	36
5813800	6	70	12	3.6	X25	42
5813810	6	80	12	3.6	X25	50
5813820	6	90	12	3.6	X25	56
5813830	6	100	12	3.6	X25	60
3587197	6	120	12	3.6	X25	70
3587198	6	140	12	3.6	X25	70
3587199	6	160	12	3.6	X25	100
3587200	6	180	12	3.6	X25	100
3587201	6	200	12	3.6	X25	100
3587202	6	220	12	3.6	X25	100
3587203	6	240	12	3.6	X25	64
3587204	8	60	14.5	4.6	X40	36
3587205	8	70	14.5	4.6	X40	42
3587206	8	80	14.5	4.6	X40	50
3587207	8	90	14.5	4.6	X40	56
3587208	8	100	14.5	4.6	X40	60
3587209	8	120	14.5	4.6	X40	70
3587210	8	140	14.5	4.6	X40	70
3587211	8	160	14.5	4.6	X40	100
3587212	8	180	14.5	4.6	X40	100
3587213	8	200	14.5	4.6	X40	100