


# SPAX®

BN 3548 - Pozi Flat countersunk head chipboard screws form Z, partially threaded with 4CUT point

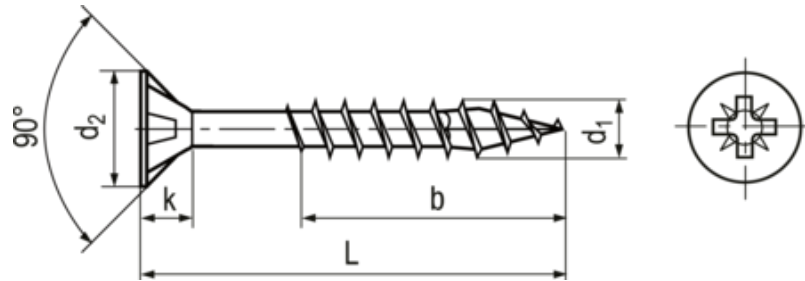

|                        |                                                                                                                                                                                                                                                                            |
|------------------------|----------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| Manufacturer           | <b>SPAX®</b>                                                                                                                                                                                                                                                               |
| Product description    | Other documentation: <a href="http://www.spax.com">www.spax.com</a>                                                                                                                                                                                                        |
| Additional information | The YELLOX® coating is an alternative chromium free (VI) surface coating with considerably higher corrosion protection compared to yellow electrogalvanizing.                                                                                                              |
| Headform               | Countersunk                                                                                                                                                                                                                                                                |
| Drive                  | Cross recess Z (Pozidriv)                                                                                                                                                                                                                                                  |
| Thread                 | partially threaded                                                                                                                                                                                                                                                         |
| Brand                  | SPAX®                                                                                                                                                                                                                                                                      |
| Material               | Steel                                                                                                                                                                                                                                                                      |
| Material execution     | case-hardened                                                                                                                                                                                                                                                              |
| Surface                | zinc plated yellow/YELLOX®, waxed                                                                                                                                                                                                                                          |
| Version                | with 4CUT point                                                                                                                                                                                                                                                            |
| Certificates           | <b>CE</b>                                                                                                                                                                                                                                                                  |
| Warnings               | <p>ISO 4042</p> <p>Quenched and tempered fasteners <math>\geq 360</math> HV and tempered case-hardened fasteners with electroplated coatings: Susceptible to hydrogen embrittlement!</p> <p>Further notice to residual risks can be found in the introduction section.</p> |

4CUT cutter for screw lengths of 160 mm and over (Significantly reduces the screwing torque).

|            |   |    |   |    |       |          |   |
|------------|---|----|---|----|-------|----------|---|
| Article no | p | d1 | L | d2 | k max | Pozidriv | b |
|------------|---|----|---|----|-------|----------|---|

| Article no | p    | d1  | L   | d2   | k max | Pozidriv | b  |
|------------|------|-----|-----|------|-------|----------|----|
| 1836528    | 1000 | 3.5 | 35  | 7    | 2.1   | 2        | 23 |
| 1836536    | 1000 | 3.5 | 40  | 7    | 2.1   | 2        | 23 |
| 1836560    | 1000 | 4   | 35  | 8    | 2.4   | 2        | 23 |
| 1836579    | 1000 | 4   | 40  | 8    | 2.4   | 2        | 23 |
| 1836587    | 500  | 4   | 45  | 8    | 2.4   | 2        | 30 |
| 1836595    | 500  | 4   | 50  | 8    | 2.4   | 2        | 32 |
| 1836609    | 500  | 4   | 60  | 8    | 2.4   | 2        | 35 |
| 1836633    | 500  | 4.5 | 40  | 8.8  | 2.7   | 2        | 25 |
| 1836641    | 500  | 4.5 | 45  | 8.8  | 2.7   | 2        | 30 |
| 1836668    | 500  | 4.5 | 50  | 8.8  | 2.7   | 2        | 32 |
| 1836676    | 500  | 4.5 | 60  | 8.8  | 2.7   | 2        | 37 |
| 1836684    | 500  | 4.5 | 70  | 8.8  | 2.7   | 2        | 42 |
| 1836692    | 200  | 4.5 | 80  | 8.8  | 2.7   | 2        | 59 |
| 1836722    | 500  | 5   | 50  | 9.7  | 2.9   | 2        | 32 |
| 1836730    | 500  | 5   | 60  | 9.7  | 2.9   | 2        | 37 |
| 1836749    | 200  | 5   | 70  | 9.7  | 2.9   | 2        | 41 |
| 1836757    | 200  | 5   | 80  | 9.7  | 2.9   | 2        | 46 |
| 1836765    | 200  | 5   | 90  | 9.7  | 2.9   | 2        | 61 |
| 1836773    | 200  | 5   | 100 | 9.7  | 2.9   | 2        | 61 |
| 1722018    | 200  | 5   | 110 | 9.7  | 2.9   | 2        | 69 |
| 1722042    | 200  | 5   | 120 | 9.7  | 2.9   | 2        | 69 |
| 1836811    | 200  | 6   | 70  | 11.6 | 3.4   | 3        | 41 |
| 1836838    | 200  | 6   | 80  | 11.6 | 3.4   | 3        | 46 |
| 1836846    | 200  | 6   | 90  | 11.6 | 3.4   | 3        | 61 |
| 1836854    | 100  | 6   | 100 | 11.6 | 3.4   | 3        | 61 |
| 1836870    | 100  | 6   | 120 | 11.6 | 3.4   | 3        | 68 |
| 1836897    | 100  | 6   | 140 | 11.6 | 3.4   | 3        | 68 |
| 1836919    | 100  | 6   | 160 | 11.6 | 3.4   | 3        | 65 |