


Hexalobular (6 Lobe) socket flat countersunk head screws

BN 20925

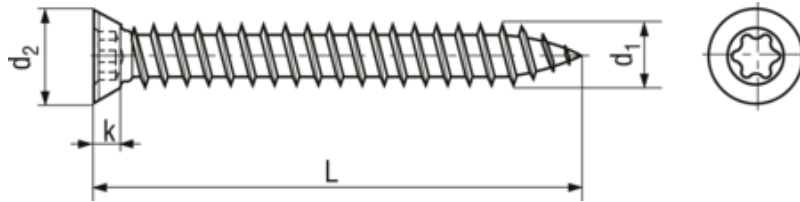

Headform	Countersunk
Drive	Hexalobular socket
Thread	fully threaded
Material	Steel
Material execution	case-hardened
Surface	zinc plated blue, added lubricant
Warnings	ISO 4042 Quenched and tempered fasteners ≥ 360 HV and tempered case-hardened fasteners with electroplated coatings: Susceptible to hydrogen embrittlement! Further notice to residual risks can be found in the introduction section.

Article no	d1	L	d2	k~	Hexalobular socket
9019225	7.5	240	11.5	3	X30
9019226	7.5	270	11.5	3	X30
9019227	7.5	320	11.5	3	X30
3615150	7.5	40	11	3	X30
3615151	7.5	50	11	3	X30
3615152	7.5	60	11	3	X30
3615153	7.5	70	11	3	X30
3615154	7.5	80	11	3	X30
3615155	7.5	90	11	3	X30
3615156	7.5	100	11	3	X30
3615157	7.5	110	11.5	3	X30
3615158	7.5	120	11.5	3	X30
3615159	7.5	130	11.5	3	X30
3615160	7.5	150	11.5	3	X30

Article no	d1	L	d2	k~	Hexalobular socket
3615161	7.5	180	11.5	3	X30
3615162	7.5	210	11.5	3	X30