

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1727040130

Status:


Active

Overview:

FCT D-Sub Connectors

Description:

FCT Coaxial Contact, Male, Straight, Solder Cable Termination, 50 Ohms, 1.30µm Gold Plating, without Inspection Hole, for RG-174U, RG-188AU, or RG-316U Cable

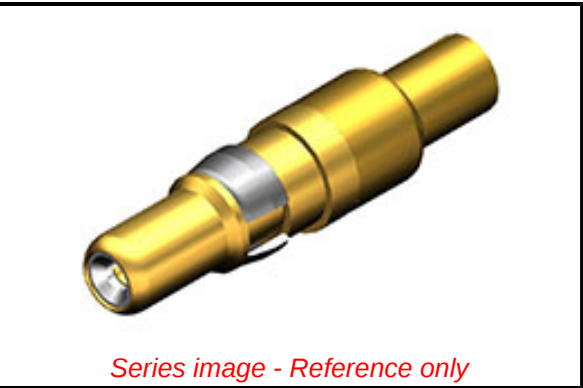

Documents:

[Drawing \(PDF\)](#)

[Application Specification 2195600660-000 \(PDF\)](#)

[Brochure \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

General	
Product Family	D-Sub Products
Series	172704
Contact Type	Coaxial
Overview	FCT D-Sub Connectors
Product Category	Contacts
Product Name	FCT Products
Taxonomy	D-Sub Contacts
Type	Mixed Layout
UPC	889056020411
Wire/Cable Type	RG-174U, RG-188AU, RG-316U
Physical	
Durability (mating cycles max)	200
Gender	Male
Material - Contact	Copper Alloy
Net Weight	1.400/g
Orientation	Straight
Packaging Type	Bag
Plating - Contact	Gold over Nickel
Plating min - Mating	1.300µm
Plating min - Termination	1.300µm
Temperature Range - Operating	-55° to +135°C
Termination Style	Solder
Electrical	
Current - Maximum per Contact	2.0A
Impedance	50Ω
Material Info	
Engineering Number	FMX006P102
Reference - Drawing Numbers	
Application Specification	2195600660-000
Sales Drawing	1731120935-000

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant with Exemption 6(c)	
REACH SVHC	
Contained Per - D(2022)4187-DC (10 June 2022)	
Lead	
Halogen-Free	
Status	
Not Relevant	
For more information, please visit Contact US	
China ROHS	Not Relevant
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

172704 Series

Use With

FCT Mixed Layout Connectors

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION