

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0039013123

Status:


Active

Overview:

Mini-Fit Family Power Connectors

Description:

Mini-Fit Jr. Plug Housing, Dual Row, 12 Circuits, UL 94V-2, without Panel Mounting Ears, Natural

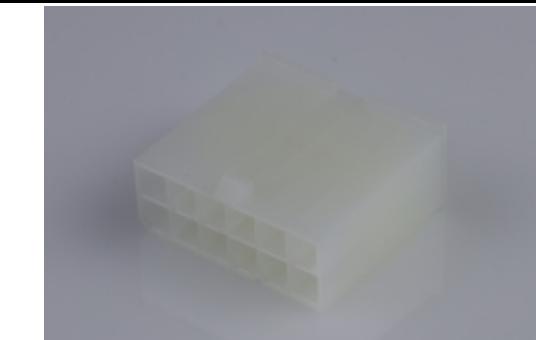

Series image - Reference only

Documents:

- [3D Model \(PDF\)](#)[Drawing \(PDF\)](#)[3D Model](#)[Product Specification PS-45750-001-001 \(PDF\)](#)[Product Specification PS-5556-001-001 \(PDF\)](#)[Application Specification 55560001-AS-000 \(PDF\)](#)
- [Application Specification AS-5557-001-001 \(PDF\)](#)[Packaging Specification PK-5559-002-001 \(PDF\)](#)[Test Summary 55560010-TS-000 \(PDF\)](#)[Test Summary TS-5556-002-001 \(PDF\)](#)[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA

UL

LR19980

E29179

General

Product Family

Series

Application

Comments

Crimp Housings

5559

Power, Wire-to-Board, Wire-to-Wire

Current = 13A max. per circuit when header is mated to a receptacle loaded with 45750 series terminals crimped to 16 AWG wire. See Molex product specification PS-45750-001 for additional current derating information.

Mini-Fit Family Power Connectors

Mini-Fit Jr.

Connector Housings

800754204071

Overview

Product Name

Taxonomy

UPC

Physical

Breakaway

Circuits (maximum)

Color - Resin

Flammability

Gender

Glow-Wire Capable

Keying to Mating Part

Lock to Mating Part

Material - Resin

Net Weight

Number of Rows

Packaging Type

Panel Mount

Pitch - Mating Interface

Pitch - Termination Interface

Polarized to Mating Part

Stackable

Temperature Range - Operating

No

12

Natural

94V-2

Plug

No

None

Yes

Nylon

3.279/g

2

Bag

No

4.20mm

4.20mm

Yes

No

-40° to +105°C

Electrical

Current - Maximum per Contact

13.0A

Solder Process Data

Lead-freeProcess Capability

N/A

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[5559](#) Series

Mates With

Mini-Fit Jr. Receptacle Housing [5557](#)

Use With

Mini-Fit Male Crimp Terminals [5558](#)

Mini-Fit Plus HCS Crimp Terminals [46012](#)
Mini-Fit Jr. Grounding Pin [30490](#)

Mini-Fit Pre-Crimped Leads [797580005](#)
, [797580013](#)
Mini-Fit Jr. Backshell [204723](#)

Material Info

Engineering Number 5559-12P1

Reference - Drawing Numbers

Application Specification 55560001-AS-000, AS-5557-001-001
Packaging Specification PK-5559-002-001
Product Specification PS-45750-001-001, PS-5556-001-001
Sales Drawing 55590001-SD-000
Test Summary 55560010-TS-000, TS-5556-002-001

This document was generated on 10/19/2022

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION