

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

5022441530

Status:


Active

Overview:

Easy-On FFC FPC Connectors

Description:

0.50mm Pitch Easy-On FFC/FPC Connector, For LVDS, 2.33mm Height, Right-Angle, Surface Mount, ZIF, Bottom Contact Style, 15 Circuits

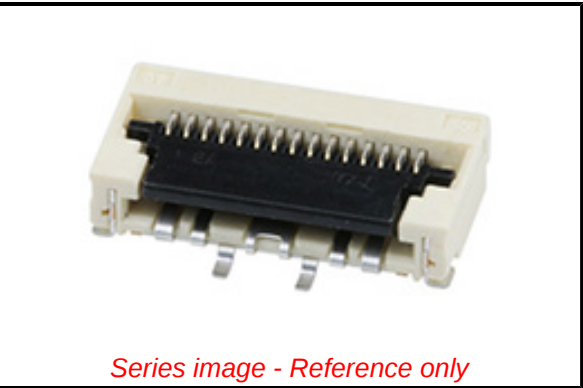

Documents:	
3D Model (PDF)	Product Specification PS-502244-001-001 (PDF)
3D Model	Packaging Specification 5022449200-SPK-200 (PDF)
Drawing (PDF)	RoHS Certificate of Compliance (PDF)

General	
Product Family	FFC/FPC Connectors
Series	502244
Overview	Easy-On FFC FPC Connectors
Product Name	Easy-On
Taxonomy	FFC / FPC Connectors
UPC	822350698825
Physical	
Actuator Type	Front Flip
Circuits (Loaded)	15
Color - Resin	Black, Natural
Contact Position	Bottom
Durability (mating cycles max)	20
Mated Height	2.33mm
Material - Metal	Phosphor Bronze
Material - Plating Mating	Gold
Material - Plating Termination	Gold
Net Weight	183.496/mg
Number of Rows	1
Orientation	Right Angle
PCB Locator	No
PCB Mounting	Surface Mount
PCB Retention	Yes
Packaging Type	Embossed Tape on Reel
Pitch - Mating Interface	0.50mm
Polarized to PCB	Yes
Stackable	No
Temperature Range - Operating	-25° to +85°C
Wire/Cable Type	FFC/FPC
Electrical	
Current - Maximum per Contact	0.4A
Voltage - Maximum	50V
Material Info	
Reference - Drawing Numbers	
Packaging Specification	5022449200-SPK-200
Product Specification	PS-502244-001-001
Sales Drawing	SD-502244-001-001, SD-502244-002-001, SD-502244-002-002, SD-502244-002-003

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - D(2022)4187-DC (10 June 2022)	
Halogen-Free	
Status	
Not Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

502244 Series

Mates With

Premo-Flex LVDS Cable [15021](#)