

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

5601230800

Status:


Active

Overview:

DuraClik Connector System

Description:

DuraClik ISL Wire-to-Board Receptacle Housing, Single Row, White, 8 Circuits

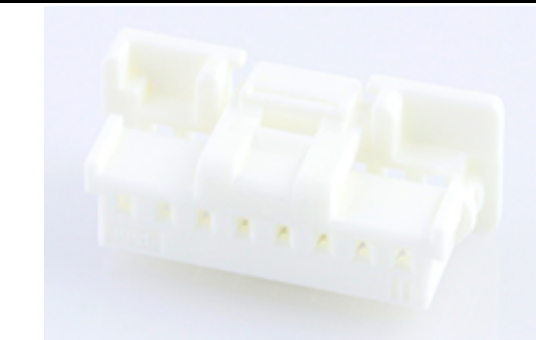

Series image - Reference only

- Documents:
- 3D Model

Application Specification AS-560123-001-001 (PDF)
- 3D Model (PDF)

Packaging Specification PK-560123-001-001 (PDF)
- Drawing (PDF)

Datasheet (PDF)
- Product Specification PS-560123-001-001 (PDF)

RoHS Certificate of Compliance (PDF)
- Product Specification PS-560123-003-001 (PDF)

Agency Certification	
UL	E29179
General	
Product Family	Crimp Housings
Series	560123
Application	Automotive, Signal, Wire-to-Board
Overview	DuraClik Connector System
Product Name	DuraClik
Taxonomy	Connector Housings
UPC	889056009553
Physical	
Circuits (maximum)	8
Color - Resin	White
Gender	Receptacle
Glow-Wire Capable	No
Keying to Mating Part	None
Lock to Mating Part	Yes
Material - Resin	PBT
Net Weight	0.455/g
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	2.00mm
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	-40° to +130°C
Solder Process Data	
Lead-freeProcess Capability	N/A
Material Info	
Reference - Drawing Numbers	
Application Specification	AS-560123-001-001
Packaging Specification	PK-560123-001-001
Product Specification	PS-560123-001-001, PS-560123-003-001
Sales Drawing	SD-560123-005-001

EU ELV

Compliant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per - D(2022)4187-DC (10 June 2022)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

Green Image

ELV

Compliant

RoHS Phthalates

Not Contained

Search Parts in this Series

560123 Series

Mates With

DuraClik Right-Angle Header [502352](#)
DuraClik Vertical Header [560020](#)

Use With

DuraClik ISL Terminal [560124](#)
DuraClik ISL Retainer [5601250800](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION