
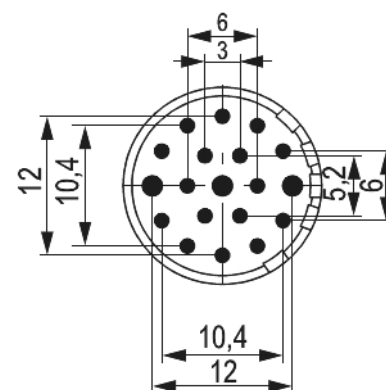


Contact insert M23 Signal - 19-pole (solder)

Item number 7001919103

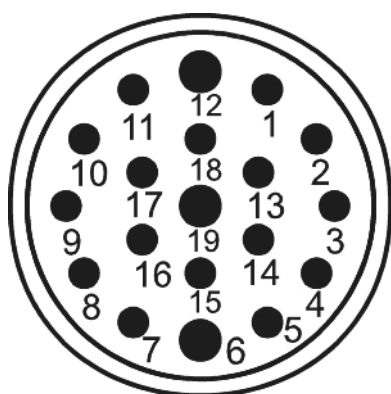

Technical data

Characteristic of connection	Solder
Number of poles	19
Pole picture	19
	Pinout clockwise
Insert	Pin
Color contact insert	white
Material insulating body	PA 6 , PBT
Number of contacts signal	16
Number of contacts power	3
Contact-Ø signal	1 mm
Contact-Ø power	1.5 mm
Nominal current signal	8 A
Nominal current power	10 A
Nominal voltage at degree of pollution 3 signal	100 V~



Contact insert M23 Signal - 19-pole (solder)

Item number 7001919103

Nominal voltage at degree of pollution 3 power	100 V~
Test voltage signal	1500 V~
Test voltage power	1500 V~
Insulation resistance signal	$> 10^6$
Insulation resistance power	$> 10^6$
max. contact resistance signal	3 mOhm
max. contact resistance power	3 mOhm
Temperature range	-40°C to +125°C
Degree of Protection	3
Flammability	V-0 (UL 94)

Contact insert M23 Signal - 19-pole (solder)

Item number 7001919103

Commercial data

Packaging Unit	25
EAN code	4033878500651
Weight	0.00346 kg
ETIM 7	EC003557
ETIM 8	EC003557
eCl@ss 10.1	27440223
Customs tariff number	85369010

Note:

