

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0701070004

Status:


Active

Overview:

SL Modular Connectors

Description:

SL Wire-to-Wire Crimp Housing, Single Row, Version A, without Mounting Ears, 5 Circuits, Black

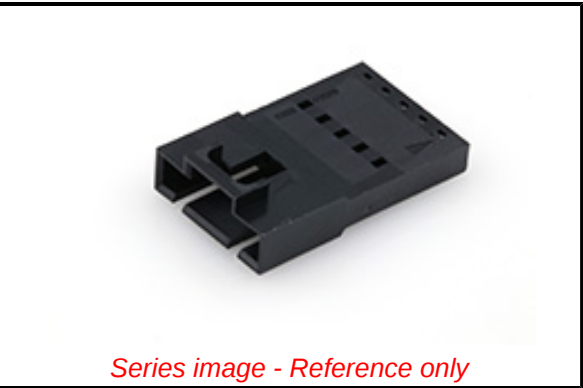

Documents:	
3D Model (PDF)	Product Specification PS-70400-001 (PDF)
3D Model	Packaging Specification PK-70107-100-001 (PDF)
Drawing (PDF)	RoHS Certificate of Compliance (PDF)

Agency Certification	
CSA	LR19980
UL	E29179
General	
Product Family	Crimp Housings
Series	70107
Application	Signal, Wire-to-Wire
Comments	Version A without Mounting Ears
Overview	SL Modular Connectors
Product Name	SL
Taxonomy	Connector Housings
UPC	800753560802
Physical	
Circuits (maximum)	5
Color - Resin	Black
Flammability	94V-0
Gender	Plug
Glow-Wire Capable	No
Lock to Mating Part	Yes
Material - Resin	Polyester
Net Weight	0.920/g
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	2.54mm
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	-40° to +105°C
Solder Process Data	
Lead-freeProcess Capability	N/A
Material Info	
Reference - Drawing Numbers	
Packaging Specification	PK-70107-100-001
Product Specification	PS-70400-001
Sales Drawing	SD-70107-0001-0024-001

EU ELV

Compliant

EU RoHS

Compliant

REACH SVHC

Not Contained Per - D(2022)4187-DC (10 June 2022)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

Green Image

ELV

Compliant

RoHS Phthalates

Not Contained

Search Parts in this Series

70107 Series

Mates With

SL Crimp Housing Versions A, G and D Only [70066](#) (Version C and H will not mate to the 70107 housing series) . SL Insulation Displacement Connector Assembly, Version G Housing [70400](#) . SL Single Row Receptacle, Version G [70430](#)

Use With

[70021](#) SL Crimp Terminal

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION