

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0936010708

Status:


Active

Overview:

GWconnect Heavy Duty Connectors (HDC)

Description:

GWconnect STD - Standard, Cover for Male Inserts, Polyamide, with 2 Pegs, with Gasket, Size 3A «21x21», Grey

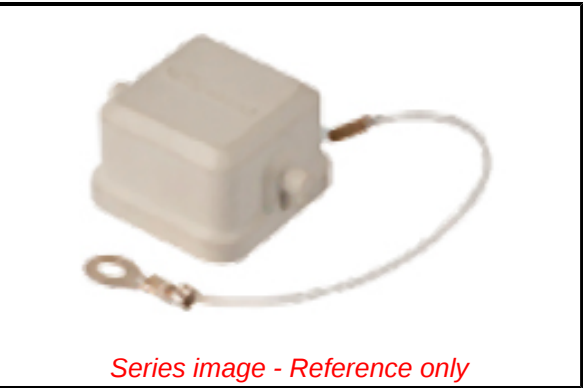

Documents:	
Drawing (PDF)	RoHS Certificate of Compliance (PDF)
Agency Certification	
CSA	256883
UL	E249674
General	
Product Family	Industrial Connectors / Enclosures
Series	93601
Comments	With nylon wire tether line.
Component Size	3A «21x21»
Component Type	Cover
IP Rating	IP66, IP67
Overview	GWconnect Heavy Duty Connectors (HDC)
Product Category	Heavy Duty Connectors
Product Name	GWconnect
Standard	ANSI/UL 50, ANSI/UL 50 E, CSA C22.2 No.94-1-2, EN 61984
Taxonomy	Heavy-Duty Connectors
Type	STD
UPC	887191844152
Physical	
Cover Color	Grey RAL 9002
Flammability	UL 94V-0
Lock to Mating Part	Yes
Material - Cover	Polyamide
Material - Gasket	NBR
Material - Peg	Polyamide
Net Weight	4.400/g
Number of Pegs	2
Packaging Type	Bag
Thread Size	N/A
Thread Type	N/A
Electrical	
Voltage - Maximum	230V / 400V
Material Info	
Engineering Number	7803.6803.0
Reference - Drawing Numbers	
Sales Drawing	936010708-000

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
ED/71/2019 (16 July
2019)

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

ZZCERT_CE -

Declaration of

Conformity

China RoHS

Green Image

Not Relevant

Not Contained

CER_4000432592_00_000.pdf

Search Parts in this Series

93601 Series

Use With

Size 3A «21x21» Housings and Female
Inserts

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION