




Specification:

Model	DC.CAB.4200.0150
DC PLUG	5.5/2.1 mm
Recommended voltage	0 - 48V
Max Current	5A
Dielectric Strenght	500 VDC
Operating temperature	-25°C to +70°C
Cord Lenght	1500mm
Cable Diameter	Ø 4 mm
Wire Diameter	2x0,5mm ²
ROHS	+

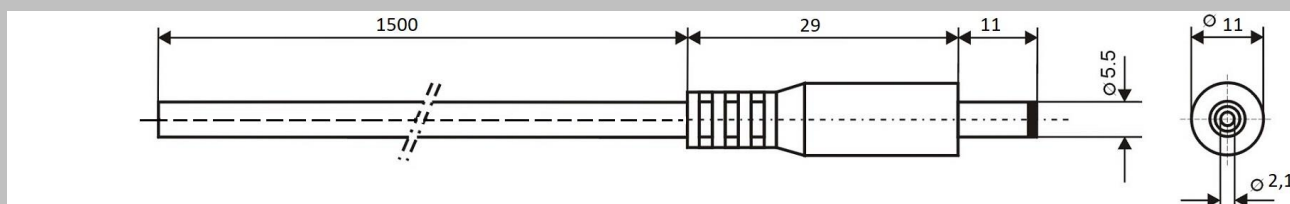

Made in Poland