


LOW VOLTAGE DC CABLE



Specification:

Model	DC.CAB.8010.0020
DC Socket	5.5/2.1 mm
Recommended voltage	0 - 48V
Max Current	5 A
Dielectric Strength	500 VDC
Operating temperature	-25°C to +70°C
Cord Length	250 mm
Cable Diameter	2,00 x 4,10 mm
Wire Diameter	2x0,5mm ²
ROHS	+

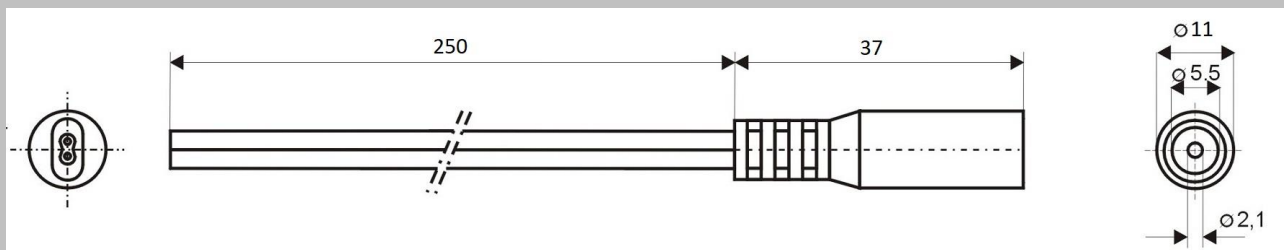

Made in Poland