


LOW VOLTAGE DC CABLE



Specification:

Model	DC.EXT.8610.0500
DC Socket / Plug	5.5/2.5 mm - 5.5/2.5 mm
Recommended voltage	0 - 48V
Max Current	5 A
Dielectric Strenght	500 VDC
Operating temperature	-25°C to +70°C
Cord Lenght	5000 mm
Cable Diameter	2,00 x 4,10 mm
Wire Diameter	2x0,5mm ²
ROHS	+

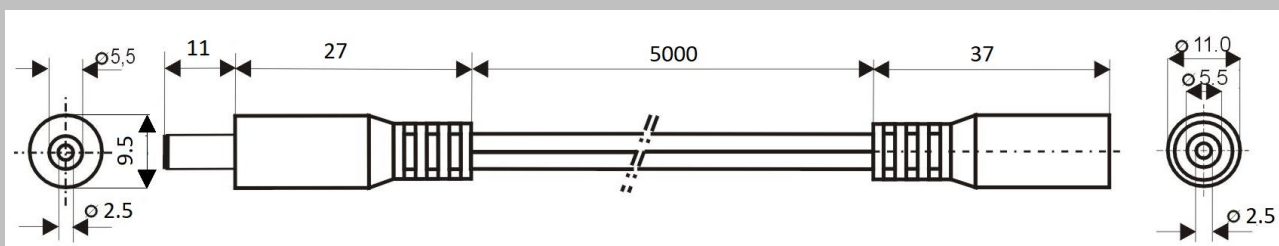

Made in Poland