




Specification:

Model	DC.EXT.4600.0300
DC Socket / PLUG	5.5/2.5 mm / 5.5/2.5 mm
Recommended voltage	0 - 48V
Max Current	5A
Dielectric Strenght	500 VDC
Operating temperature	-25°C to +70°C
Cord Lenght	3000 mm
Cable Diameter	Ø 4 mm
Wire Diameter	2x0,5mm ²
ROHS	+

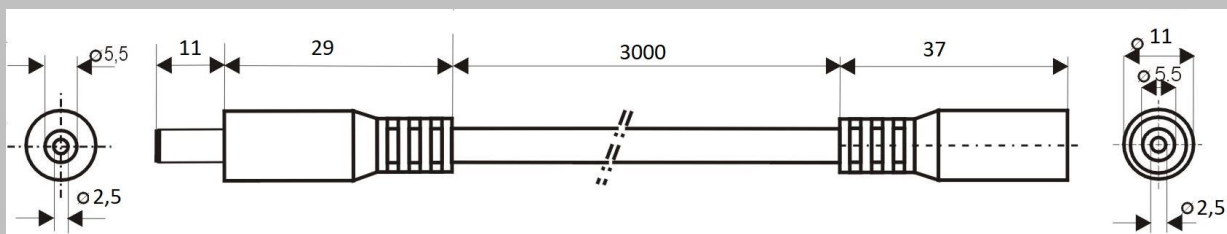

Made in Poland