


LOW VOLTAGE DC CABLE



Specification:

Model	DC.EXT.6600.0200
DC Socket / Plug	5.5/2.5 mm / 5.5/2.5 mm
Recommended voltage	0 - 48V
Max Current	3 A
Dielectric Strength	500 VDC
Operating temperature	-25°C to +70°C
Cord Length	2000 mm
Cable Diameter	1,62 x 3,42 mm
Wire Diameter	2x0,35mm ²
ROHS	+

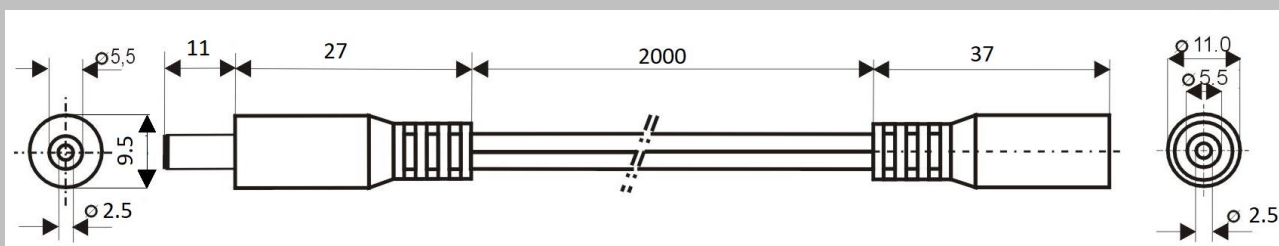

Made in Poland