


Hex socket head cap screws with low head, partially / fully threaded

BN 2844

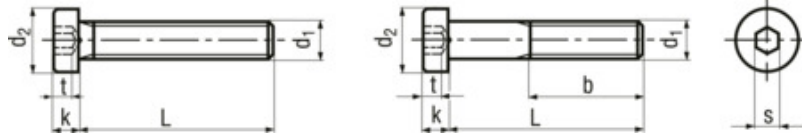

Standard

DIN 7984, ~UNI 9327

Product description

- Tensile strength min. 600 N/mm²
- Proof stress 0,2% min. 450 N/mm²

Headform

Cylindrical low

Drive

Hexagon socket

Thread

partially / fully threaded

Material

Stainless steel

Material type

A2

b: the partially threaded version can not always be guaranteed

Article no.	d1	L	d2	b	k	s	t
1256556	M3	5	5,5	-	2	2	1,5
1256580	M3	6	5,5	-	2	2	1,5
1568736	M3	8	5,5	-	2	2	1,5
1489380	M3	10	5,5	-	2	2	1,5
1489399	M3	12	5,5	-	2	2	1,5
1489402	M3	16	5,5	-	2	2	1,5
1489410	M3	20	5,5	12	2	2	1,5
1489429	M3	25	5,5	12	2	2	1,5
1568744	M4	6	7	-	2,8	2,5	2,3
1568752	M4	8	7	-	2,8	2,5	2,3
1489437	M4	10	7	-	2,8	2,5	2,3
1489445	M4	12	7	-	2,8	2,5	2,3
1489453	M4	16	7	-	2,8	2,5	2,3
1489461	M4	20	7	-	2,8	2,5	2,3

Article no.	d1	L	d2	b	k	s	t
1489488	M4	25	7	14	2,8	2,5	2,3
1489496	M4	30	7	14	2,8	2,5	2,3
1568760	M5	8	8,5	-	3,5	3	2,7
1489518	M5	10	8,5	-	3,5	3	2,7
1489526	M5	12	8,5	-	3,5	3	2,7
1489534	M5	16	8,5	-	3,5	3	2,7
1489542	M5	20	8,5	-	3,5	3	2,7
1489550	M5	25	8,5	-	3,5	3	2,7
1489569	M5	30	8,5	16	3,5	3	2,7
1489577	M5	35	8,5	16	3,5	3	2,7
1489585	M5	40	8,5	16	3,5	3	2,7
1568779	M6	8	10	-	4	4	3
1568787	M6	10	10	-	4	4	3
1489593	M6	12	10	-	4	4	3
1489607	M6	16	10	-	4	4	3
1489615	M6	20	10	-	4	4	3
1489623	M6	25	10	-	4	4	3
1489631	M6	30	10	18	4	4	3
1489658	M6	35	10	18	4	4	3
1489666	M6	40	10	18	4	4	3
1489674	M6	45	10	18	4	4	3
1489682	M6	50	10	18	4	4	3
1489690	M6	60	10	18	4	4	3
1568795	M8	10	13	-	5	5	3,8
1568809	M8	12	13	-	5	5	3,8
1489704	M8	16	13	-	5	5	3,8
1489712	M8	20	13	-	5	5	3,8
1489720	M8	25	13	-	5	5	3,8
1489739	M8	30	13	-	5	5	3,8
1489747	M8	35	13	22	5	5	3,8
1489755	M8	40	13	22	5	5	3,8
1489763	M8	45	13	22	5	5	3,8
1489771	M8	50	13	22	5	5	3,8
1489798	M8	60	13	22	5	5	3,8
5519085	M8	70	13	22	5	5	3,8
1568825	M10	16	16	-	6	7	4,5
1489801	M10	20	16	-	6	7	4,5
1489828	M10	25	16	-	6	7	4,5
1489836	M10	30	16	-	6	7	4,5
1489844	M10	35	16	-	6	7	4,5
1489852	M10	40	16	26	6	7	4,5
1489860	M10	45	16	26	6	7	4,5
1489879	M10	50	16	26	6	7	4,5
1489887	M10	60	16	26	6	7	4,5
1489895	M10	70	16	26	6	7	4,5
1489909	M10	80	16	26	6	7	4,5
1568833	M12	20	18	-	7	8	5
1568841	M12	25	18	-	7	8	5
1568876	M12	30	18	-	7	8	5
1568884	M12	35	18	-	7	8	5

Article no.	d1	L	d2	b	k	s	t
1568892	M12	40	18	-	7	8	5
1568914	M12	50	18	30	7	8	5