

Heavy duty diagonal cutting nippers

466/4G



Profiles




Standards

DIN ISO 5749

Product features

- material: premium plus carbon steel
- drop forged, entirely hardened and tempered
- cutting edges induction hardened
- head surface finish: finely ground
- surface finish: phosphated to standard ISO 9717
- heavy duty plastic handles
- made according to standard ISO 5749

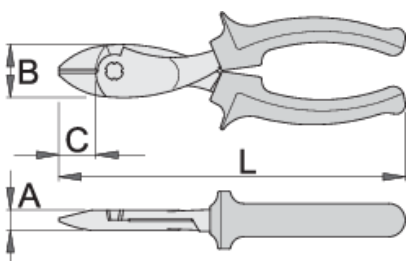

	L	B	A	C	
617687	160	23.5	10	20.5	214
608700	180	28	11	20	313
609190	200	27	11	21	344

cutting capacity (10N=1kg)

	L	max 2150 N/mm² 	max 650 N/mm² 
617687	160	1,6	2,5
608700	180	1,8	3,0
609190	200	2,0	3,5

* Images of products are symbolic. All dimensions are in mm, and weight in grams. All listed dimensions may vary in tolerance.

Photo (pictures)

