

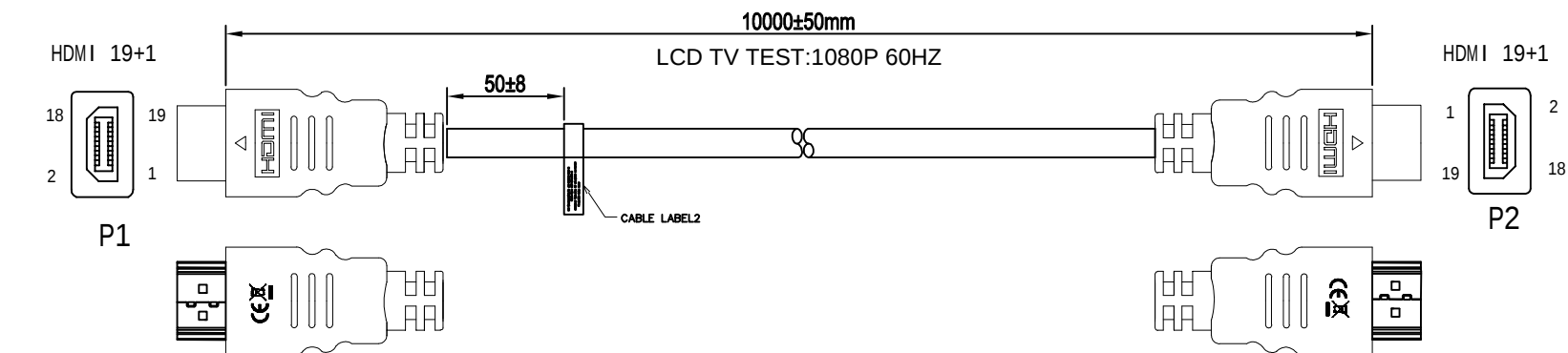


REACH&RoHS Compliant

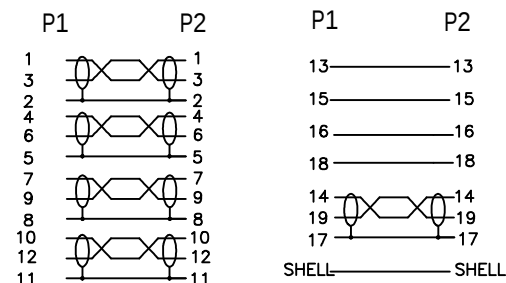


PIN OUT

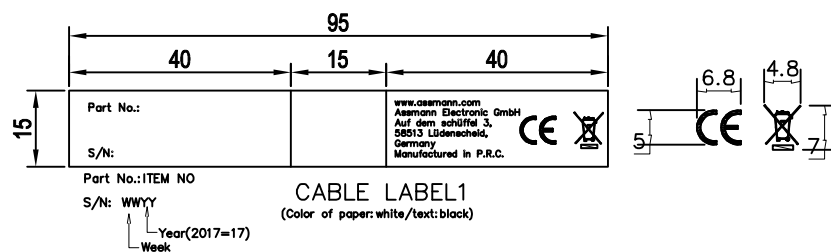

NOTE:

1. CABLE: (1/0.254BC/PE*2C+1/0.254CCS+AL)*5P+1/0.254BC/PE*4C+AL+1/0.254BC+80/0.12MG OD:6.0 JACKET COLOR:BLACK
CABLE PRINT:High Speed HDMI Cable with Ethernet Assmann Electronic GmbH, 58513 Lüdenscheld, Germany
2. LENGTH:10M
3. CONNECTOR: HDMI A/M,Black Insulator,Shell:Gold plated,Contact:Gold plated
4. MOLD: ASS'Y TYPE--MOLDING TYPE.
5. OPEN/SHORT TEST: 100% TEST.
A.100% OPEN,SHORT&INTERMITANCE TEST.
B.CONDUCTOR RESISTANCE:3ohms MAX:
C.INSULATION RESISTANCE:5M Min/,10ms:
6. ALL MUST BE ROHS COMPLIANT.
- Cross Section:
- 
- Twist pair Outer Jacket
- | | |
|------------|------|
| | |
| Drawn by | 2022 |
| Checked by | |

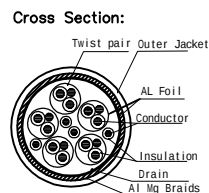

		Date	Name	Part No. AK-330107-100-S EAN:4016032307051		
Drawn by		2022/7/6				
Checked by						
Approved by						
ASSMANN Electronic GmbH				Title HDMI CONNECTION CABLE		
				Scale	N/A	Sheet 1/2
				Unit	MM	

87363

	1	2	3	4	5	6	7																	
A	Package Details Single Cable REACH&RoHS Compliant 105mm 70mm Item code AK-330107-100-S Description HDMI High Speed connection cable Properties Type A MM: 10.0m HDMI 1.4 gdd. bl www.assmann.com ASSMANN Electronic GmbH Am Alten Gießhof 2 40160 Cologne Germany 01812000000 www.assmann.com ASSMANN Electronic GmbH Am Alten Gießhof 2 40160 Cologne Germany 01812000000 4016032307051 CE 10 m HEAT SEALED							A																
B	<table><tr><th>P/N</th><th>Cable Length</th><th>Rolling Size (Single Cable)</th><th>Polybag Type (Single Cable)</th><th>Bag Size (Single Cable)</th><th>Article Weight (Single Cable)</th></tr><tr><td>AK-330107-100-S</td><td>10M</td><td>220mm max</td><td>DIGITUS polybag</td><td>280*390mm</td><td>0.615kg</td></tr></table>							P/N	Cable Length	Rolling Size (Single Cable)	Polybag Type (Single Cable)	Bag Size (Single Cable)	Article Weight (Single Cable)	AK-330107-100-S	10M	220mm max	DIGITUS polybag	280*390mm	0.615kg	B				
P/N	Cable Length	Rolling Size (Single Cable)	Polybag Type (Single Cable)	Bag Size (Single Cable)	Article Weight (Single Cable)																			
AK-330107-100-S	10M	220mm max	DIGITUS polybag	280*390mm	0.615kg																			
C	Inner Packing Unit <table><tr><th>P/N</th><th>Cable Length</th><th>Quantity (Inner Packing Unit)</th><th>Type (Inner Packing Unit)</th><th>Size (Inner Packing Unit)</th><th>Weight (Inner Packing Unit)</th></tr><tr><td>AK-330107-100-S</td><td>10M</td><td>5pcs</td><td>neutral polybag</td><td>400*530mm</td><td>3kg</td></tr></table> Code 39 – it is 11 numbers which will be found on PO. (it is changeable) Inner Packing Unit							P/N	Cable Length	Quantity (Inner Packing Unit)	Type (Inner Packing Unit)	Size (Inner Packing Unit)	Weight (Inner Packing Unit)	AK-330107-100-S	10M	5pcs	neutral polybag	400*530mm	3kg	C				
P/N	Cable Length	Quantity (Inner Packing Unit)	Type (Inner Packing Unit)	Size (Inner Packing Unit)	Weight (Inner Packing Unit)																			
AK-330107-100-S	10M	5pcs	neutral polybag	400*530mm	3kg																			
D	Carton Details <table><tr><th>P/N</th><th>Cable Length</th><th>Quantity (Carton)</th><th>Measurement (Carton)</th><th>N.W. (Carton)</th><th>G.W. (Carton)</th></tr><tr><td>AK-330107-100-S</td><td>10M</td><td>20pcs</td><td>400*380*210mm</td><td>12.3kg</td><td>13.3kg</td></tr></table> 70mm 45mm P/N:AK-330107-100-S QTY:5pcs CE 10 m 4 016032 307051 S/N:530205XXXXX HEAT SEALED							P/N	Cable Length	Quantity (Carton)	Measurement (Carton)	N.W. (Carton)	G.W. (Carton)	AK-330107-100-S	10M	20pcs	400*380*210mm	12.3kg	13.3kg	D				
P/N	Cable Length	Quantity (Carton)	Measurement (Carton)	N.W. (Carton)	G.W. (Carton)																			
AK-330107-100-S	10M	20pcs	400*380*210mm	12.3kg	13.3kg																			
E	<table><tr><th>P/N</th><th>Cable Length</th><th>Quantity (Carton)</th><th>Measurement (Carton)</th><th>N.W. (Carton)</th><th>G.W. (Carton)</th></tr><tr><td>AK-330107-100-S</td><td>10M</td><td>20pcs</td><td>400*380*210mm</td><td>12.3kg</td><td>13.3kg</td></tr></table>							P/N	Cable Length	Quantity (Carton)	Measurement (Carton)	N.W. (Carton)	G.W. (Carton)	AK-330107-100-S	10M	20pcs	400*380*210mm	12.3kg	13.3kg	E				
P/N	Cable Length	Quantity (Carton)	Measurement (Carton)	N.W. (Carton)	G.W. (Carton)																			
AK-330107-100-S	10M	20pcs	400*380*210mm	12.3kg	13.3kg																			
F	DIGITUS® Rotterdam C/NO: MANUFACTURED IN P.R.C ORDER NO: ITEM NO: QTY: G.W.: MEAS.: EAN-Code: Code39: Do not use waterproof bags							F																
G	<table><tr><th></th><th>Date</th><th>Name</th><th>Part No.</th></tr><tr><td>Drawn by</td><td>2022/7/6</td><td></td><td>AK-330107-100-S</td></tr><tr><td>Checked by</td><td></td><td></td><td>EAN:4016032307051</td></tr><tr><td>Approved by</td><td></td><td></td><td></td></tr></table>								Date	Name	Part No.	Drawn by	2022/7/6		AK-330107-100-S	Checked by			EAN:4016032307051	Approved by				G
	Date	Name	Part No.																					
Drawn by	2022/7/6		AK-330107-100-S																					
Checked by			EAN:4016032307051																					
Approved by																								
H	ASSMANN Electronic GmbH 87363 * "ROTTERDAM" is for Sea Freight shipment * "COLOGNE" is for Air Freight shipment * "LUDENSCHIED" is for Fedex or UPS shipment Scale Unit N/A MM Sheet 2/2							H																
	1	2	3	4	5	6	7																	