

Product family:

Terminals - Uninsulated quick-connect terminals

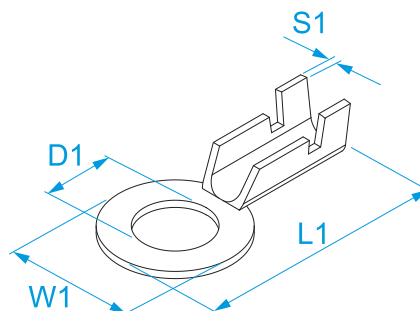
Code:

91103, 91113, 92103, 92113, 91104, 91114, 92104, 92114, 91105, 91115, 92105, 92115, 91203, 91213, 92203, 92213, 91204, 91214, 92204, 92214, 91205, 91215, 92205, 92215

Description:

TERMINAL LUGS FOR COPPER CONDUCTORS · UNINSULATED FROM SHEET · OPEN BRASS

Image:

Technical Drawing:

Specifications:
TERMINAL MATERIAL:

tinned/passivated brass

OPERATING TEMPERATURE:

from -50 °C to +150 °C

Code	Material	Execution	Section (mm ²)	Section (AWG/MCM)	For screw Ø screw (mm)	For screw Stud size	W1 (mm)	L1 (mm)	D1 (mm)	S1 (mm)	
91103	passivated brass	loose	0.75 ÷ 1	(18)	3	#4	8	21	3,2	0,6	200/2000
91113	tinned brass	loose	0.75 ÷ 1	(18)	3	#4	8	21	3,2	0,6	
92103	passivated brass	reel	0.75 ÷ 1	(18)	3	#4	7	17,7	3,2	0,5	8000/8000
92113	tinned brass	reel	0.75 ÷ 1	(18)	3	#4	7	17,7	3,2	0,5	
91104	passivated brass	loose	0.75 ÷ 1	(18)	4	#8	8,7	20	4,3	0,6	200/2000
91114	tinned brass	loose	0.75 ÷ 1	(18)	4	#8	8,7	20	4,3	0,6	
92104	passivated brass	reel	0.75 ÷ 1	(18)	4	#8	7	17,7	4,2	0,5	8000/8000
92114	tinned brass	reel	0.75 ÷ 1	(18)	4	#8	7	17,7	4,2	0,5	
91105	passivated brass	loose	0.75 ÷ 1	(18)	5	#10	8,7	20	5,2	0,6	200/2000
91115	tinned brass	loose	0.75 ÷ 1	(18)	5	#10	8,7	20	5,2	0,6	
92105	passivated brass	reel	0.75 ÷ 1	(18)	5	#10	7	17,7	5,2	0,5	8000/8000
92115	tinned brass	reel	0.75 ÷ 1	(18)	5	#10	7	17,7	5,2	0,5	
91203	passivated brass	loose	1 ÷ 2.5	(18 - 14)	3	#4	8	21	3,2	0,5	200/2000
91213	tinned brass	loose	1 ÷ 2.5	(18 - 14)	3	#4	8	21	3,2	0,5	
92203	passivated brass	reel	1 ÷ 2.5	(18 - 14)	3	#4	7	17,7	3,2	0,5	5000/5000
92213	tinned brass	reel	1 ÷ 2.5	(18 - 14)	3	#4	7	17,7	3,2	0,5	
91204	passivated brass	loose	1 ÷ 2.5	(18 - 14)	4	#8	8,7	20	4,3	0,6	200/2000
91214	tinned brass	loose	1 ÷ 2.5	(18 - 14)	4	#8	8,7	20	4,3	0,6	
92204	passivated brass	reel	1 ÷ 2.5	(18 - 14)	4	#8	7	17,7	4,2	0,5	5000/5000
92214	tinned brass	reel	1 ÷ 2.5	(18 - 14)	4	#8	7	17,7	4,2	0,5	
91205	passivated brass	loose	1 ÷ 2.5	(18 - 14)	5	#10	8,7	20	5,2	0,6	200/2000
91215	tinned brass	loose	1 ÷ 2.5	(18 - 14)	5	#10	8,7	20	5,2	0,6	
92205	passivated brass	reel	1 ÷ 2.5	(18 - 14)	5	#10	7	17,7	5,2	0,5	5000/5000
92215	tinned brass	reel	1 ÷ 2.5	(18 - 14)	5	#10	7	17,7	5,2	0,5	